



MAXOLUTION®

Vertical conveyor with
optional energy management

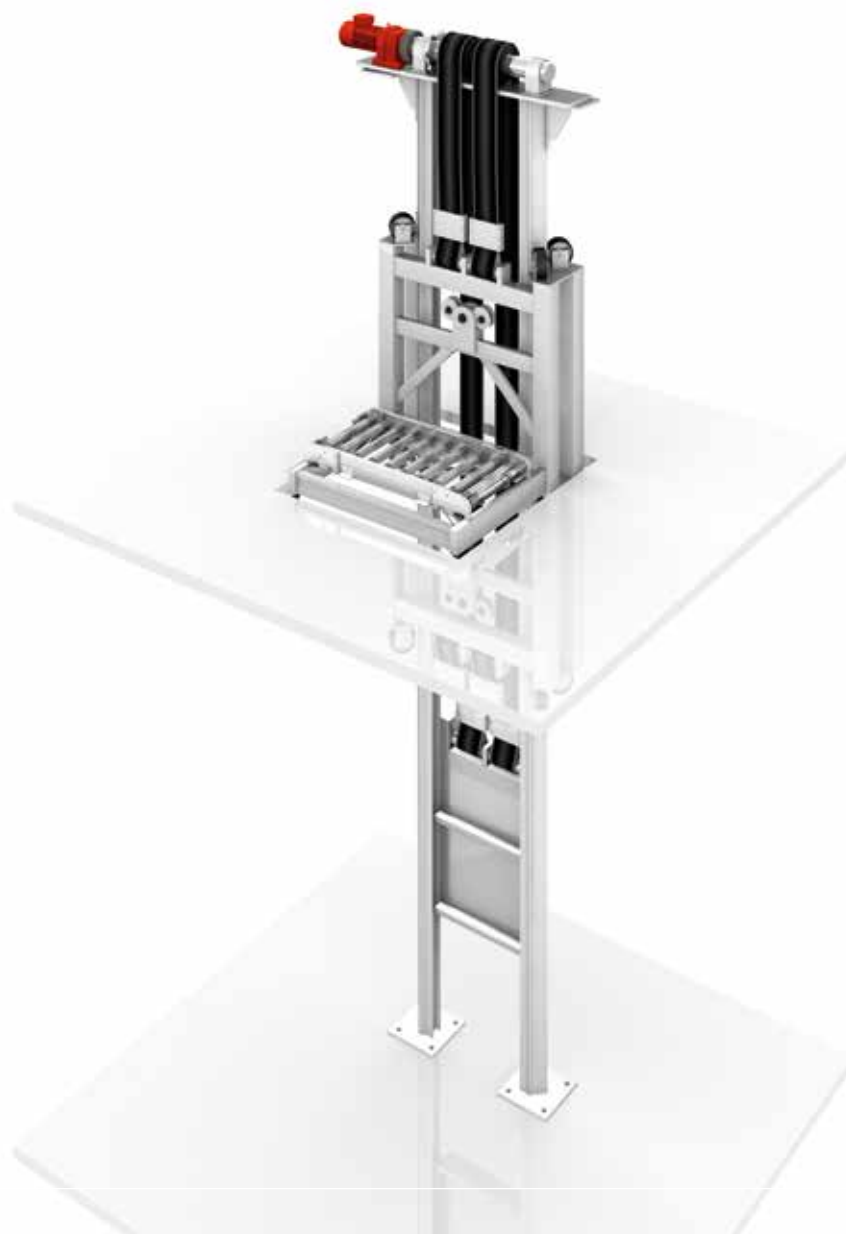

Vertical conveyor with optional energy management

The Vertical conveyor with optional energy management solution package is designed for relocating and order-picking tasks in lifting applications in many areas of logistics. The three options of auxiliary axes meet different handling loads and optimize the energy use. The decentralized technology enables conveyance and lifting more flexible, variable and efficient.

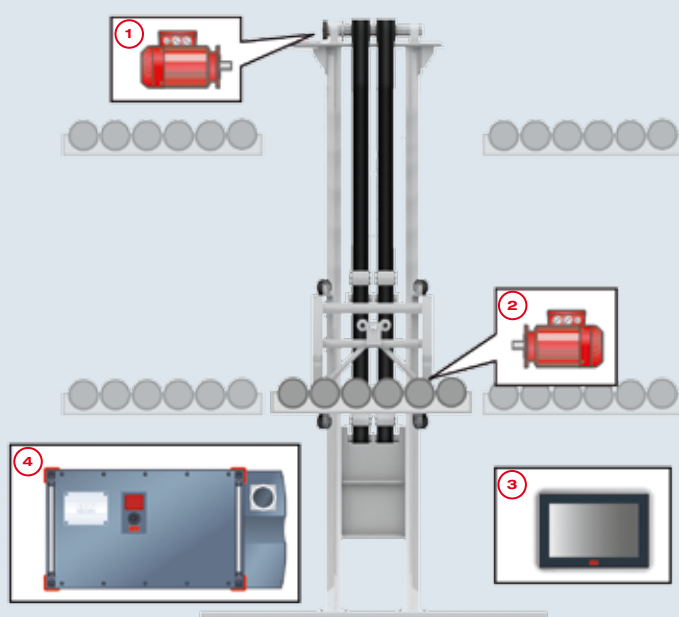

Used components

- ① Lifting drive DR.. / CMP..
- ② DRC.. SBus / MOVIFIT® SBus Slave / MOVIGEAR® SBus
- ③ Optional: DOP stationary operator panel
- ④ MOVIPRO® ADC

Not shown:
System software MOVIVISION®

Advantage

Functionality

- Simple adjustment for speed and position
- Standard brake components are available for MOVIPRO® ADC
- Communication via/within bus system
- Standard software for visualization, control and diagnostics
- Uninterruptible power supply
- Grid load reduction due to the energy storage device

Cost savings

- Simple installation due to prefabricated cables and calibrated components
- Fast startup due to parameterization via application software
- Low maintenance effort
- Energy saving
- Easy integration with existing installation/ interfaces

Service

- Optimized ordering and delivery processes
- Worldwide project management
- Training course
- System-specific documentation
- Possibilities for software customization

SEW
EURODRIVE

SEW-EURODRIVE GmbH & Co KG
P.O.Box 30 23
76642 Bruchsal/Germany
Tel. +49 7251 75-0
Fax +49 7251 75-1970
sew@sew-eurodrive.com

→ www.sew-eurodrive.com