

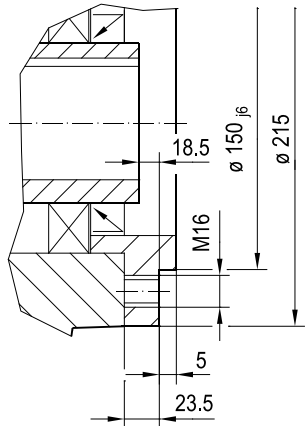
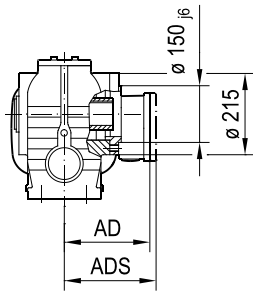
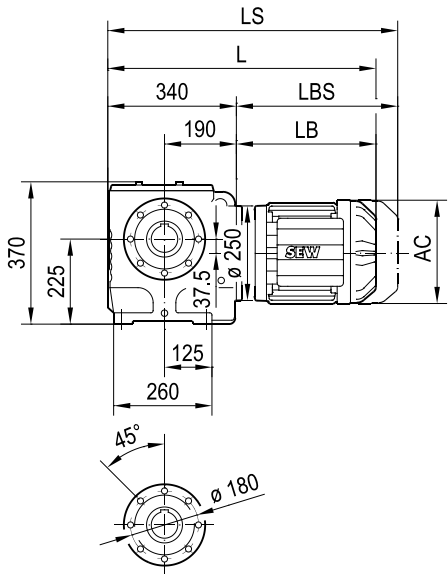


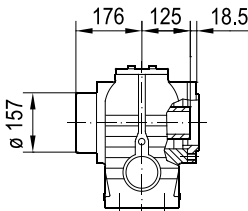




SAZ87/SAZ87p..

SHZ87/SHZ87p..

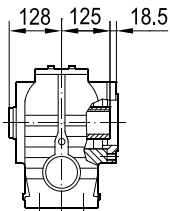

ø 70 H7

ø 60 H7

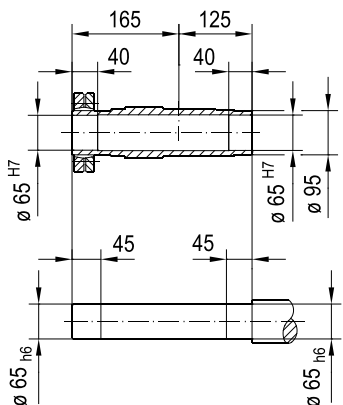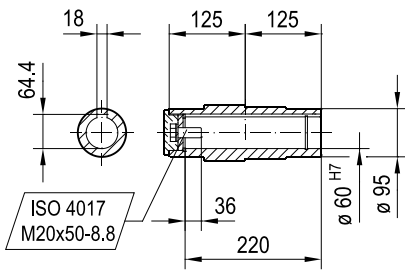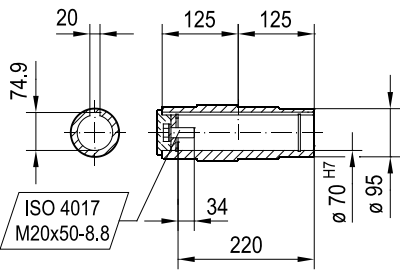

(→ 📖 4.1)	DRN												
	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..
AC	156	156	156	179	179	197	197	221	221	261	261	314	357
AD	128	128	128	140	140	157	157	170	170	228	228	253	268
ADS	139	139	139	150	150	158	158	172	172	228	228	253	268
L	558	575	604	606	638	633	683	714	764	782	808	874	897
LS	639	656	685	699	731	727	777	826	876	920	945	1063	1086
LB	218	235	264	266	298	293	343	374	424	442	468	534	557
LBS	299	316	345	359	391	387	437	486	536	580	605	723	746