




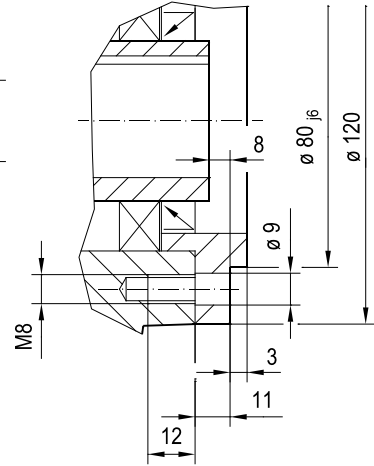


KAZ47..

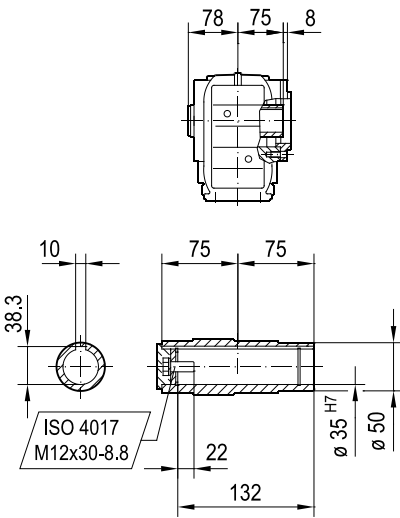

KHZ47..

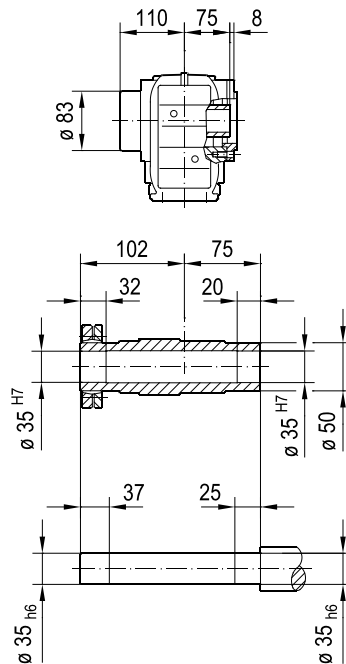

KVZ47..

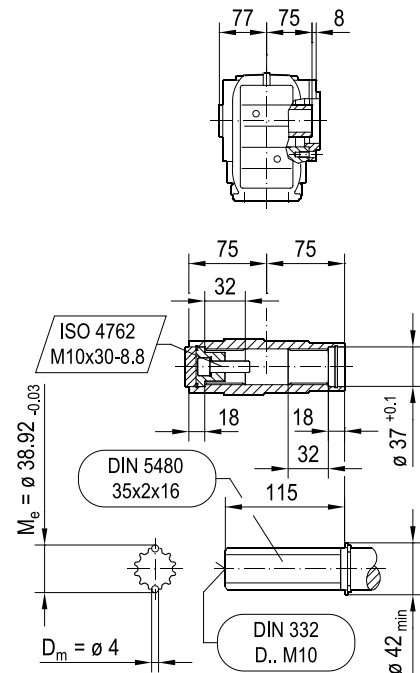

(→ 📖 4.1)	DRN										
	63MS	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM
AC	115	115	139	139	156	156	156	179	179	197	197
AD	98	98	118	118	128	128	128	140	140	157	157
ADS	98	98	129	129	139	139	139	150	150	158	158
L	427	441	442	462	473	490	519	521	553	548	598
LS	483	497	510	530	554	571	600	614	646	642	692
LB	184	198	199	219	230	247	276	278	310	305	355
LBS	240	254	267	287	311	328	357	371	403	399	449