




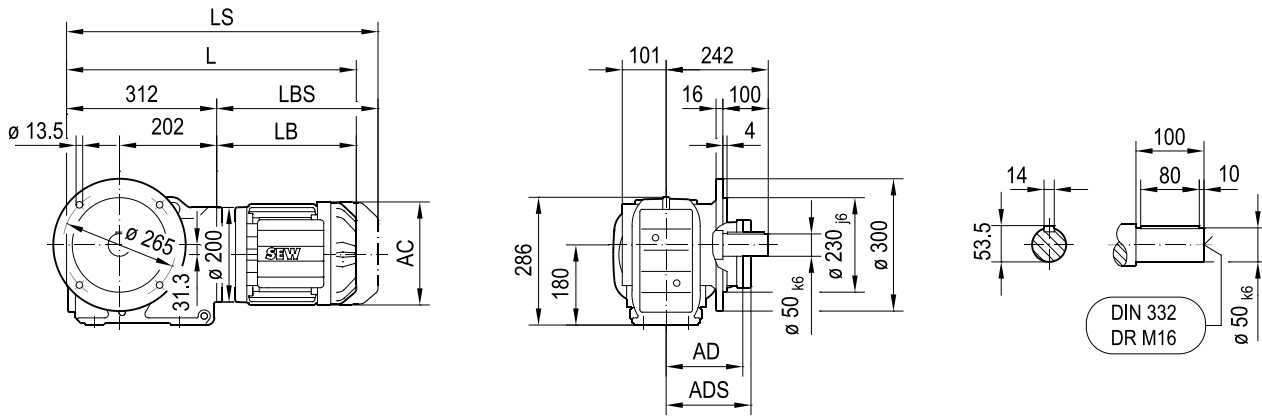


KAF77..

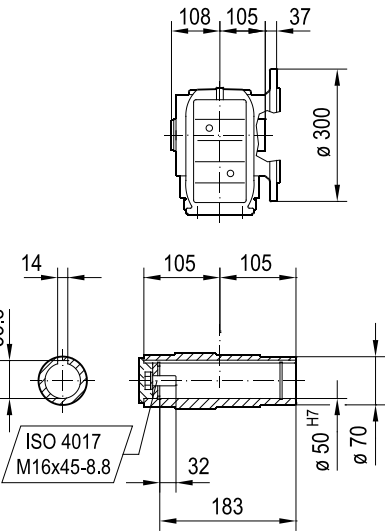

KHF77..

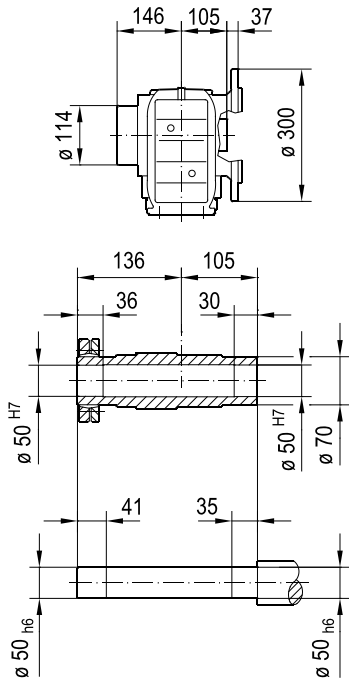

KVF77..

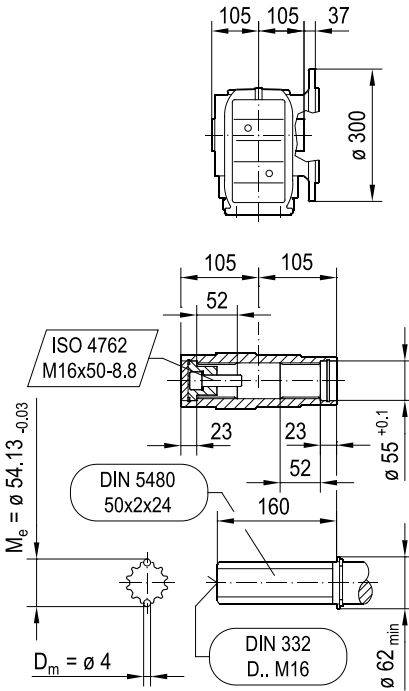

| (→ 📖 4.1) | DRN |      |      |     |     |     |       |         |      |      |      |      |       |
|-----------|-----|------|------|-----|-----|-----|-------|---------|------|------|------|------|-------|
|           | 71M | 80MK | 80MS | 80M | 90S | 90L | 100LS | 100L/LM | 112M | 132S | 132M | 132L | 160.. |
| AC        | 139 | 156  | 156  | 156 | 179 | 179 | 197   | 197     | 221  | 221  | 261  | 261  | 314   |
| AD        | 118 | 128  | 128  | 128 | 140 | 140 | 157   | 157     | 170  | 170  | 228  | 228  | 253   |
| ADS       | 129 | 139  | 139  | 139 | 150 | 150 | 158   | 158     | 172  | 172  | 228  | 228  | 253   |
| L         | 524 | 535  | 552  | 581 | 583 | 615 | 610   | 660     | 691  | 741  | 759  | 785  | 851   |
| LS        | 592 | 616  | 633  | 662 | 676 | 708 | 704   | 754     | 803  | 853  | 897  | 922  | 1040  |
| LB        | 212 | 223  | 240  | 269 | 271 | 303 | 298   | 348     | 379  | 429  | 447  | 473  | 539   |
| LBS       | 280 | 304  | 321  | 350 | 364 | 396 | 392   | 442     | 491  | 541  | 585  | 610  | 728   |