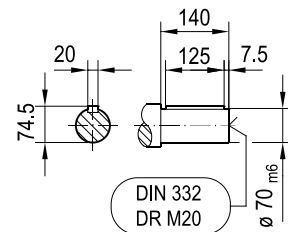
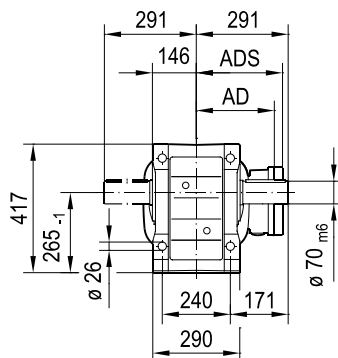
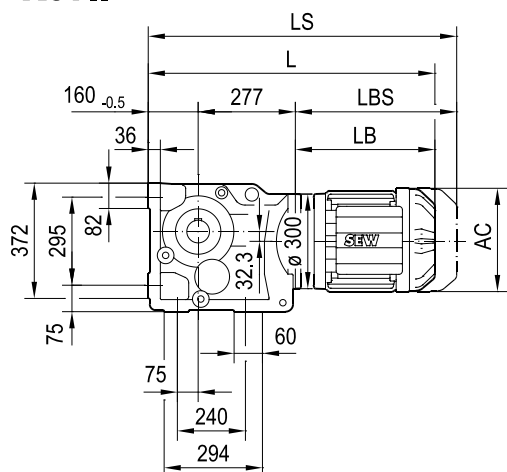
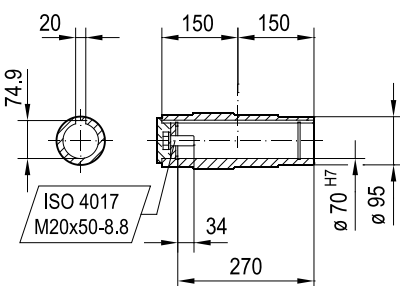
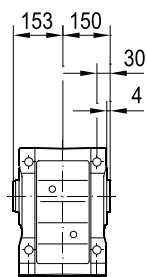
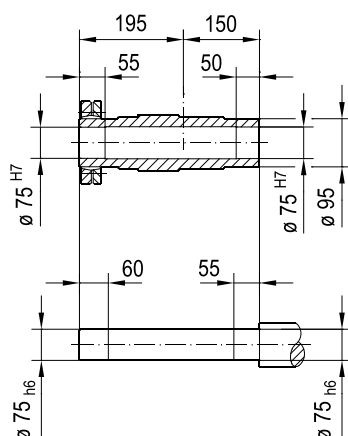
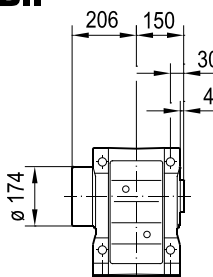
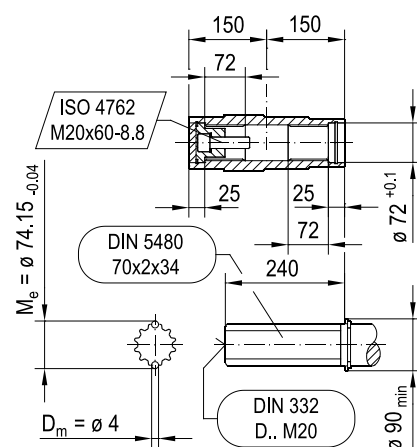
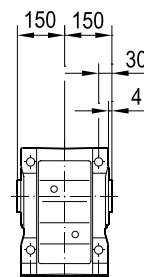


K97..**KA97B..****KH97B..****KV97B..**

(→ 4.1)	DRN											
	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..
AC	179	179	197	197	221	221	261	261	314	357	394	434
AD	140	140	157	157	170	170	228	228	253	268	283	305
ADS	150	150	158	158	172	172	228	228	253	268	283	305
L	698	730	725	775	806	856	874	900	966	989	1099	1073
LS	791	823	819	869	918	968	1012	1037	1155	1178	1304	1278
LB	261	293	288	338	369	419	437	463	529	552	662	636
LBS	354	386	382	432	481	531	575	600	718	741	867	841