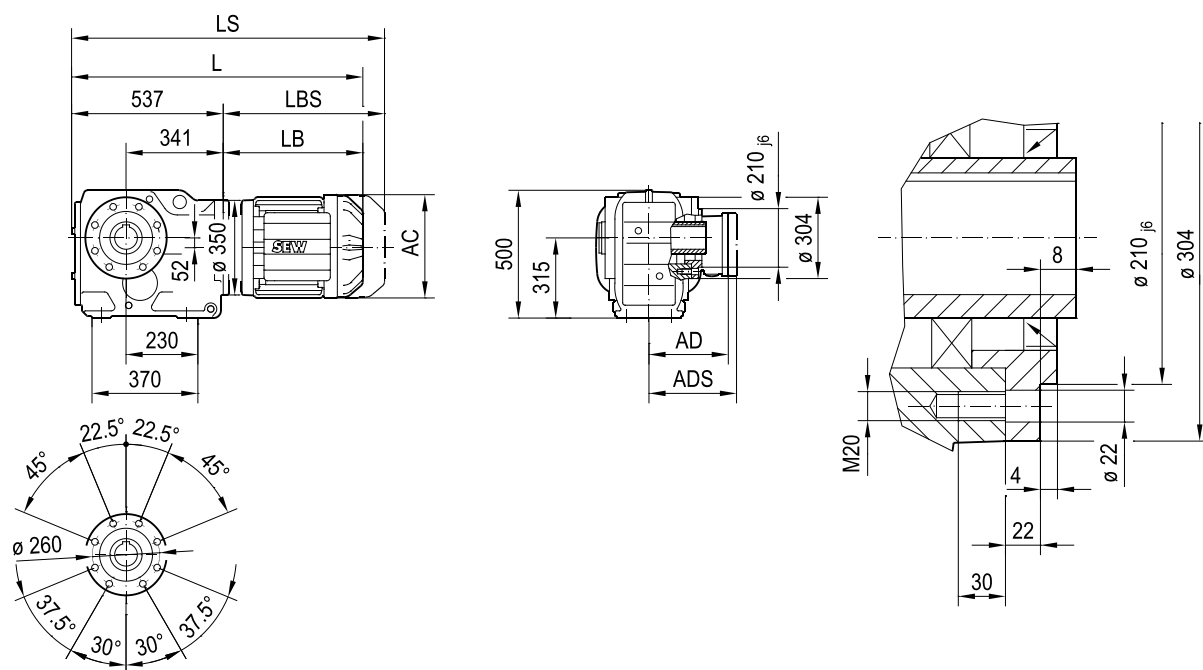
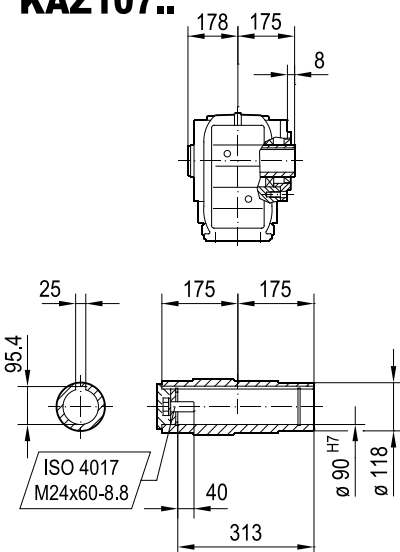
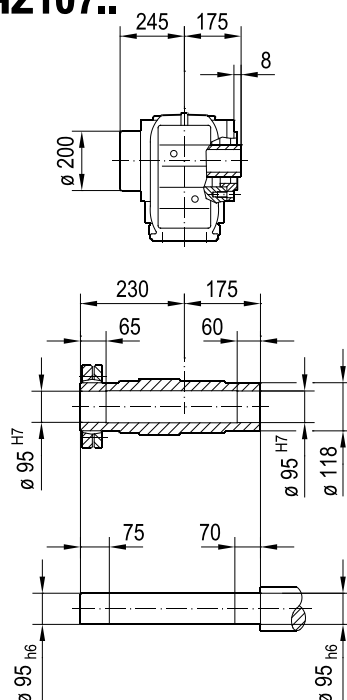
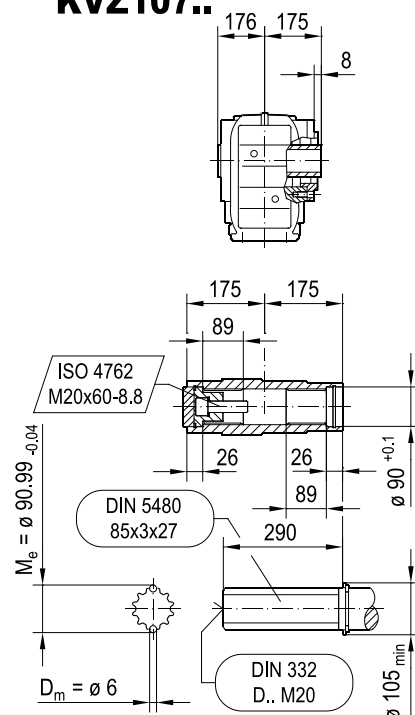


KAZ107..**KAZ107..****KHZ107..****KVZ107..**

(→ 4.1)	DRN										
	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..	250M
AC	197	197	221	221	261	261	314	357	394	434	495
AD	157	157	170	170	228	228	253	268	283	305	394
ADS	158	158	172	172	228	228	253	268	283	305	394
L	819	869	900	950	968	994	1060	1083	1193	1167	1304
LS	913	963	1012	1062	1106	1131	1249	1272	1398	1372	1544
LB	282	332	363	413	431	457	523	546	656	630	767
LBS	376	426	475	525	569	594	712	735	861	835	1007