




KAZ127..

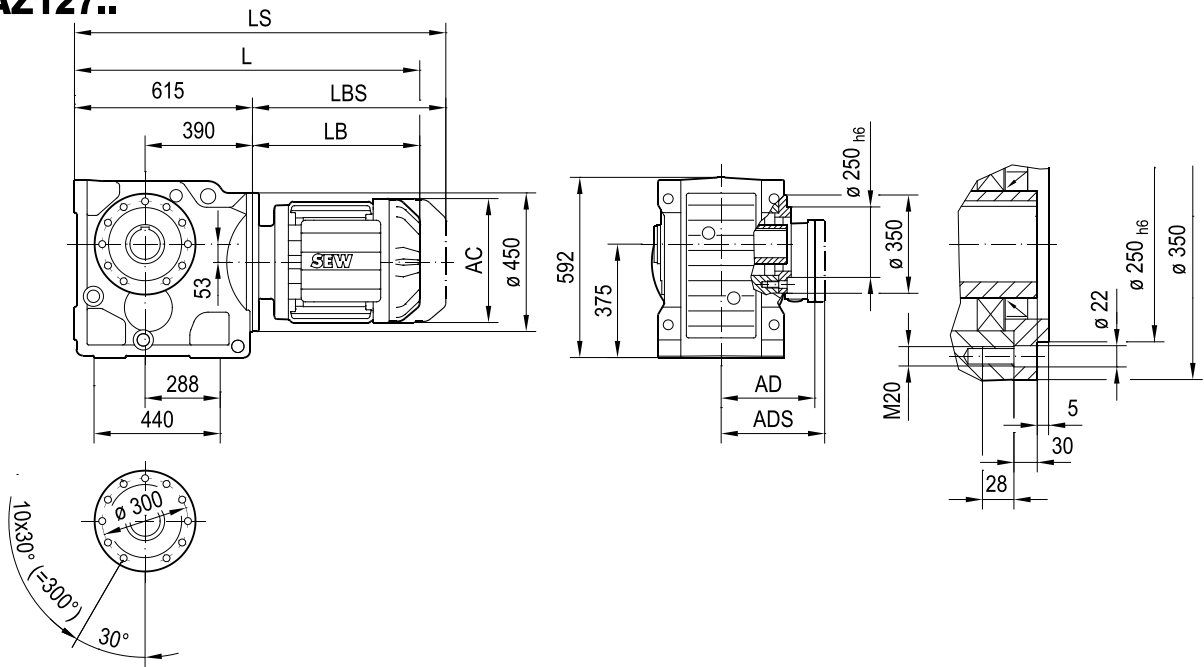

KAZ127..

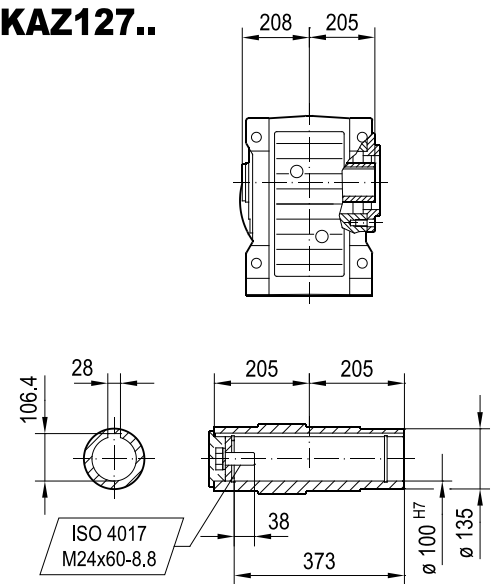

KHZ127..

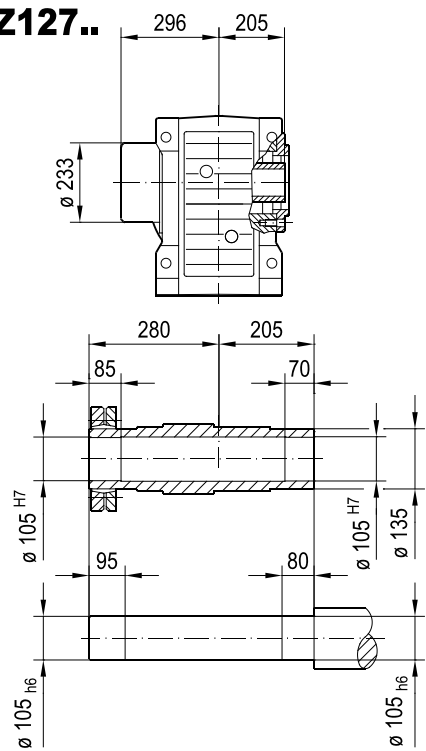

($\rightarrow$ 4.1)	DRN									
	132S	132M	132L	160..	180..	200L	225..	250M	280S	280M
AC	221	261	261	314	357	394	434	495	495	495
AD	170	228	228	253	268	283	305	394	394	394
ADS	172	228	228	253	268	283	305	394	394	394
L	1013	1031	1057	1123	1146	1256	1230	1367	1367	1462
LS	1125	1169	1194	1312	1335	1461	1435	1607	1607	1702
LB	398	416	442	508	531	641	615	752	752	847
LBS	510	554	579	697	720	846	820	992	992	1087