

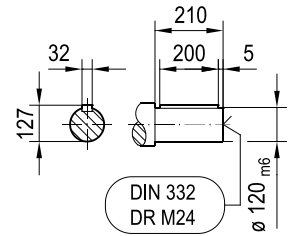
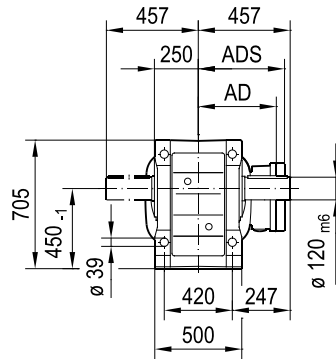



K157..

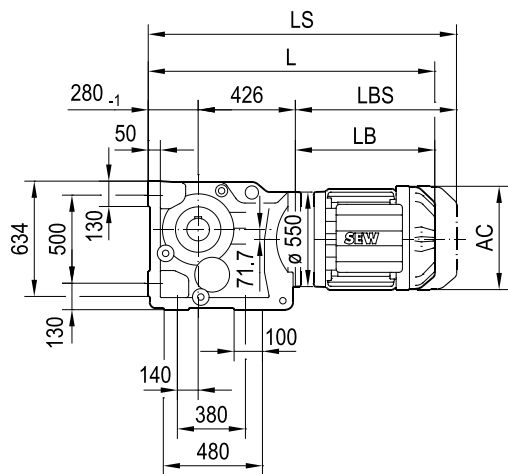

KA157B..

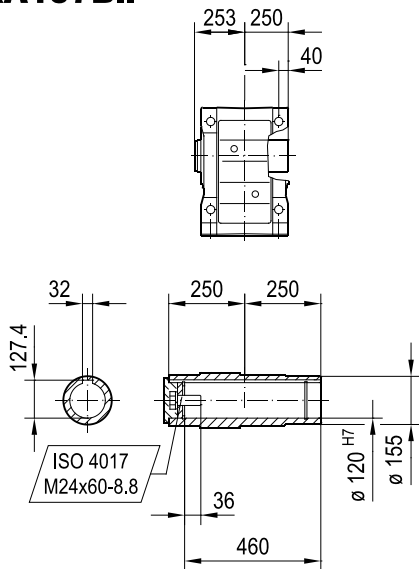

KH157B..

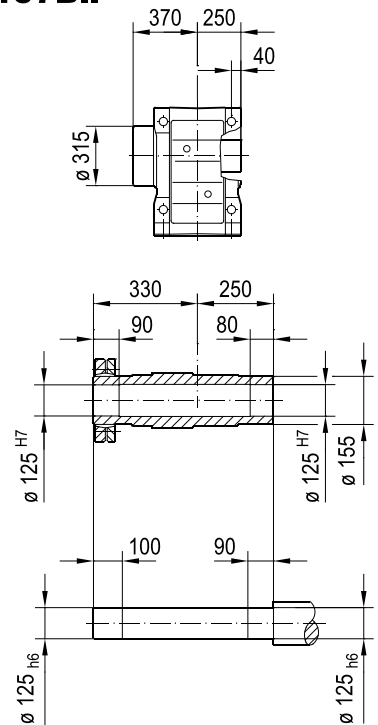

(→ 📖 4.1)	DRN									
	132L	160..	180..	200L	225..	250M	280S	280M	315S-M	315ME-H
AC	261	314	357	394	434	495	495	495	624	624
AD	228	253	268	283	305	394	394	394	506	506
ADS	228	253	268	283	305	394	394	394	506	506
L	1140	1206	1229	1339	1313	1450	1450	1545	1647	1777
LS	1277	1395	1418	1544	1518	1690	1690	1785	1898	2028
LB	434	500	523	633	607	744	744	839	941	1071
LBS	571	689	712	838	812	984	984	1079	1192	1322