

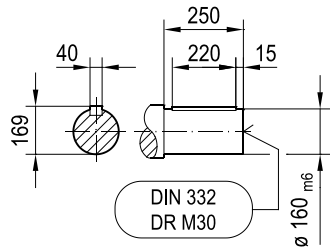
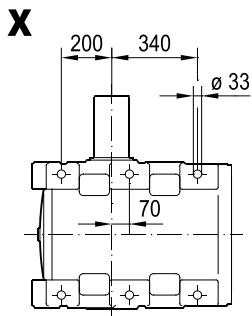
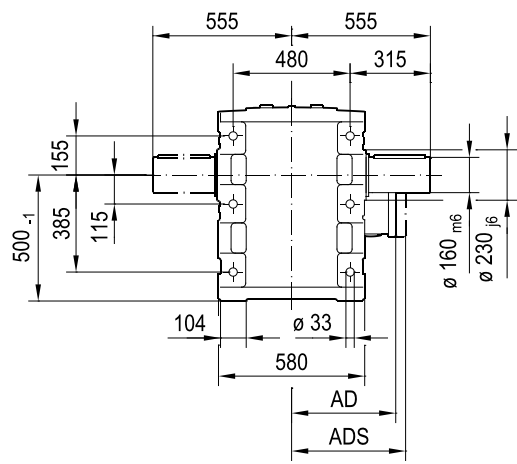
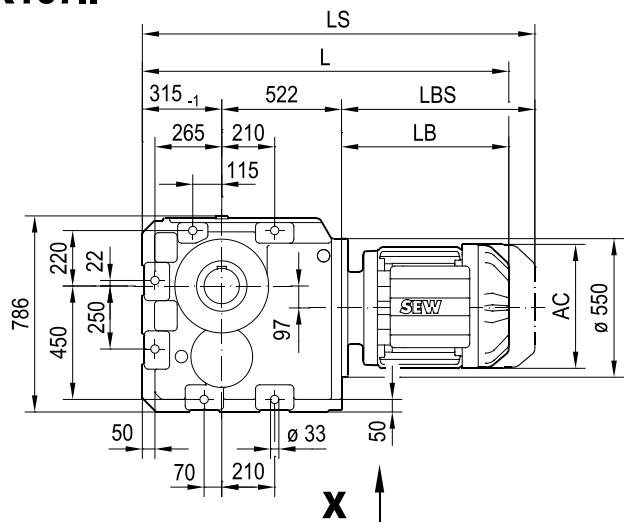


K167..

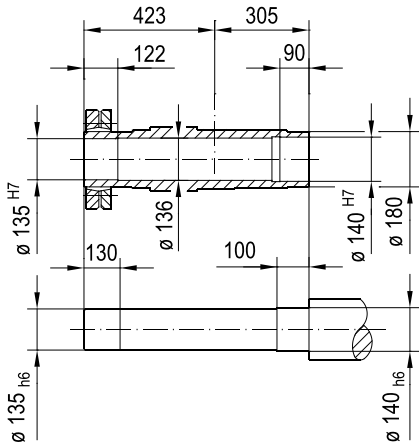

KH167B..

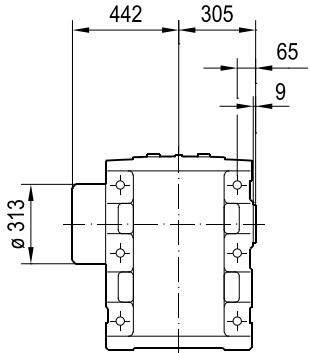

(→ 4.1)	DRN									
	132L	160..	180..	200L	225..	250M	280S	280M	315S-M	315ME-H
AC	261	314	357	394	434	495	495	495	624	624
AD	228	253	268	283	305	394	394	394	506	506
ADS	228	253	268	283	305	394	394	394	506	506
L	1271	1337	1360	1470	1444	1581	1581	1676	1778	1908
LS	1408	1526	1549	1675	1649	1821	1821	1916	2029	2159
LB	434	500	523	633	607	744	744	839	941	1071
LBS	571	689	712	838	812	984	984	1079	1192	1322