

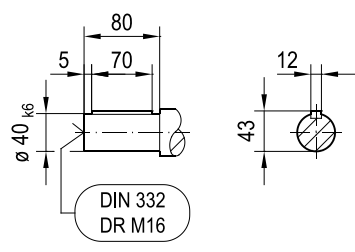
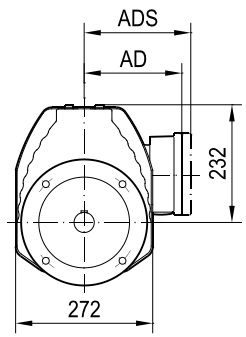



RXF87..

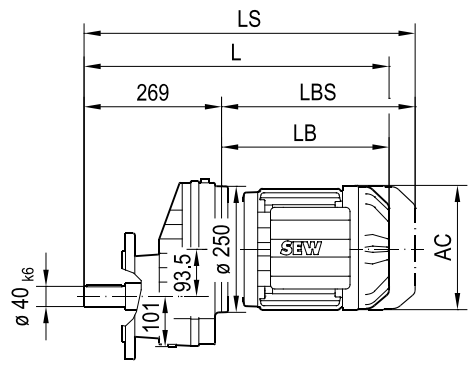

ø 250

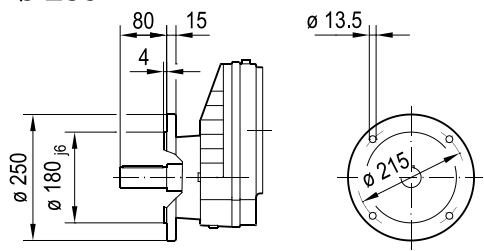

ø 300

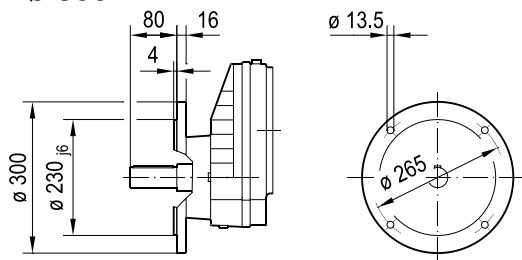

(→ 4.1)	DRN											
	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L
AC	156	179	179	197	197	221	221	261	261	314	357	394
AD	128	140	140	157	157	170	170	228	228	253	268	283
ADS	139	150	150	158	158	172	172	228	228	253	268	283
L	533	535	567	562	612	643	693	711	737	803	826	936
LS	614	628	660	656	706	755	805	849	874	992	1015	1141
LB	264	266	298	293	343	374	424	442	468	534	557	667
LBS	345	359	391	387	437	486	536	580	605	723	746	872