

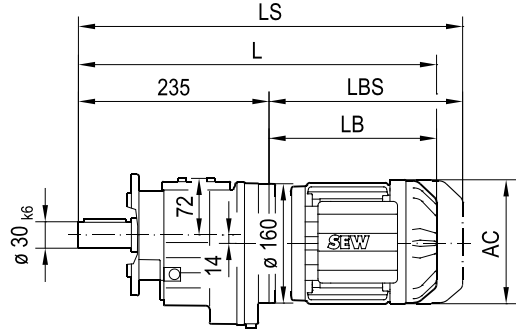



ø 140

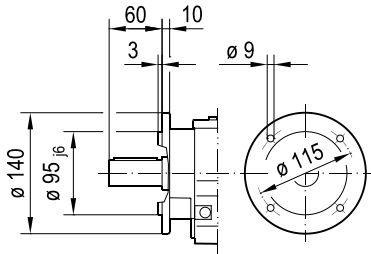

ø 160

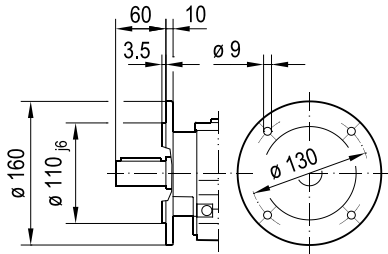

ø 200

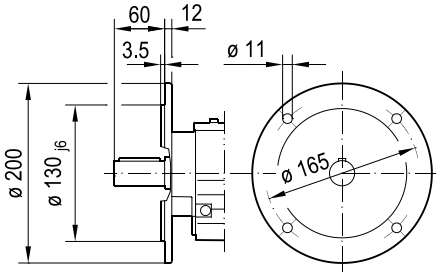

(→ 📖 4.1)	DRN												
	63MS	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S
AC	115	115	139	139	156	156	156	179	179	197	197	221	221
AD	98	98	118	118	128	128	128	140	140	157	157	170	170
ADS	98	98	129	129	139	139	139	150	150	158	158	172	172
L	419	433	434	454	465	482	511	513	545	540	590	621	675
LS	475	489	502	522	546	563	592	606	638	634	684	733	787
LB	184	198	199	219	230	247	276	278	310	305	355	386	440
LBS	240	254	267	287	311	328	357	371	403	399	449	498	552