



R87..

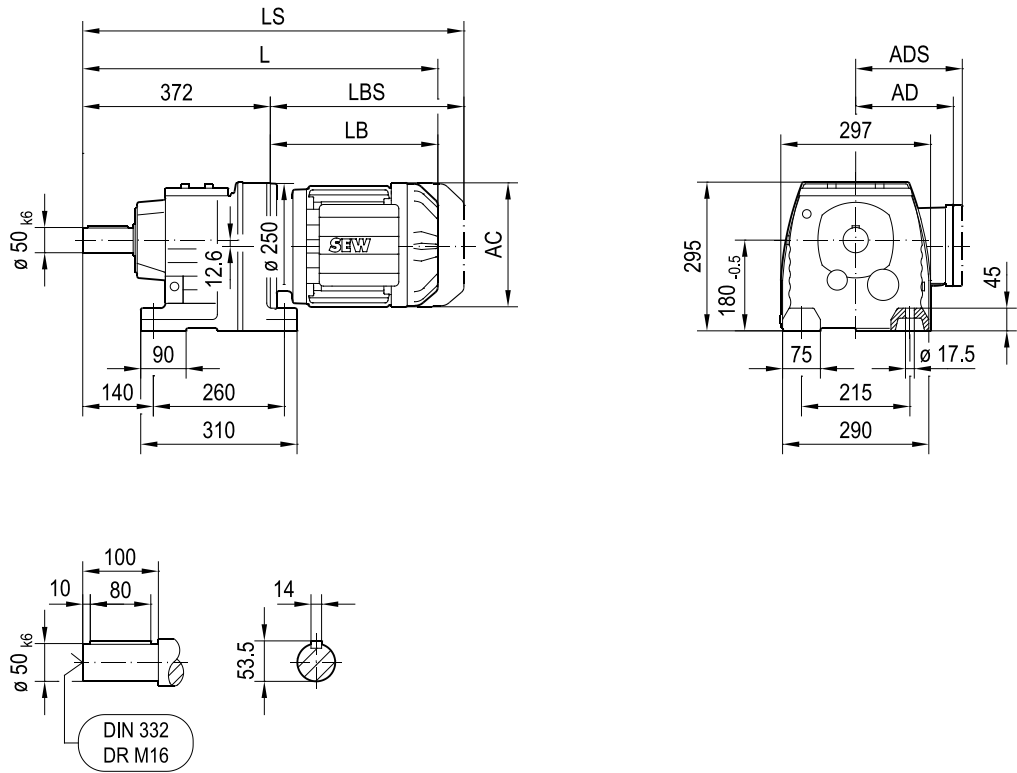

R87F..

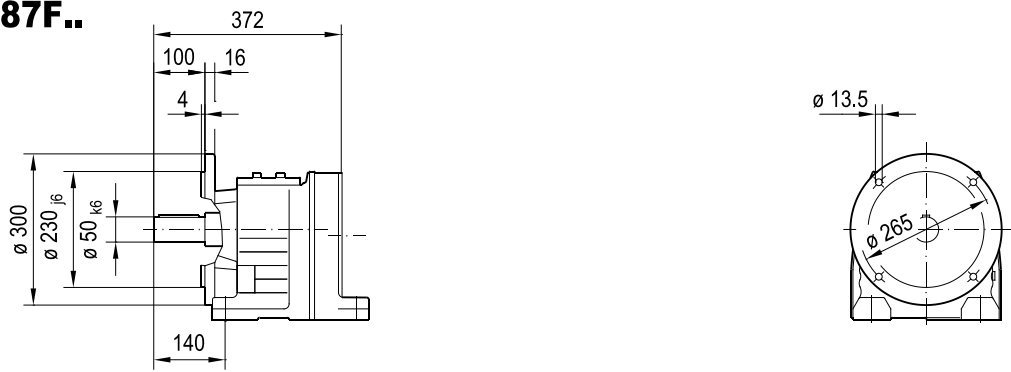

(→ 📖 4.1)	DRN														
	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L
AC	139	156	156	156	179	179	197	197	221	221	261	261	314	357	394
AD	118	128	128	128	140	140	157	157	170	170	228	228	253	268	283
ADS	129	139	139	139	150	150	158	158	172	172	228	228	253	268	283
L	579	590	607	636	638	670	665	715	746	796	814	840	906	929	1039
LS	647	671	688	717	731	763	759	809	858	908	952	977	1095	1118	1244
LB	207	218	235	264	266	298	293	343	374	424	442	468	534	557	667
LBS	275	299	316	345	359	391	387	437	486	536	580	605	723	746	872