




RF87..

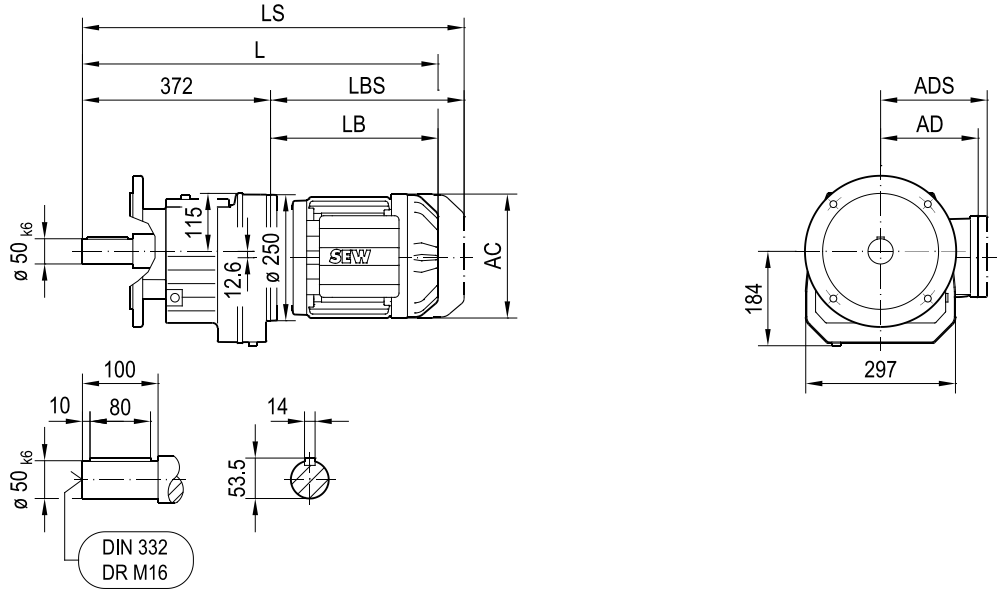


ø 300

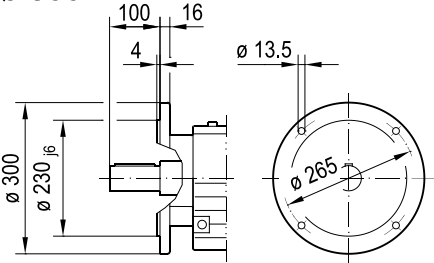

ø 350

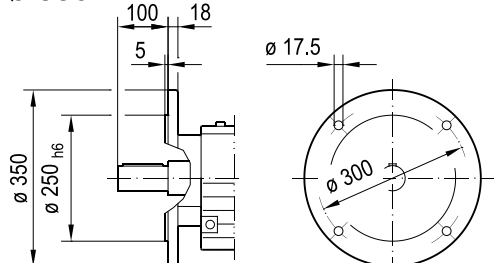

RM87..

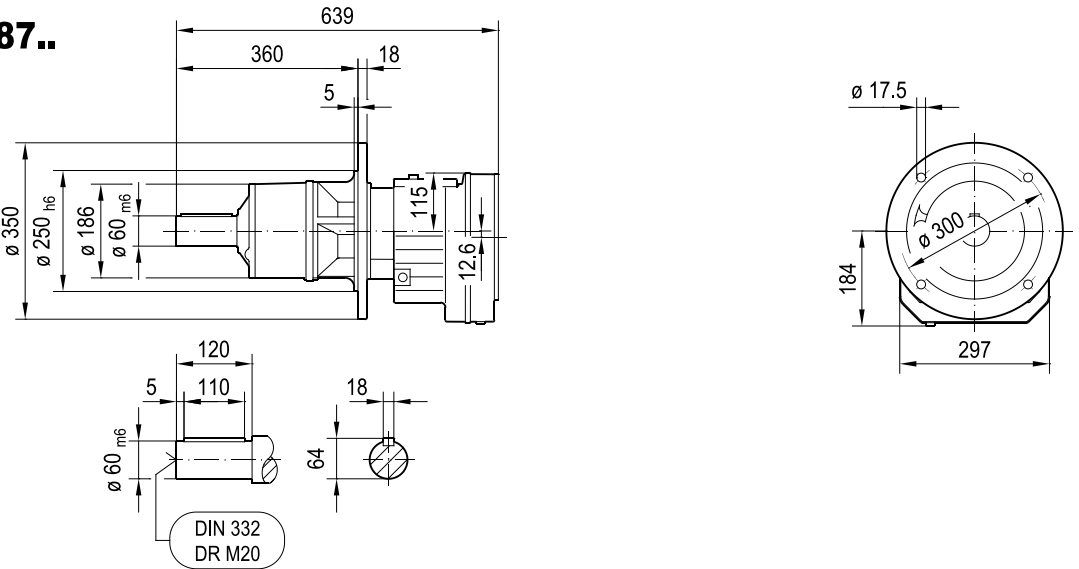

| (→ 📖 4.1) | DRN |      |      |     |     |     |       |         |      |      |      |      |       |       |      |
|-----------|-----|------|------|-----|-----|-----|-------|---------|------|------|------|------|-------|-------|------|
|           | 71M | 80MK | 80MS | 80M | 90S | 90L | 100LS | 100L/LM | 112M | 132S | 132M | 132L | 160.. | 180.. | 200L |
| AC        | 139 | 156  | 156  | 156 | 179 | 179 | 197   | 197     | 221  | 221  | 261  | 261  | 314   | 357   | 394  |
| AD        | 118 | 128  | 128  | 128 | 140 | 140 | 157   | 157     | 170  | 170  | 228  | 228  | 253   | 268   | 283  |
| ADS       | 129 | 139  | 139  | 139 | 150 | 150 | 158   | 158     | 172  | 172  | 228  | 228  | 253   | 268   | 283  |
| L         | 579 | 590  | 607  | 636 | 638 | 670 | 665   | 715     | 746  | 796  | 814  | 840  | 906   | 929   | 1039 |
| LS        | 647 | 671  | 688  | 717 | 731 | 763 | 759   | 809     | 858  | 908  | 952  | 977  | 1095  | 1118  | 1244 |
| LB        | 207 | 218  | 235  | 264 | 266 | 298 | 293   | 343     | 374  | 424  | 442  | 468  | 534   | 557   | 667  |
| LBS       | 275 | 299  | 316  | 345 | 359 | 391 | 387   | 437     | 486  | 536  | 580  | 605  | 723   | 746   | 872  |