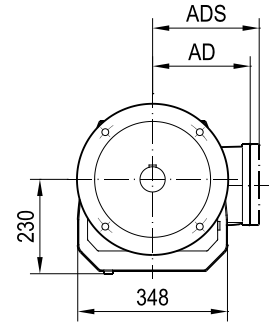
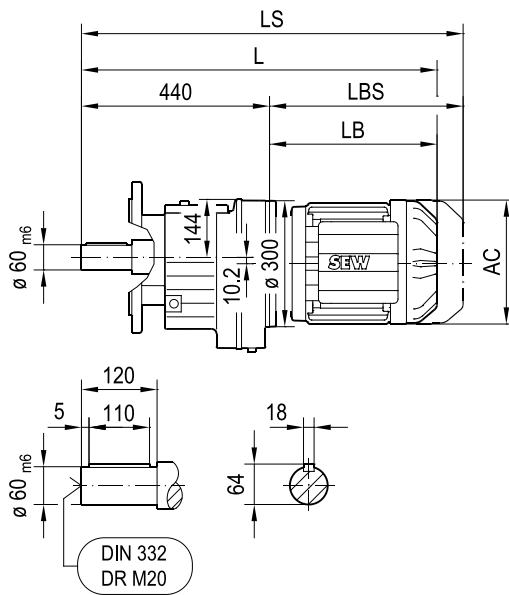
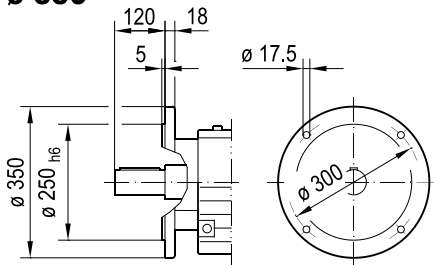
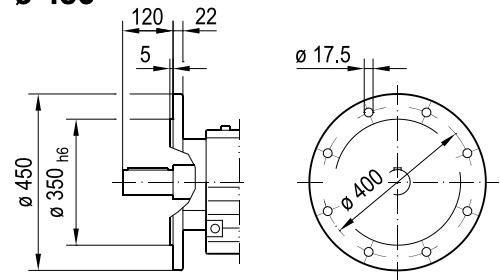
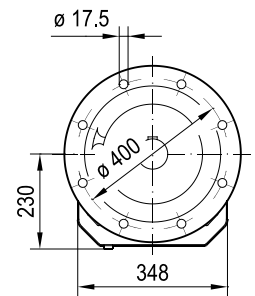
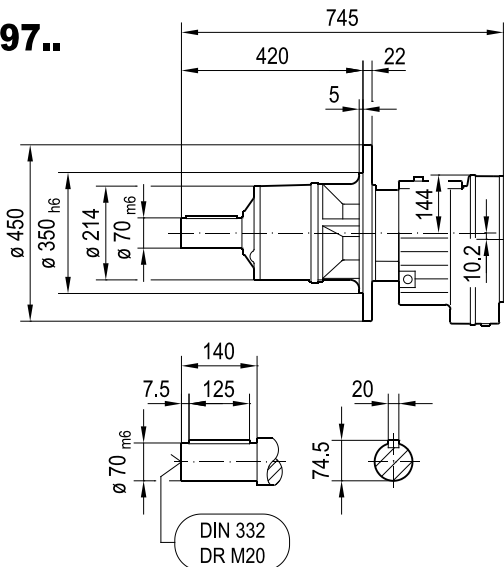


RF97..**ø 350****ø 450****RM97..**

(→ 📖 4.1)	DRN														
	71M	80MK	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..
AC	139	156	156	179	179	197	197	221	221	261	261	314	357	394	434
AD	118	128	128	140	140	157	157	170	170	228	228	253	268	283	305
ADS	129	139	139	150	150	158	158	172	172	228	228	253	268	283	305
L	642	653	699	701	733	728	778	809	859	877	903	969	992	1102	1076
LS	710	734	780	794	826	822	872	921	971	1015	1040	1158	1181	1307	1281
LB	202	213	259	261	293	288	338	369	419	437	463	529	552	662	636
LBS	270	294	340	354	386	382	432	481	531	575	600	718	741	867	841