




RF107..

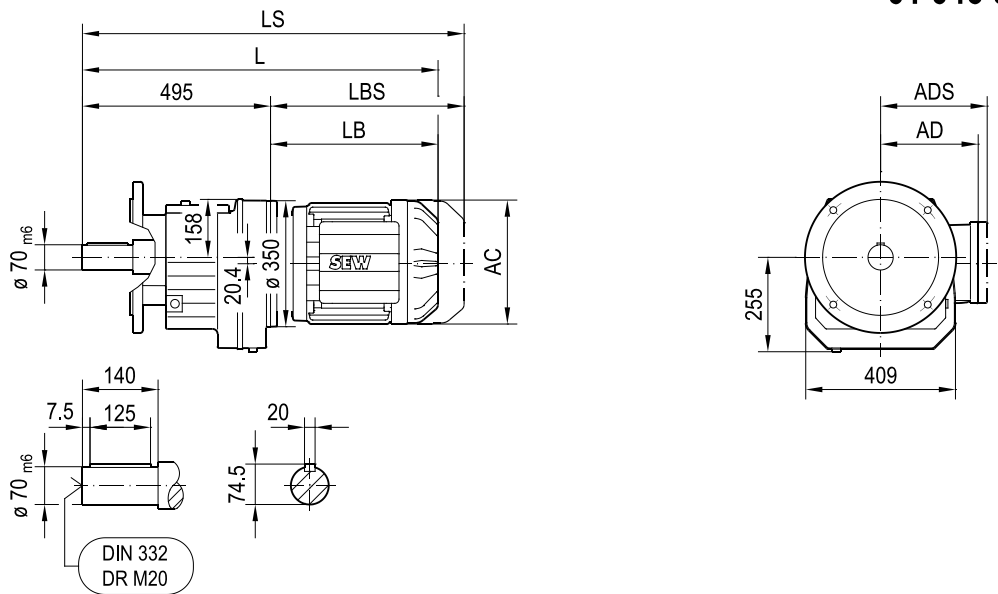


ø 350

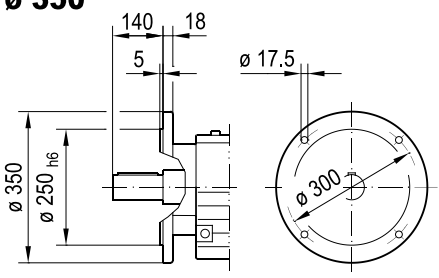

ø 450

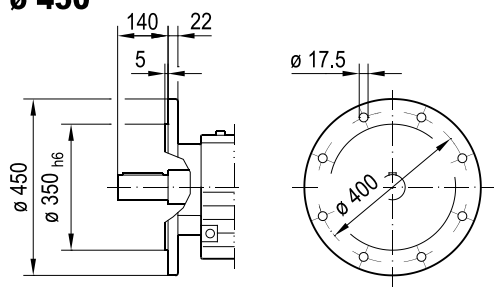

RM107..

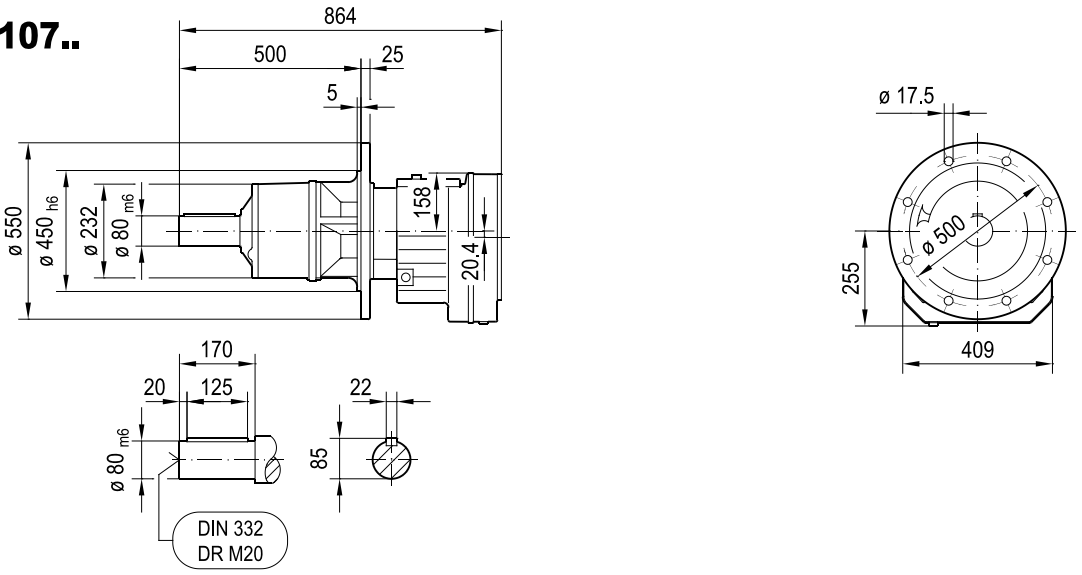

(→ 4.1)	DRN									
	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..
AC	197	197	221	221	261	261	314	357	394	434
AD	157	157	170	170	228	228	253	268	283	305
ADS	158	158	172	172	228	228	253	268	283	305
L	777	827	858	908	926	952	1018	1041	1151	1125
LS	871	921	970	1020	1064	1089	1207	1230	1356	1330
LB	282	332	363	413	431	457	523	546	656	630
LBS	376	426	475	525	569	594	712	735	861	835