




RF127..

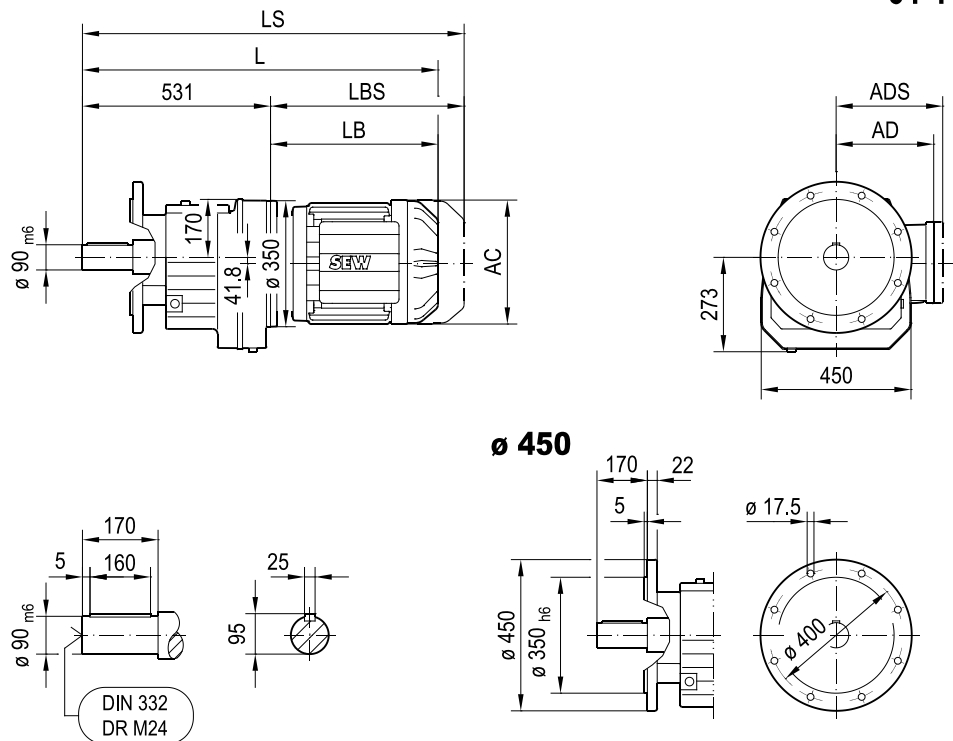

ø 450

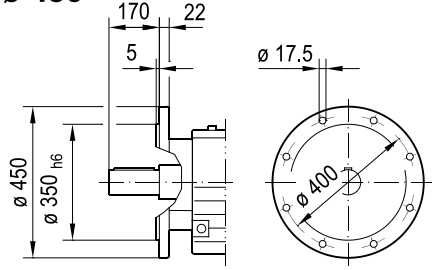

RM127..

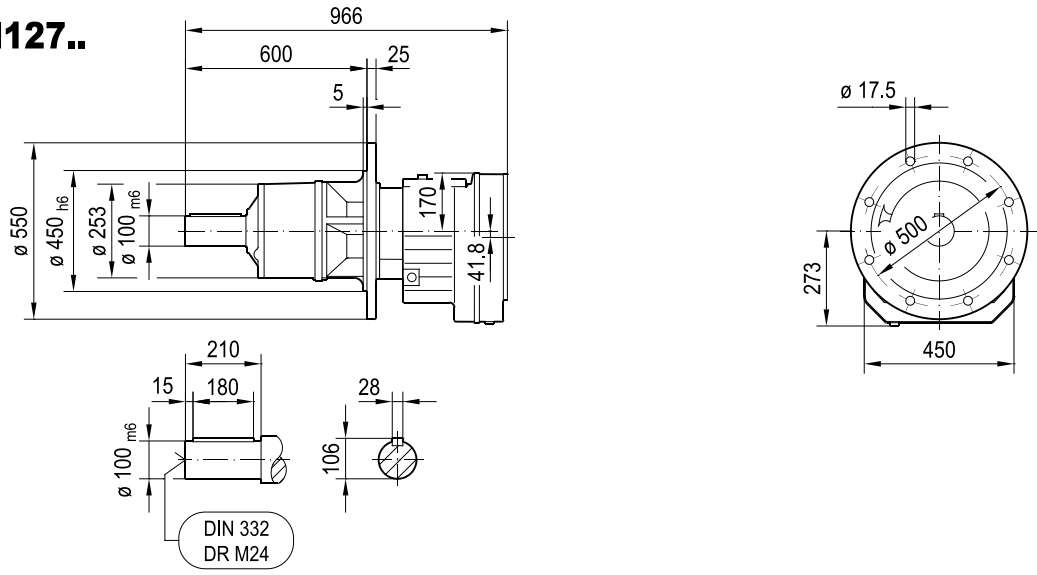

(→ 4.1)	DRN										
	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..	250M
AC	197	197	221	221	261	261	314	357	394	434	495
AD	157	157	170	170	228	228	253	268	283	305	394
ADS	158	158	172	172	228	228	253	268	283	305	394
L	813	863	894	944	962	988	1054	1077	1187	1161	1298
LS	907	957	1006	1056	1100	1125	1243	1266	1392	1366	1538
LB	282	332	363	413	431	457	523	546	656	630	767
LBS	376	426	475	525	569	594	712	735	861	835	1007