




RF137..

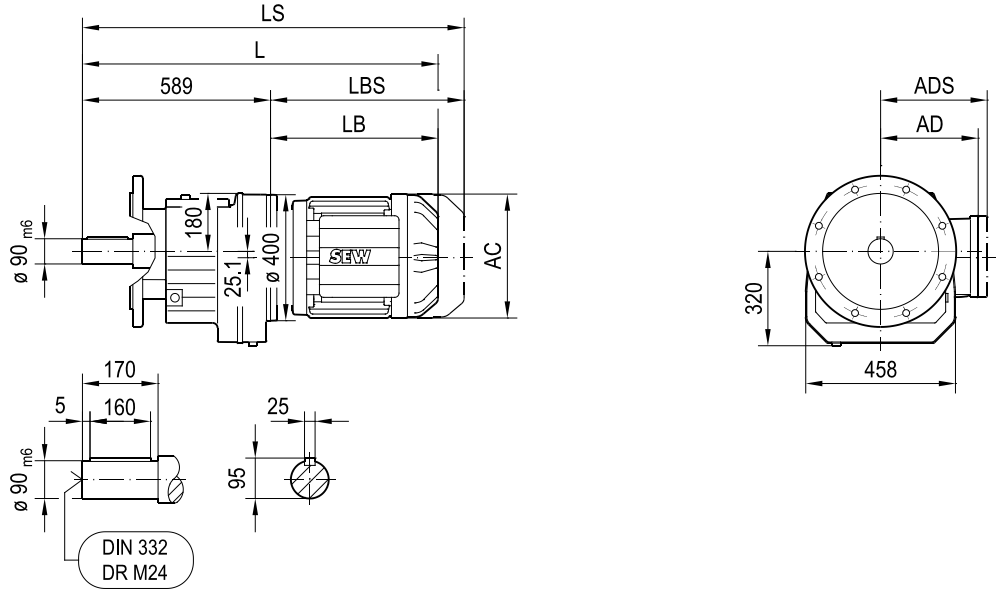


ø 450

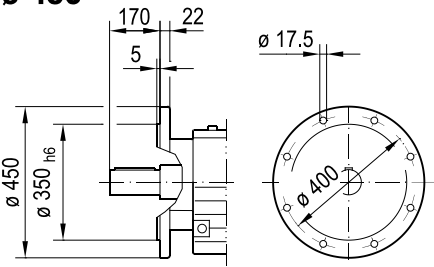

ø 550

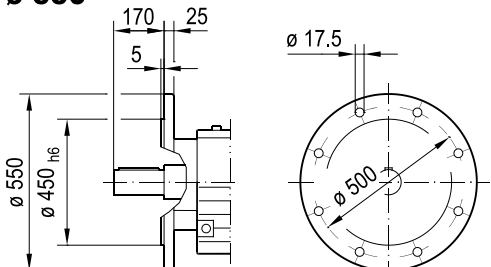

RM137..

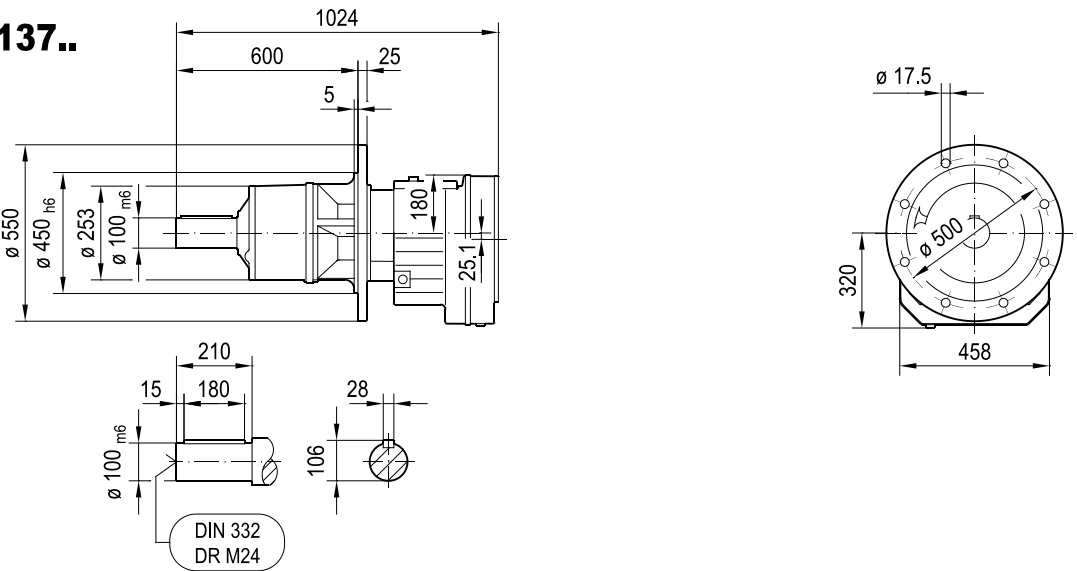

(→ 4.1)	DRN									
	132S	132M	132L	160..	180..	200L	225..	250M	280S	280M
AC	221	261	261	314	357	394	434	495	495	495
AD	170	228	228	253	268	283	305	394	394	394
ADS	172	228	228	253	268	283	305	394	394	394
L	995	1013	1039	1105	1128	1238	1212	1349	1349	1444
LS	1107	1151	1176	1294	1317	1443	1417	1589	1589	1684
LB	406	424	450	516	539	649	623	760	760	855
LBS	518	562	587	705	728	854	828	1000	1000	1095