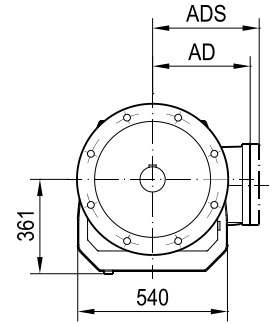
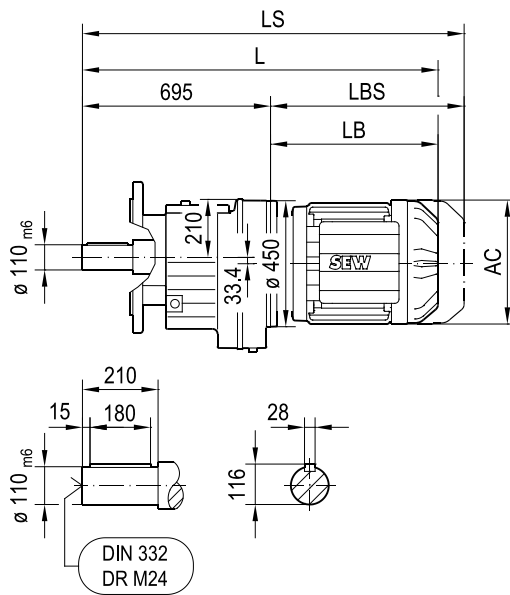
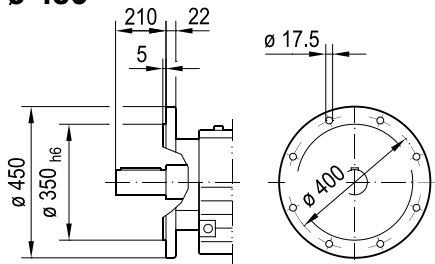
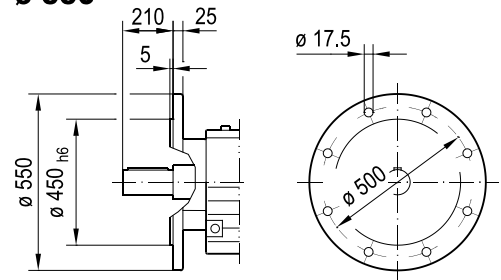
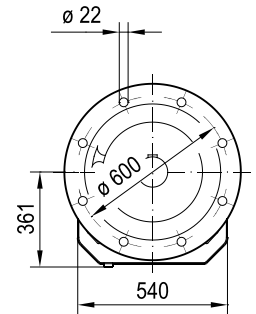
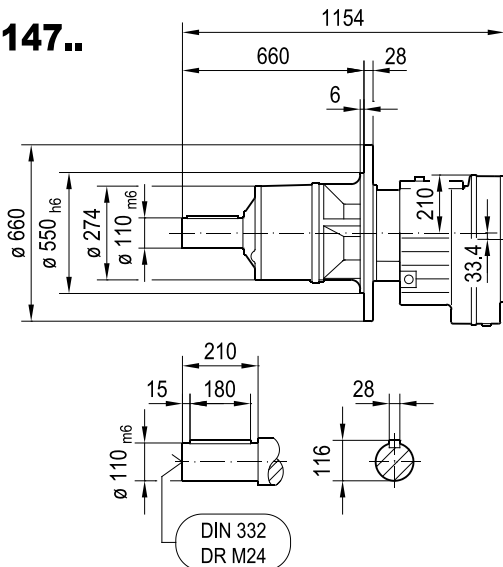


RF147..**ø 450****ø 550****RM147..**

 4.1	DRN							
	132L	160..	180..	200L	225..	250M	280S	280M
AC	261	314	357	394	434	495	495	495
AD	228	253	268	283	305	394	394	394
ADS	228	253	268	283	305	394	394	394
L	1137	1203	1226	1336	1310	1447	1447	1542
LS	1274	1392	1415	1541	1515	1687	1687	1782
LB	442	508	531	641	615	752	752	847
LBS	579	697	720	846	820	992	992	1087