
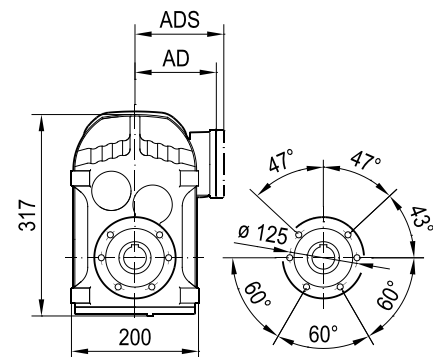


FAZ57..




42 037 00 14

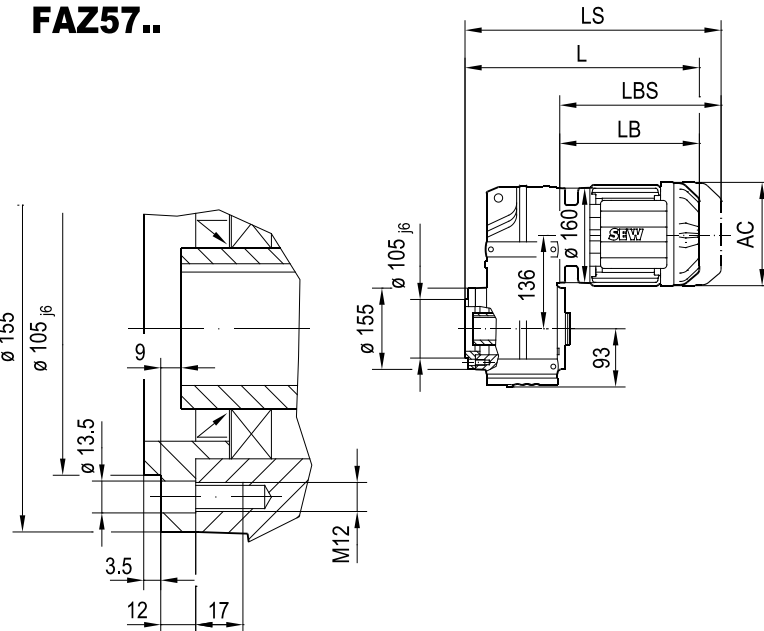

FAZ57..

FHZ57.. max. DRN100L

FVZ57..

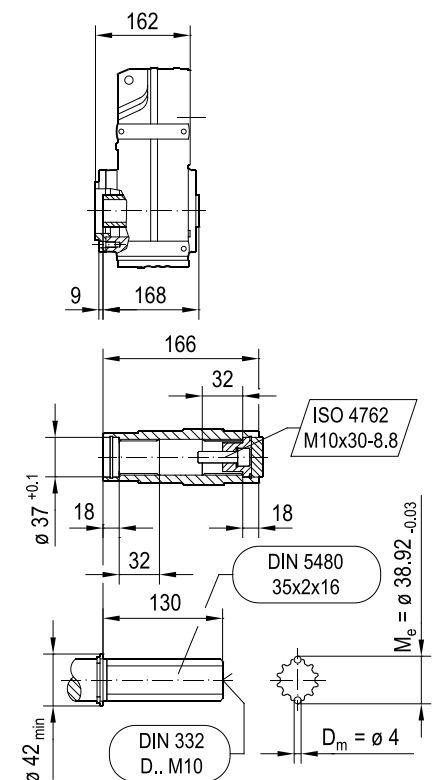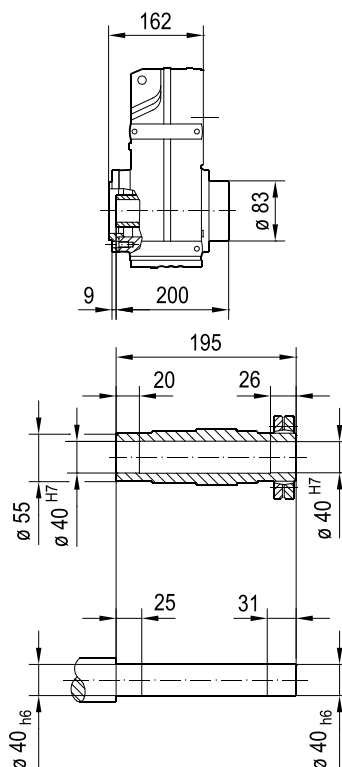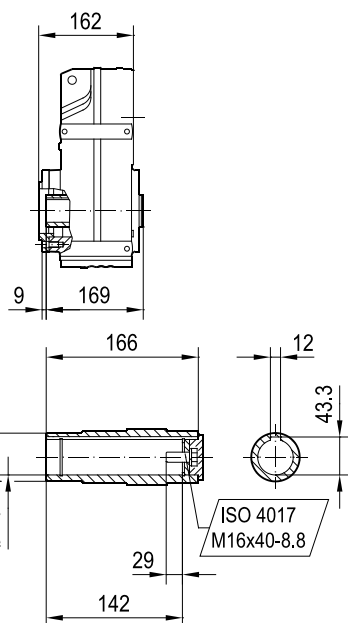

(→ 📖 4.1)	DRN													
	63MS	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M
AC	115	115	139	139	156	156	156	179	179	197	197	221	221	261
AD	98	98	118	118	128	128	128	140	140	157	157	170	170	228
ADS	98	98	129	129	139	139	139	150	150	158	158	172	172	228
L	346	360	361	381	392	409	438	440	472	467	517	548	602	620
LS	402	416	429	449	473	490	519	533	565	561	611	660	714	758
LB	184	198	199	219	230	247	276	278	310	305	355	386	440	458
LBS	240	254	267	287	311	328	357	371	403	399	449	498	552	596