


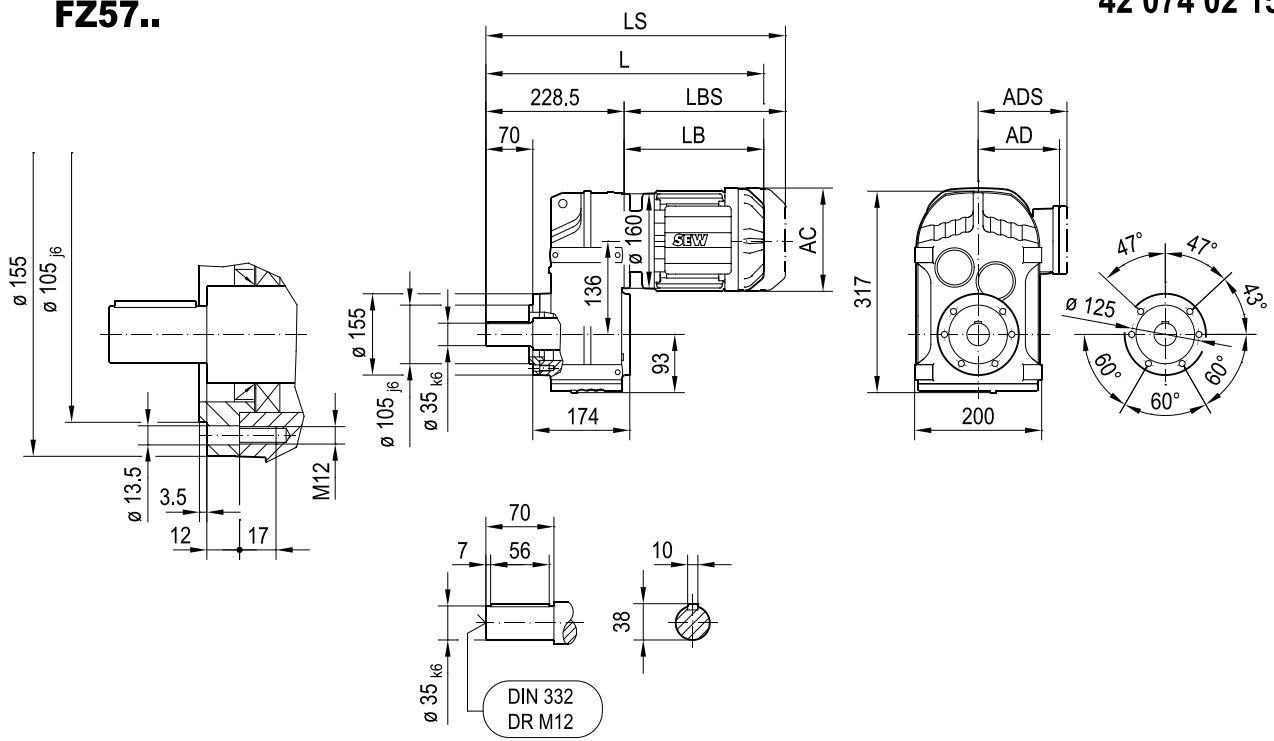

(→ 4.1)	DRN													
	63MS	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M
AC	115	115	139	139	156	156	156	179	179	197	197	221	221	261
AD	98	98	118	118	128	128	128	140	140	157	157	170	170	228
ADS	98	98	129	129	139	139	139	150	150	158	158	172	172	228
L	412	426	428	448	459	476	505	506	538	534	584	615	669	687
LS	468	482	495	515	540	557	586	600	632	627	677	727	781	824
LB	184	198	199	219	230	247	276	278	310	305	355	386	440	458
LBS	240	254	267	287	311	328	357	371	403	399	449	498	552	596