
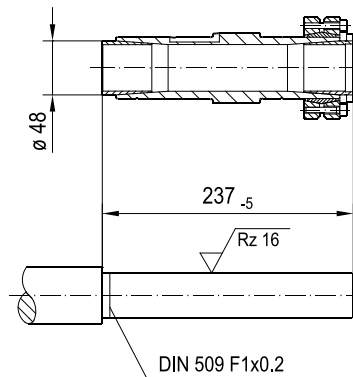


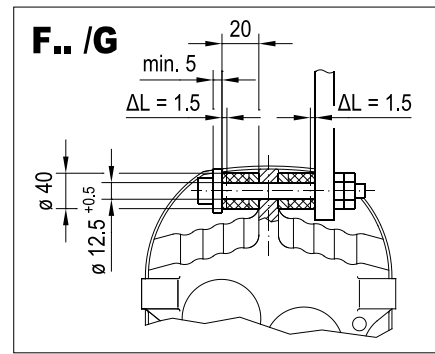

(→ 📖 4.1)	DRN									
	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM
AC	115	139	139	156	156	156	179	179	197	197
AD	98	118	118	128	128	128	140	140	157	157
ADS	98	129	129	139	139	139	150	150	158	158
L	379	380	400	411	428	457	459	491	486	536
LS	435	448	468	492	509	538	552	584	580	630
LB	198	199	219	230	247	276	278	310	305	355
LBS	254	267	287	311	328	357	371	403	399	449