
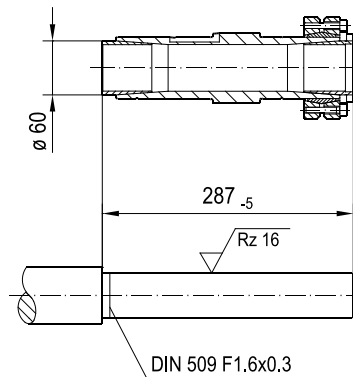


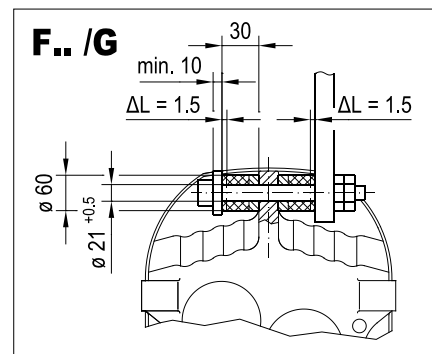

(→ 📖 4.1)	DRN												
	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L
AC	139	139	156	156	156	179	179	197	197	221	221	261	261
AD	118	118	128	128	128	140	140	157	157	170	170	228	228
ADS	129	129	139	139	139	150	150	158	158	172	172	228	228
L	408	428	439	456	485	487	519	514	564	595	645	663	689
LS	476	496	520	537	566	580	612	608	658	707	757	801	826
LB	192	212	223	240	269	271	303	298	348	379	429	447	473
LBS	260	280	304	321	350	364	396	392	442	491	541	585	610