

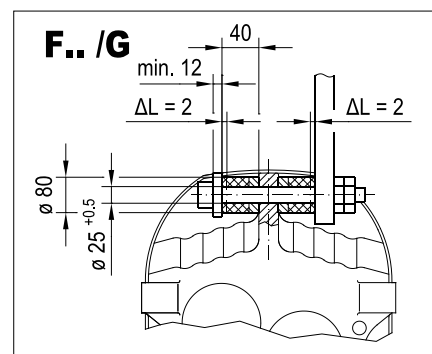


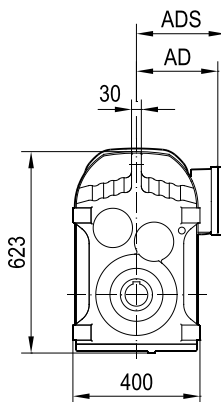

FH97..

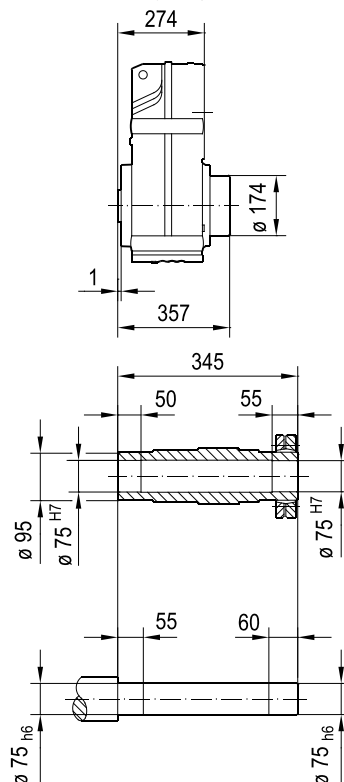

(→ 🏠 4.1)	DRN												
	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..
AC	156	179	179	197	197	221	221	261	261	314	357	394	434
AD	128	140	140	157	157	170	170	228	228	253	268	283	305
ADS	139	150	150	158	158	172	172	228	228	253	268	283	305
L	533	535	567	562	612	643	693	711	737	803	826	936	910
LS	614	628	660	656	706	755	805	849	874	992	1015	1141	1115
LB	259	261	293	288	338	369	419	437	463	529	552	662	636
LBS	340	354	386	382	432	481	531	575	600	718	741	867	841