
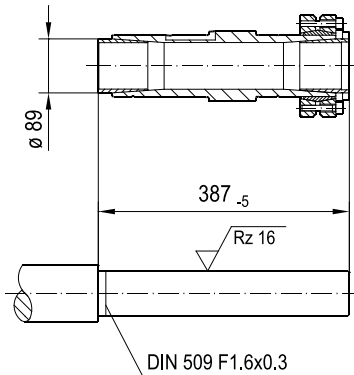
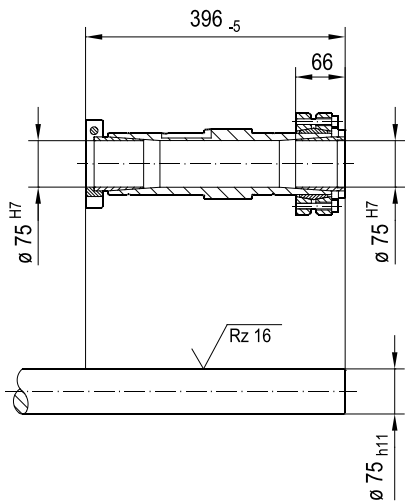
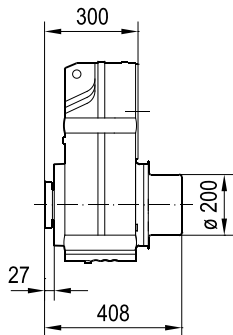
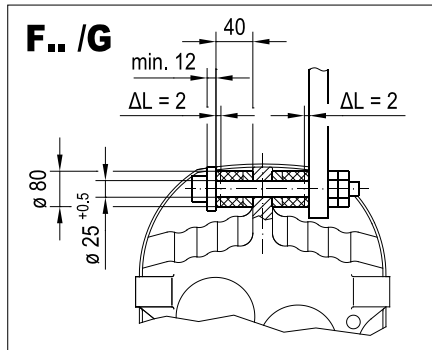
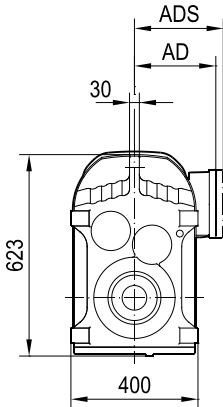


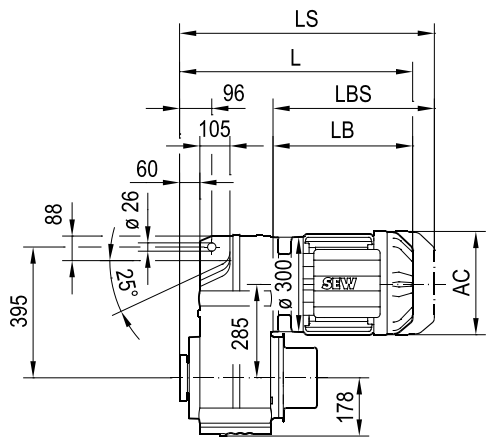

(→ 4.1)	DRN										
	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..
AC	156	179	179	197	197	221	221	261	261	314	357
AD	128	140	140	157	157	170	170	228	228	253	268
ADS	139	150	150	158	158	172	172	228	228	253	268
L	559	561	593	588	638	669	719	737	763	829	852
LS	640	654	686	682	732	781	831	875	900	1018	1041
LB	259	261	293	288	338	369	419	437	463	529	552
LBS	340	354	386	382	432	481	531	575	600	718	741