



FM107..

42 116 00 17

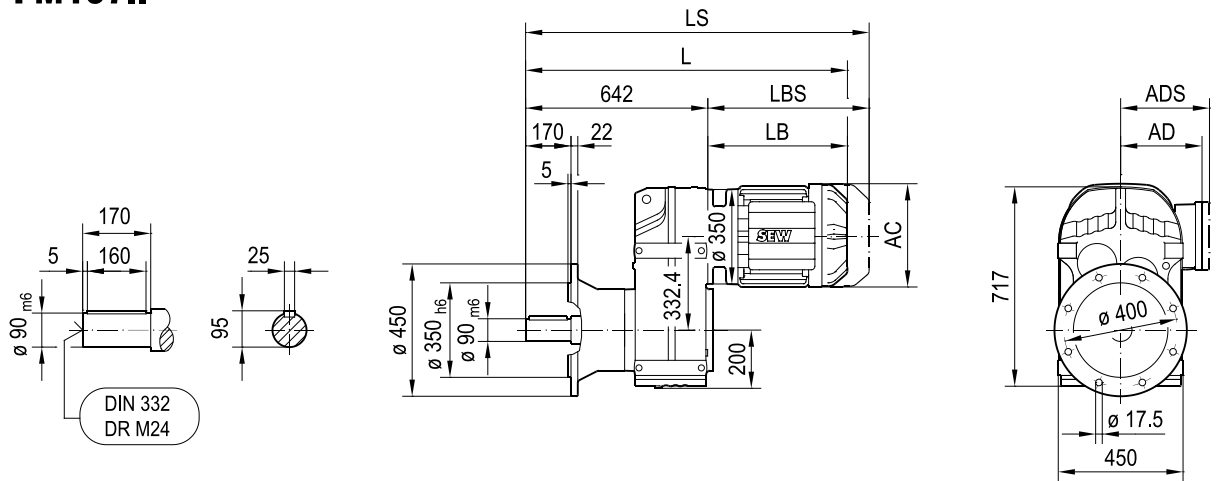

FAM107..

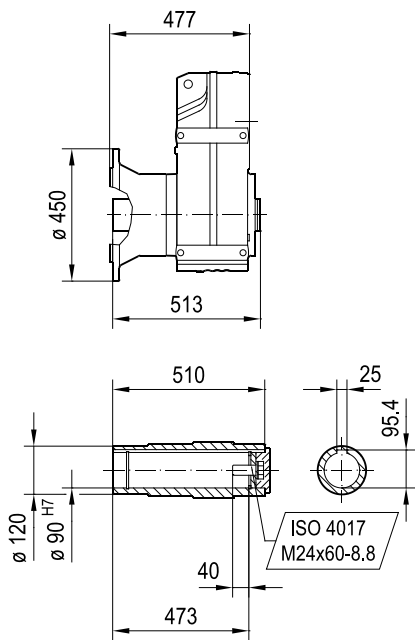

( 4.1)	DRN										
	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..	250M
AC	197	197	221	221	261	261	314	357	394	434	495
AD	157	157	170	170	228	228	253	268	283	305	394
ADS	158	158	172	172	228	228	253	268	283	305	394
L	924	974	1005	1055	1073	1099	1165	1188	1298	1272	1409
LS	1018	1068	1117	1167	1211	1236	1354	1377	1503	1477	1649
LB	282	332	363	413	431	457	523	546	656	630	767
LBS	376	426	475	525	569	594	712	735	861	835	1007