




FAZ127..

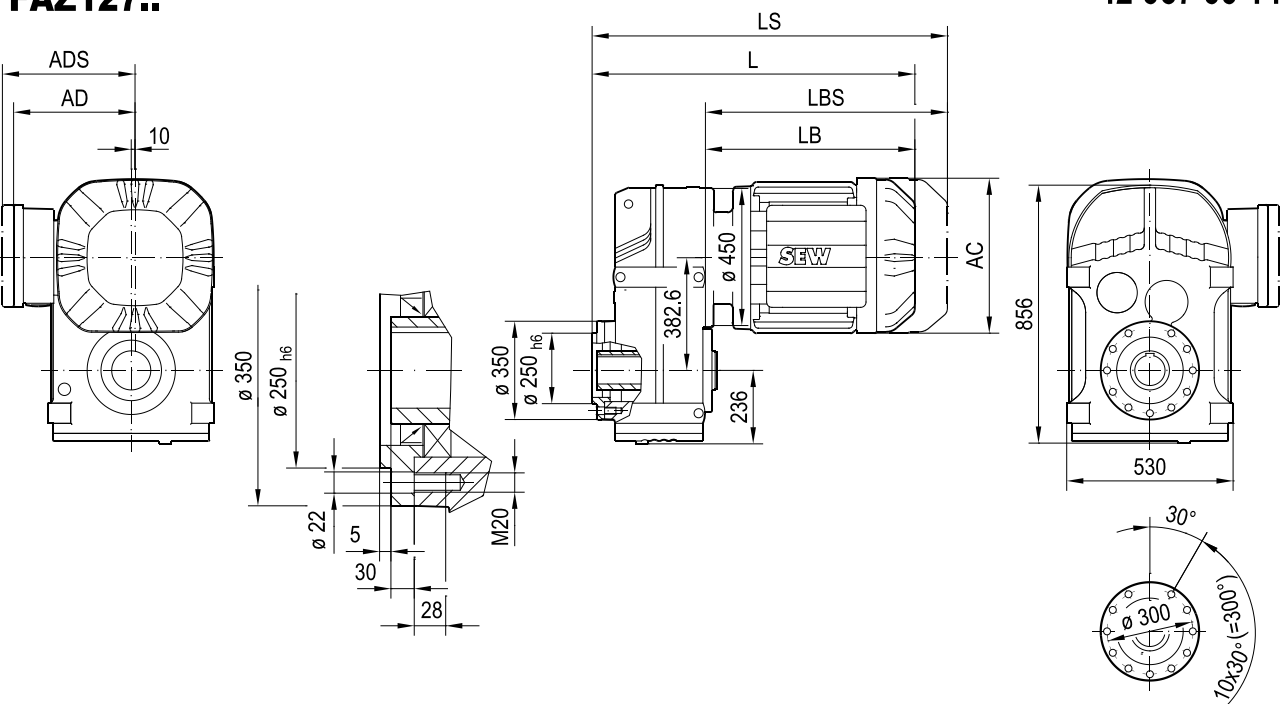

FAZ127..

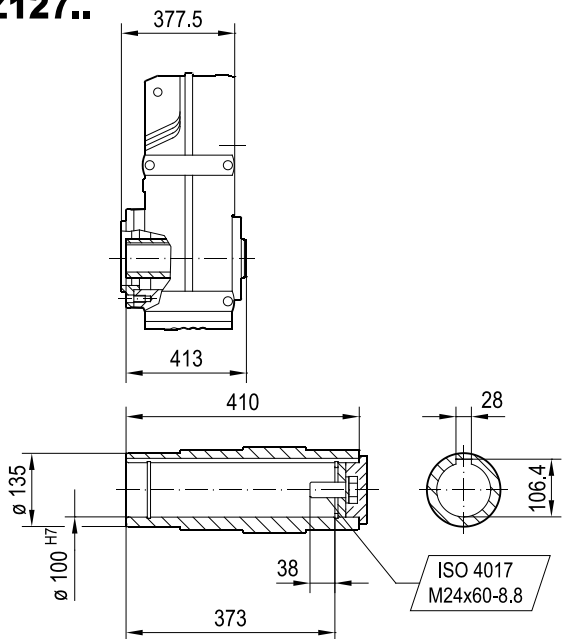

FHZ127..

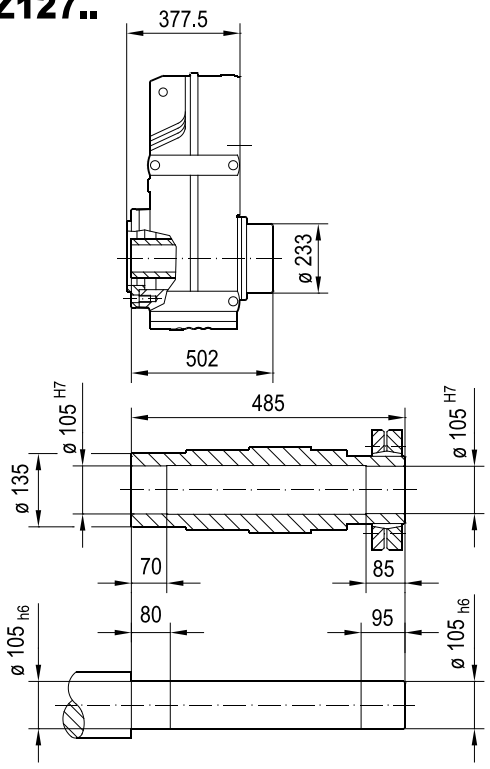

(→ 4.1)	DRN									
	132S	132M	132L	160..	180..	200L	225..	250M	280S	280M
AC	221	261	261	314	357	394	434	495	495	495
AD	170	228	228	253	268	283	305	394	394	394
ADS	172	228	228	253	268	283	305	394	394	394
L	776	794	819	886	909	1018	993	1130	1130	1225
LS	888	931	956	1075	1098	1223	1198	1370	1370	1465
LB	398	416	442	508	531	641	615	752	752	847
LBS	510	554	579	697	720	846	820	992	992	1087