


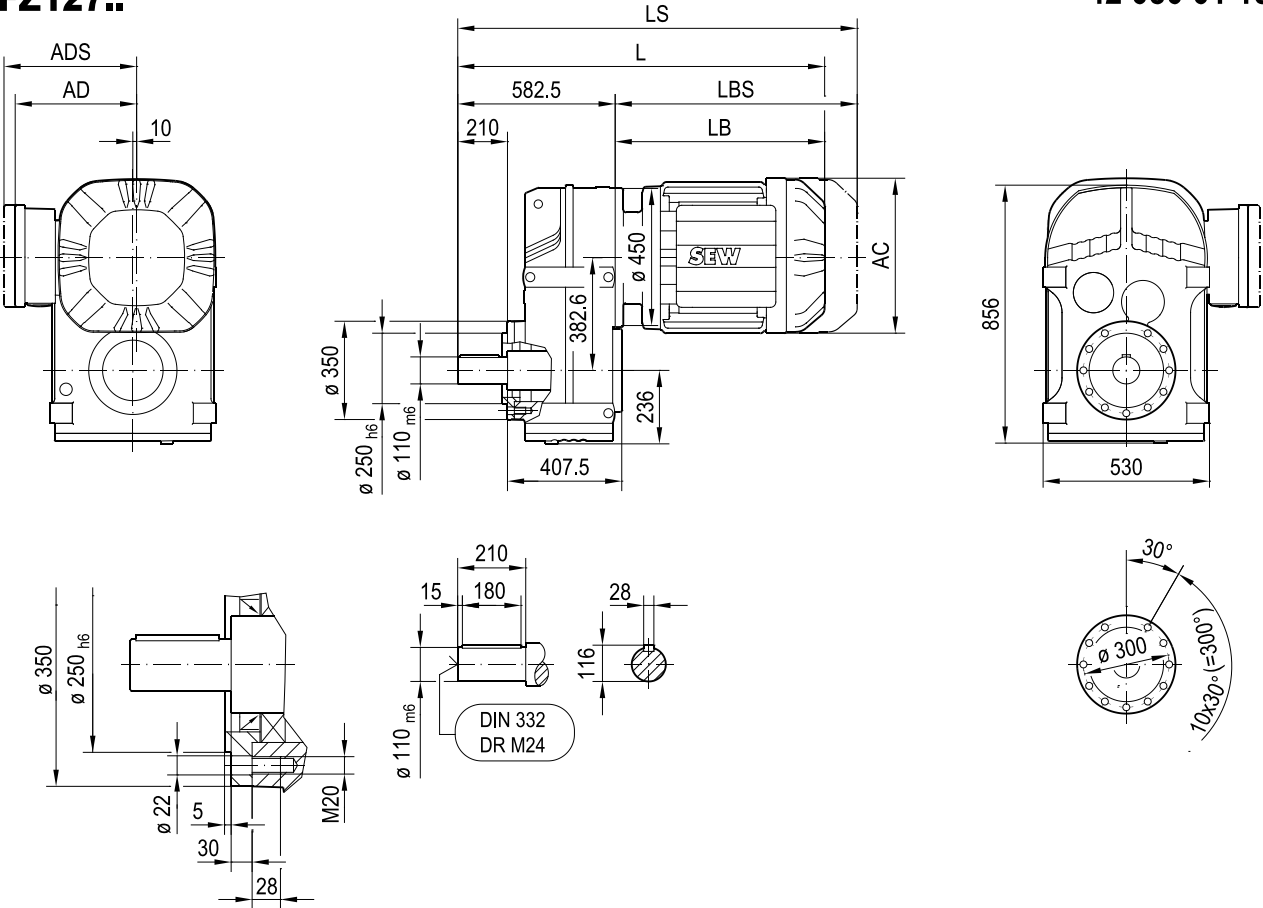

(→ 4.1)	DRN									
	132S	132M	132L	160..	180..	200L	225..	250M	280S	280M
AC	221	261	261	314	357	394	434	495	495	495
AD	170	228	228	253	268	283	305	394	394	394
ADS	172	228	228	253	268	283	305	394	394	394
L	981	999	1024	1091	1114	1223	1198	1335	1335	1430
LS	1093	1136	1161	1280	1303	1428	1403	1575	1575	1670
LB	398	416	442	508	531	641	615	752	752	847
LBS	510	554	579	697	720	846	820	992	992	1087