


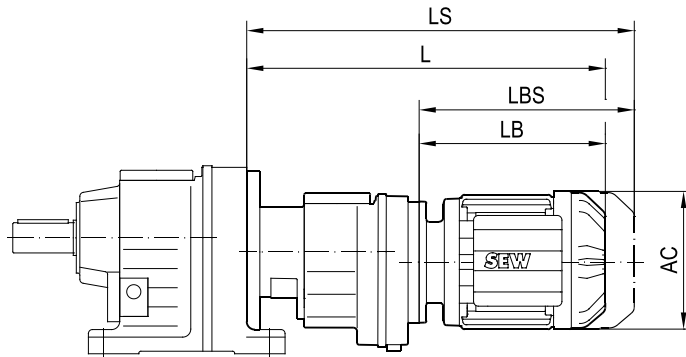

(→ 4.1)	AC	L	LS	LB	LBS
R..27R17 DRN63MS	115	323	379	190	246
R..27R17 DRN63M	115	337	393	204	260
R..27R17 DRN71MS	139	339	406	206	273
R..27R17 DRN71M	139	359	426	226	293
R..37R17 DRN63MS	115	323	379	190	246
R..37R17 DRN63M	115	337	393	204	260
R..37R17 DRN71MS	139	339	406	206	273
R..37R17 DRN71M	139	359	426	226	293
R..37R17 DRN80MK	156	370	451	237	318
R..47R37 DRN63MS	115	355	411	190	246
R..47R37 DRN63M	115	369	425	204	260
R..47R37 DRN71MS	139	371	438	206	273
R..47R37 DRN71M	139	391	458	226	293
R..47R37 DRN80MK	156	402	483	237	318
R..47R37 DRN80M	156	448	529	283	364
R..57R37 DRN63MS	115	355	411	190	246
R..57R37 DRN63M	115	369	425	204	260
R..57R37 DRN71MS	139	371	438	206	273
R..57R37 DRN71M	139	391	458	226	293
R..57R37 DRN80MK	156	402	483	237	318
R..57R37 DRN80M	156	448	529	283	364
R..67R37 DRN63MS	115	355	411	190	246
R..67R37 DRN63M	115	369	425	204	260
R..67R37 DRN71MS	139	371	438	206	273
R..67R37 DRN71M	139	391	458	226	293
R..67R37 DRN80MK	156	402	483	237	318
R..67R37 DRN80M	156	448	529	283	364
R..67R37 DRN90S	179	449	543	284	378
R..77R37 DRN63M	115	361	417	204	260
R..77R37 DRN71MS	139	363	430	206	273
R..77R37 DRN71M	139	383	450	226	293
R..77R37 DRN80MK	156	394	475	237	318
R..77R37 DRN80M	156	440	521	283	364
R..77R37 DRN90S	179	441	535	284	378
R..77R37 DRN90L	179	473	567	316	410
R..87R57 DRN80MK	156	458	539	230	311
R..87R57 DRN80M	156	504	585	276	357
R..87R57 DRN90S	179	505	599	278	371
R..87R57 DRN90L	179	537	631	310	403
R..87R57 DRN100L/LM	197	583	676	355	449
R..97R57 DRN80MK	156	453	534	230	311
R..97R57 DRN80M	156	499	580	276	357
R..97R57 DRN90S	179	500	594	278	371
R..97R57 DRN90L	179	532	626	310	403
R..97R57 DRN100LS	197	528	621	305	399
R..97R57 DRN100L/LM	197	578	671	355	449

	AC	L	LS	LB	LBS
R..107R77 DRN100LS	197	545	639	298	392
R..107R77 DRN100L/LM	197	595	689	348	442
R..107R77 DRN112M	221	626	738	379	491
R..107R77 DRN132S	221	676	788	429	541
R..127R77 DRN100LS	197	545	639	298	392
R..127R77 DRN100L/LM	197	595	689	348	442
R..127R77 DRN112M	221	626	738	379	491
R..127R77 DRN132S	221	676	788	429	541
R..127R77 DRN132M	261	694	832	447	585
R..127R77 DRN132L	261	720	857	473	610
R..127R77 DRN160..	314	786	975	539	728
R..137R77 DRN132S	221	669	781	429	541
R..137R77 DRN132M	261	687	825	447	585
R..137R77 DRN132L	261	713	850	473	610
R..147R87 DRN132L	261	748	885	468	605
R..147R87 DRN160..	314	814	1003	534	723
R..147R87 DRN180..	357	837	1026	557	746
R..167R97 DRN132L	261	788	925	463	600
R..167R97 DRN160..	314	854	1043	529	718
R..167R107 DRN132L	261	839	976	457	594
R..167R107 DRN160..	314	905	1094	523	712
R..167R107 DRN180..	357	928	1117	546	735
R..167R107 DRN200L	394	1038	1243	656	861