

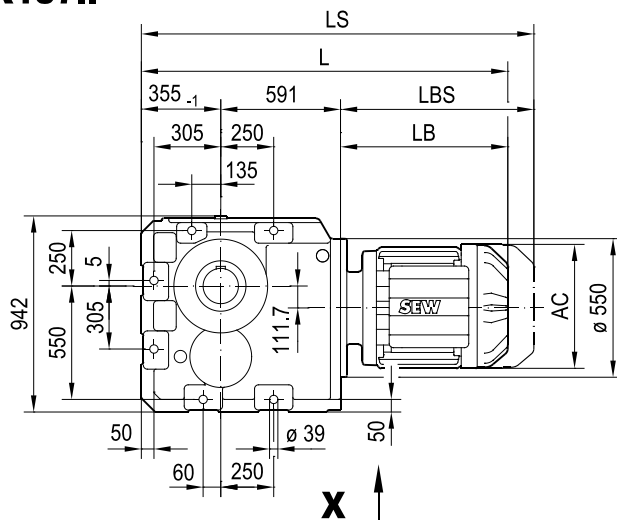
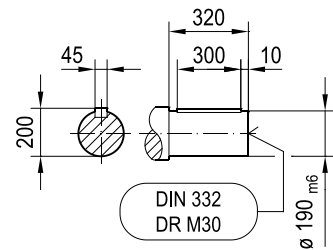




K187..

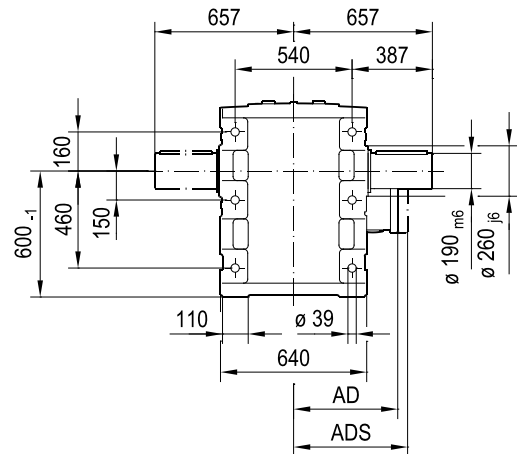

X

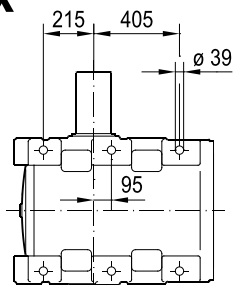

KH187B..

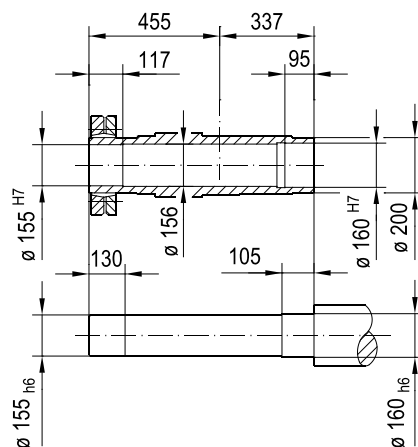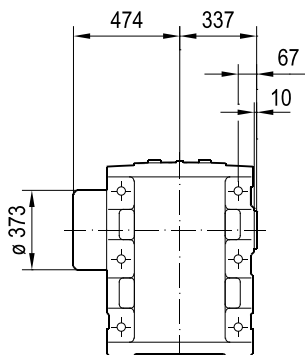

(→ 📖 4.1)	DRN								
	160..	180..	200L	225..	250M	280S	280M	315S-M	315ME-H
AC	314	357	394	434	495	495	495	624	624
AD	253	268	283	305	394	394	394	506	506
ADS	253	268	283	305	394	394	394	506	506
L	1446	1469	1579	1553	1690	1690	1785	1887	2017
LS	1635	1658	1784	1758	1930	1930	2025	2138	2268
LB	500	523	633	607	744	744	839	941	1071
LBS	689	712	838	812	984	984	1079	1192	1322