




### SAZ77/SAZ77p..

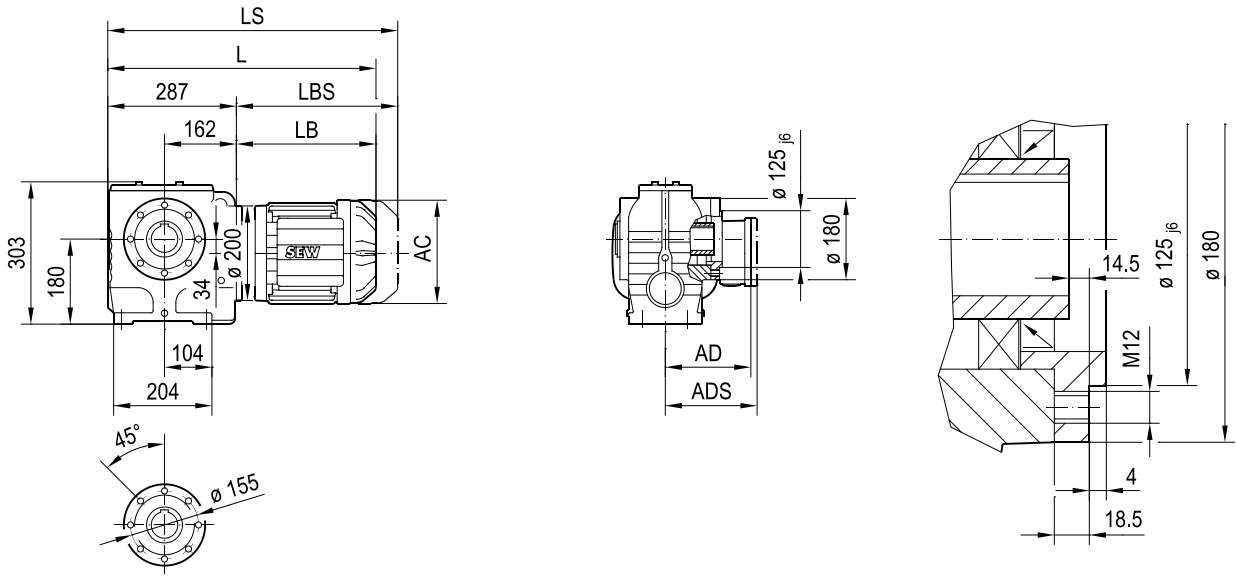


### SAZ77/SAZ77p..

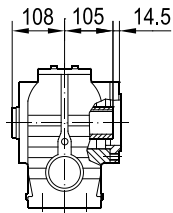



### SHZ77/SHZ77p..

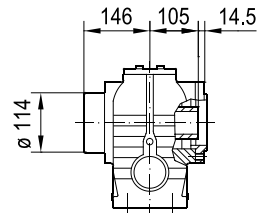

#### ø 60 H7

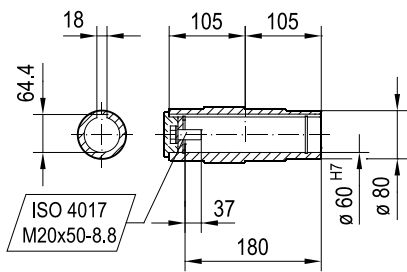

#### ø 50 H7

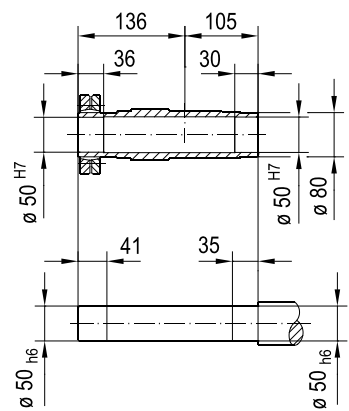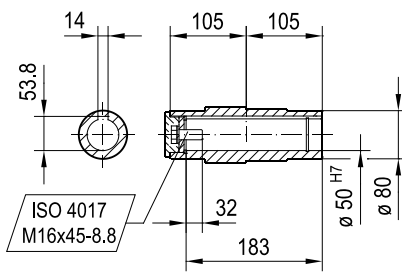

(→ 4.1)	DRN												
	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..
AC	139	156	156	156	179	179	197	197	221	221	261	261	314
AD	118	128	128	128	140	140	157	157	170	170	228	228	253
ADS	129	139	139	139	150	150	158	158	172	172	228	228	253
L	499	510	527	556	558	590	585	635	666	716	734	760	826
LS	567	591	608	637	651	683	679	729	778	828	872	897	1015
LB	212	223	240	269	271	303	298	348	379	429	447	473	539
LBS	280	304	321	350	364	396	392	442	491	541	585	610	728