








KAZ37..

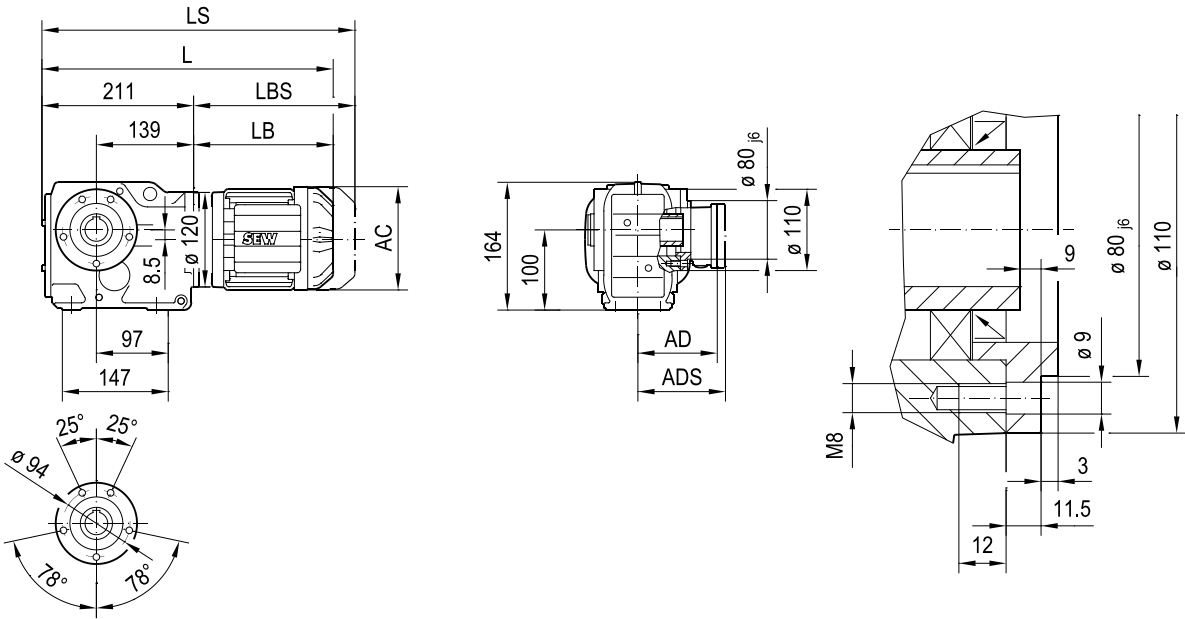

KAZ37..

KHZ37..

KVZ37..

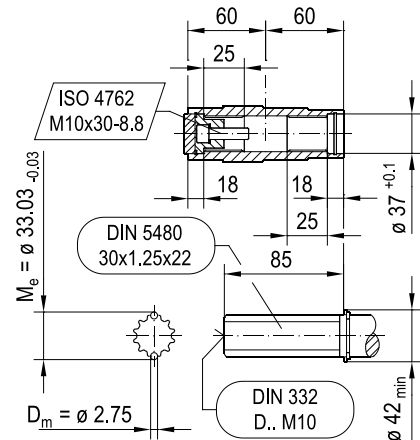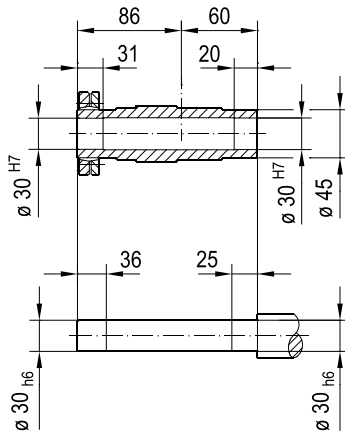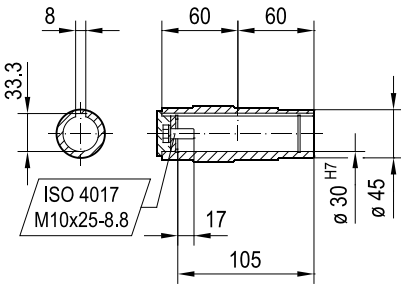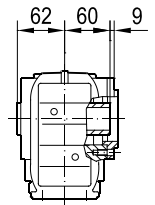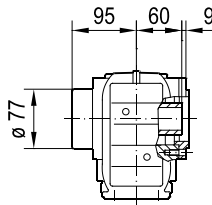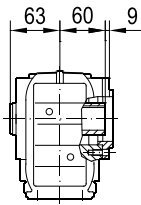

(-> 4.1)	DRN										
	63MS	63M	71MS	71M	80MK	80MS	80M	90S	90L	100LS	100L/LM
AC	115	115	139	139	156	156	156	179	179	197	197
AD	98	98	118	118	128	128	128	140	140	157	157
ADS	98	98	129	129	139	139	139	150	150	158	158
L	401	415	417	437	448	465	494	495	527	525	575
LS	457	471	484	504	529	546	575	589	621	619	669
LB	190	204	206	226	237	254	283	284	316	314	364
LBS	246	260	273	293	318	335	364	378	410	408	458