




K87..

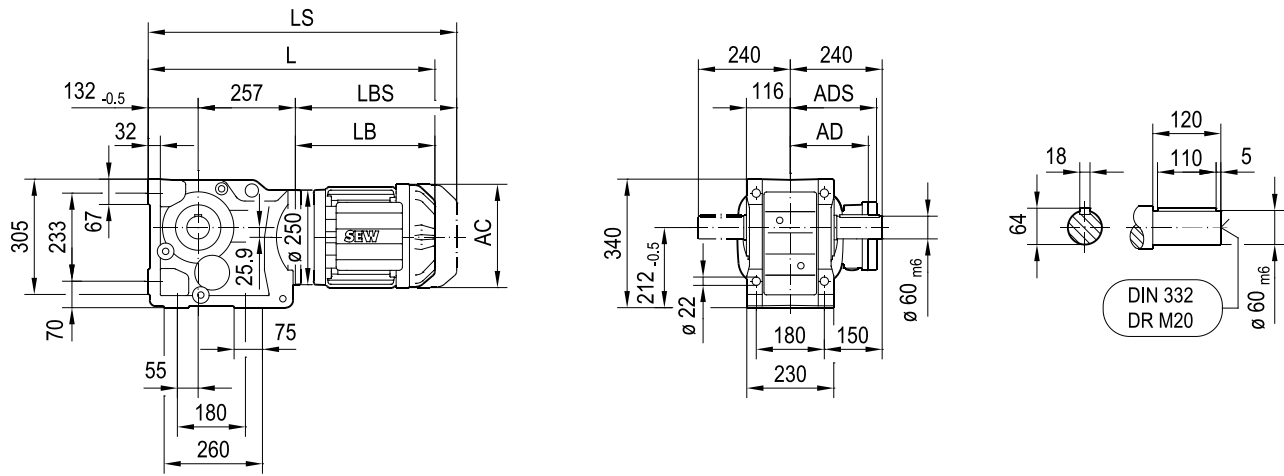





KA87B..

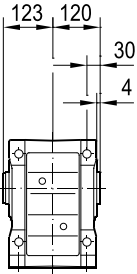

KH87B..

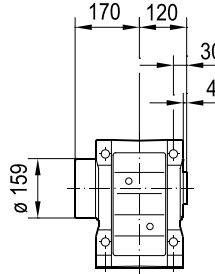

KV87B..

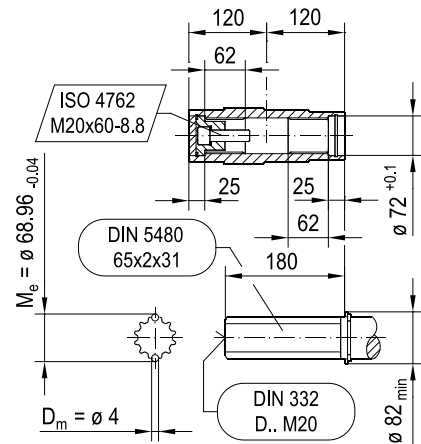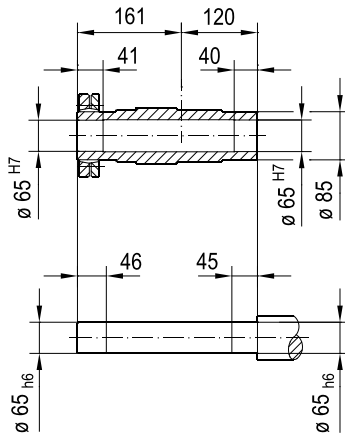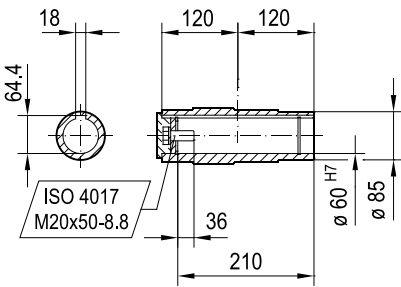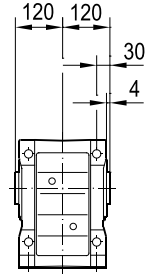

(→ 4.1)	DRN												
	80MK	80M	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L
AC	156	156	179	179	197	197	221	221	261	261	314	357	394
AD	128	128	140	140	157	157	170	170	228	228	253	268	283
ADS	139	139	150	150	158	158	172	172	228	228	253	268	283
L	607	653	655	687	682	732	763	813	831	857	923	946	1056
LS	688	734	748	780	776	826	875	925	969	994	1112	1135	1261
LB	218	264	266	298	293	343	374	424	442	468	534	557	667
LBS	299	345	359	391	387	437	486	536	580	605	723	746	872