



KAZ97..

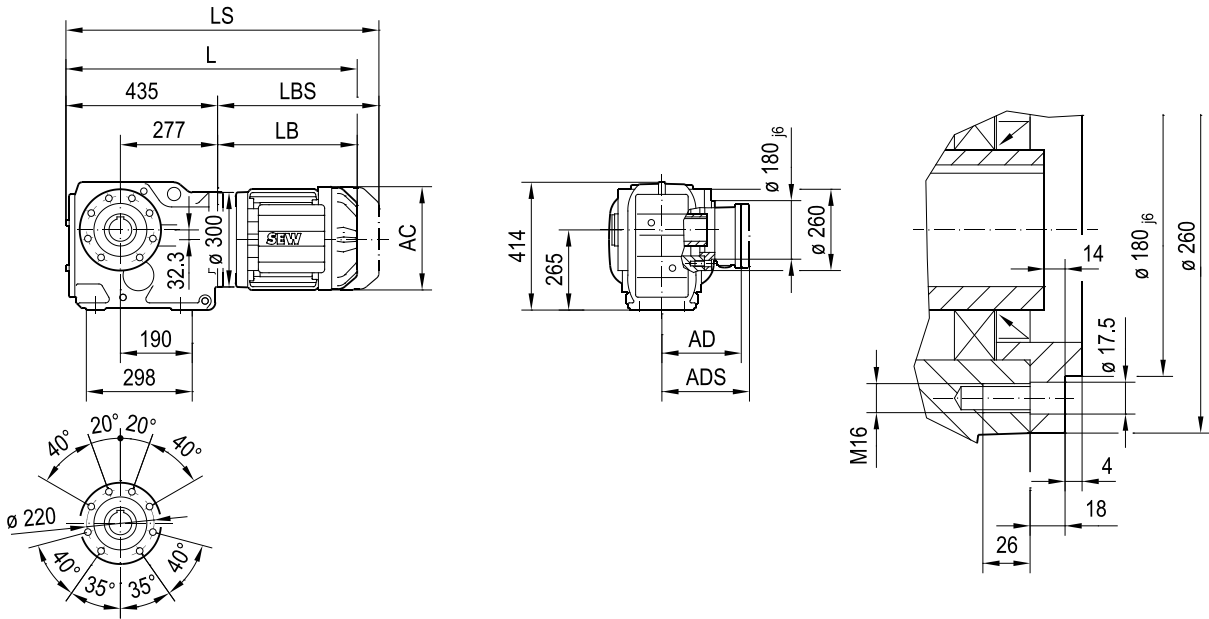

KAZ97..

KHZ97..

KVZ97..

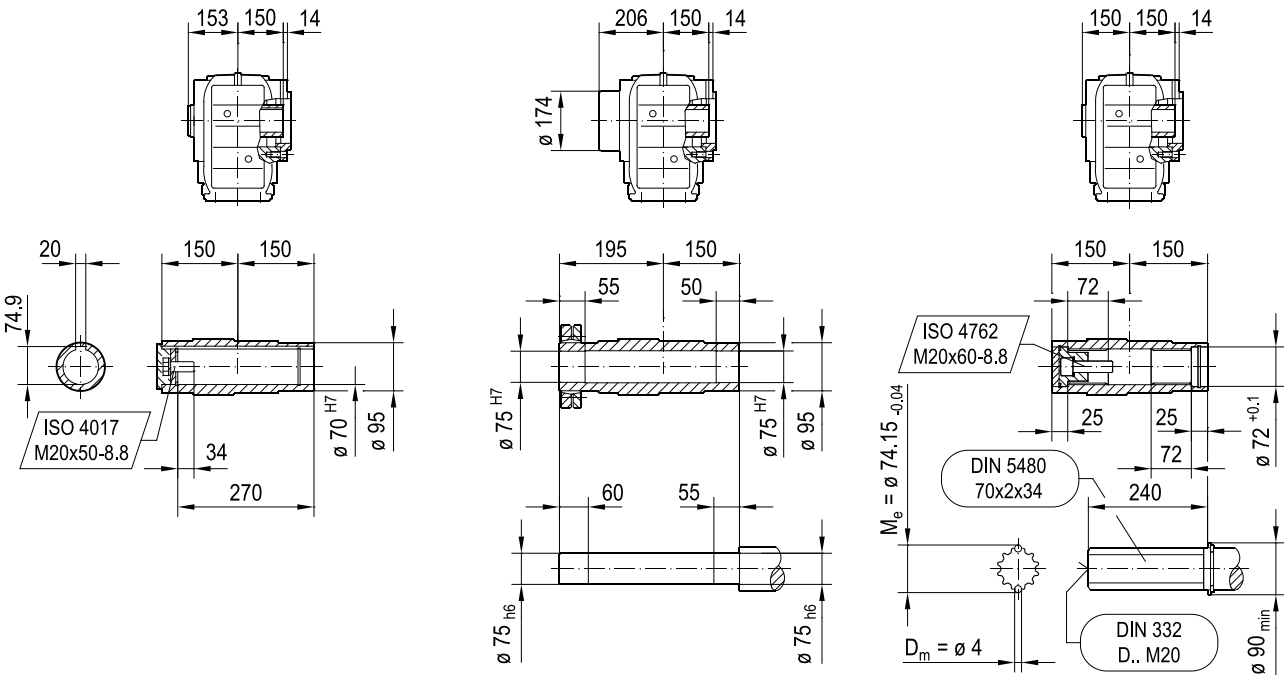

(-> 4.1)	DRN											
	90S	90L	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..
AC	179	179	197	197	221	221	261	261	314	357	394	434
AD	140	140	157	157	170	170	228	228	253	268	283	305
ADS	150	150	158	158	172	172	228	228	253	268	283	305
L	696	728	723	773	804	854	872	898	964	987	1097	1071
LS	789	821	817	867	916	966	1010	1035	1153	1176	1302	1276
LB	261	293	288	338	369	419	437	463	529	552	662	636
LBS	354	386	382	432	481	531	575	600	718	741	867	841