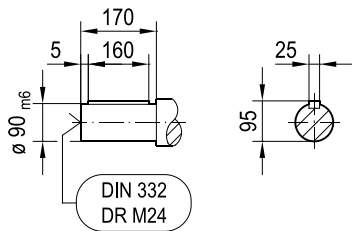
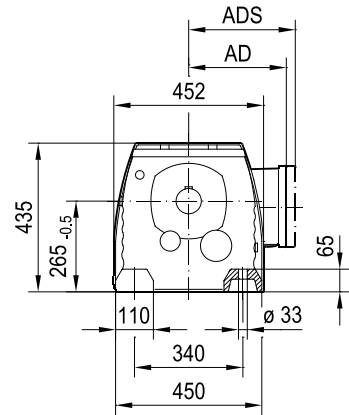
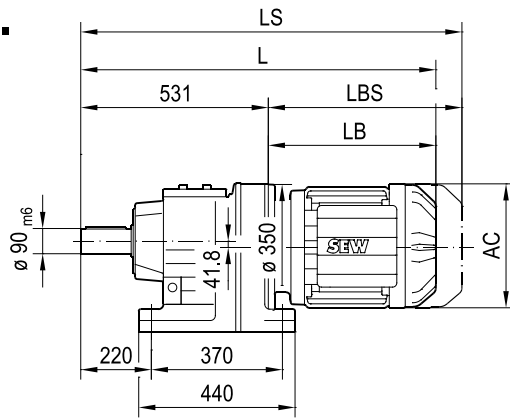



**R127..**

(→  4.1)	DRN										
	100LS	100L/LM	112M	132S	132M	132L	160..	180..	200L	225..	250M
<b>AC</b>	197	197	221	221	261	261	314	357	394	434	495
<b>AD</b>	157	157	170	170	228	228	253	268	283	305	394
<b>ADS</b>	158	158	172	172	228	228	253	268	283	305	394
<b>L</b>	813	863	894	944	962	988	1054	1077	1187	1161	1298
<b>LS</b>	907	957	1006	1056	1100	1125	1243	1266	1392	1366	1538
<b>LB</b>	282	332	363	413	431	457	523	546	656	630	767
<b>LBS</b>	376	426	475	525	569	594	712	735	861	835	1007