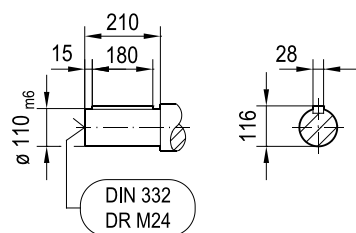
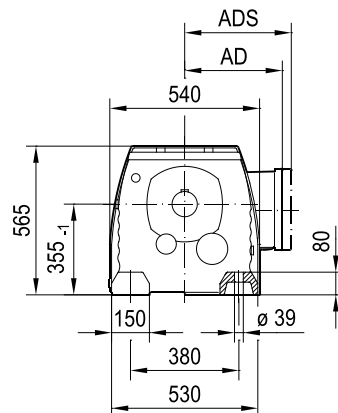
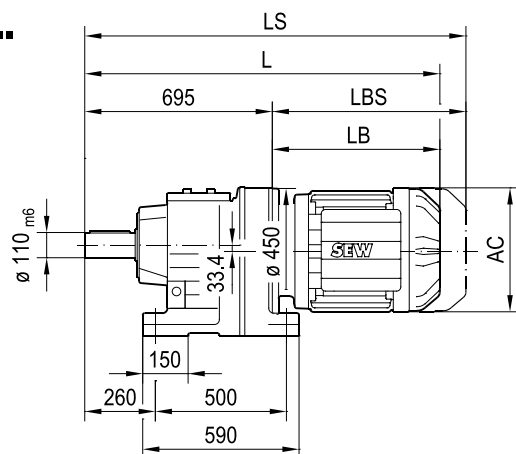


**R147..**

(> 4.1)	DRN							
	132L	160..	180..	200L	225..	250M	280S	280M
<b>AC</b>	261	314	357	394	434	495	495	495
<b>AD</b>	228	253	268	283	305	394	394	394
<b>ADS</b>	228	253	268	283	305	394	394	394
<b>L</b>	1137	1203	1226	1336	1310	1447	1447	1542
<b>LS</b>	1274	1392	1415	1541	1515	1687	1687	1782
<b>LB</b>	442	508	531	641	615	752	752	847
<b>LBS</b>	579	697	720	846	820	992	992	1087