




FF127..

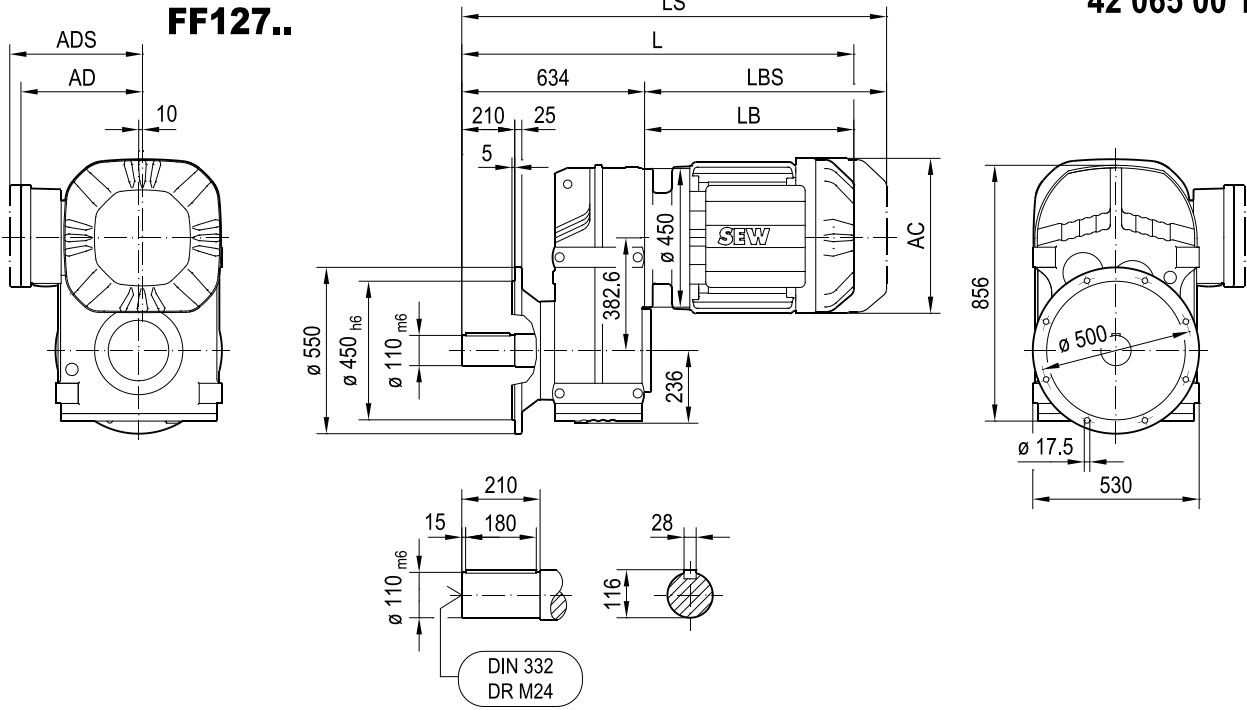

FAF127..

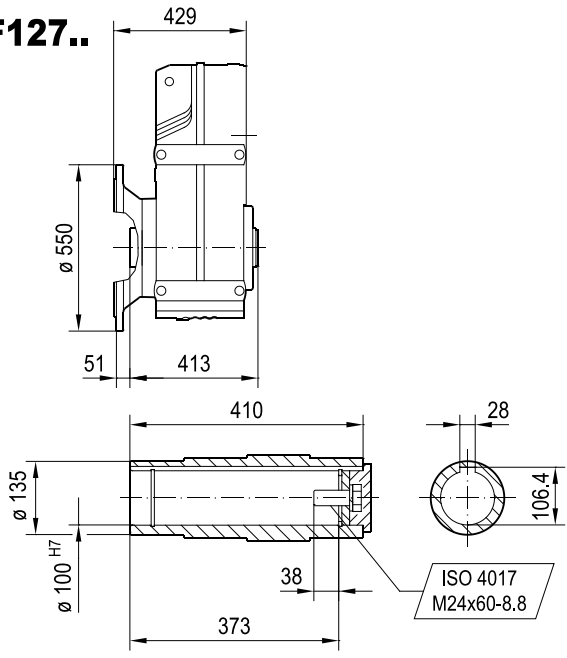

FHF127..

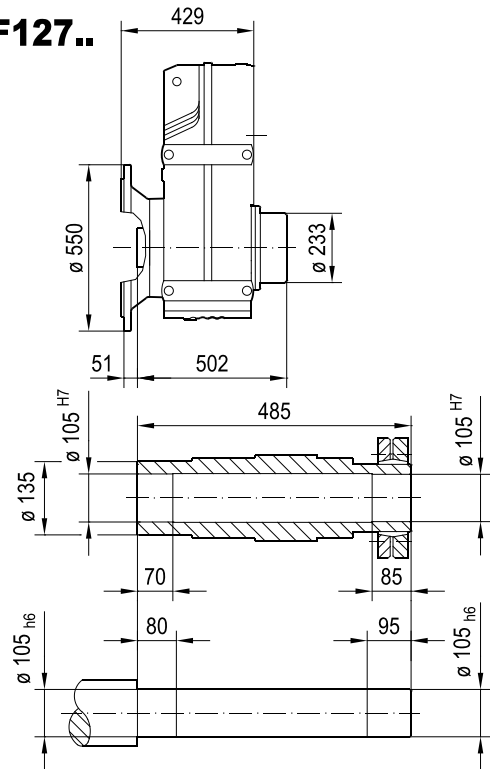

(-) 4.1	DRN									
	132S	132M	132L	160..	180..	200L	225..	250M	280S	280M
AC	221	261	261	314	357	394	434	495	495	495
AD	170	228	228	253	268	283	305	394	394	394
ADS	172	228	228	253	268	283	305	394	394	394
L	1032	1050	1076	1142	1165	1275	1249	1386	1386	1481
LS	1144	1188	1213	1331	1354	1480	1454	1626	1626	1721
LB	398	416	442	508	531	641	615	752	752	847
LBS	510	554	579	697	720	846	820	992	992	1087