




FF157..

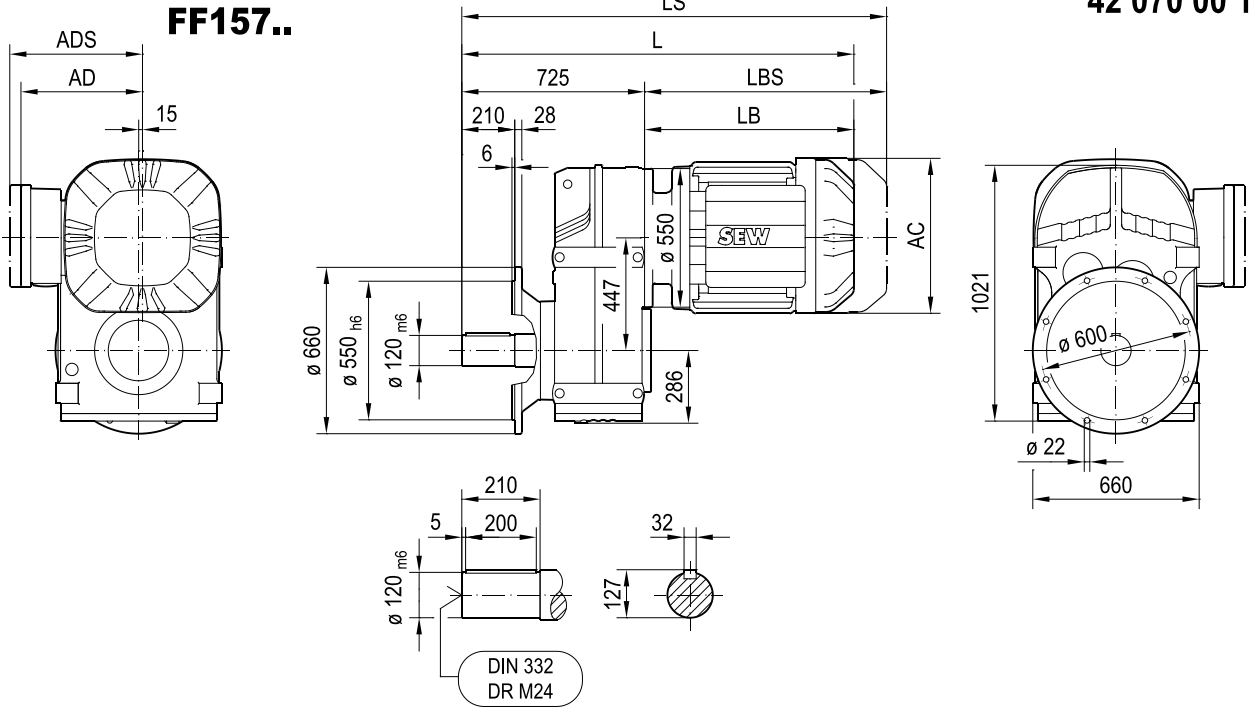

FAF157..

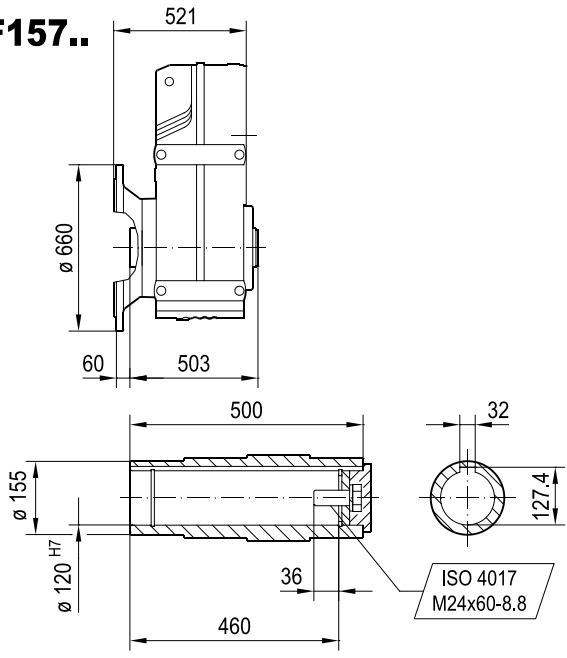

FHF157..

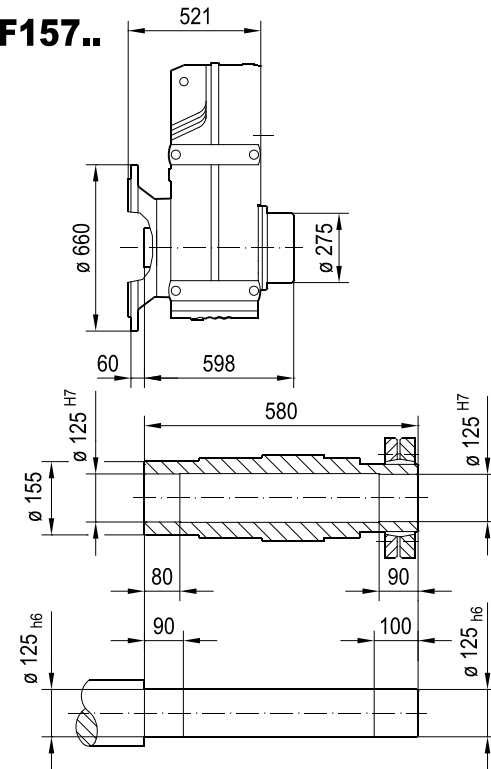

(-> 4.1)	DRN									
	132L	160..	180..	200L	225..	250M	280S	280M	315S-M	315ME-H
AC	261	314	357	394	434	495	495	495	624	624
AD	228	253	268	283	305	394	394	394	506	506
ADS	228	253	268	283	305	394	394	394	506	506
L	1159	1225	1248	1358	1332	1469	1469	1564	1666	1796
LS	1296	1414	1437	1563	1537	1709	1709	1804	1917	2047
LB	434	500	523	633	607	744	744	839	941	1071
LBS	571	689	712	838	812	984	984	1079	1192	1322