




FAZ157..

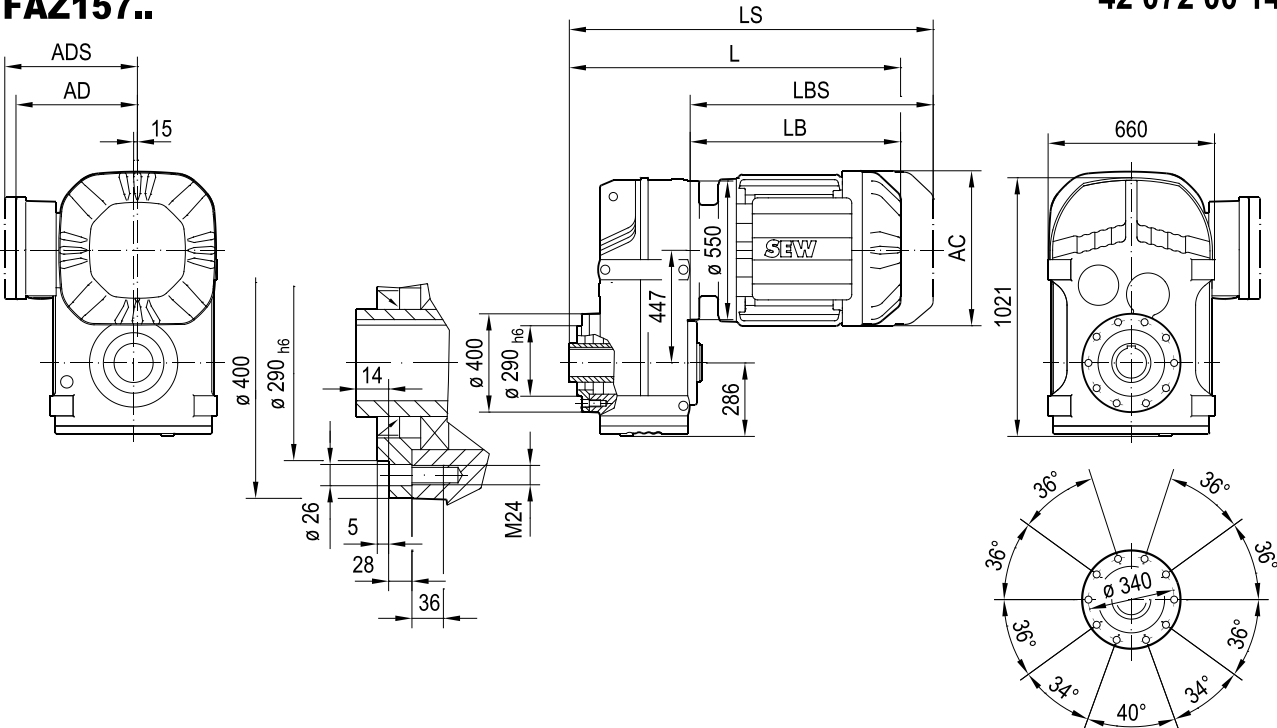

FAZ157..

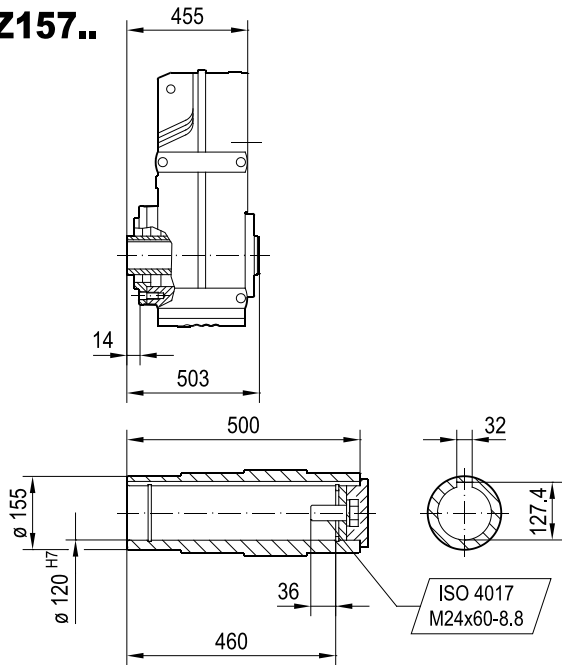

FHZ157..

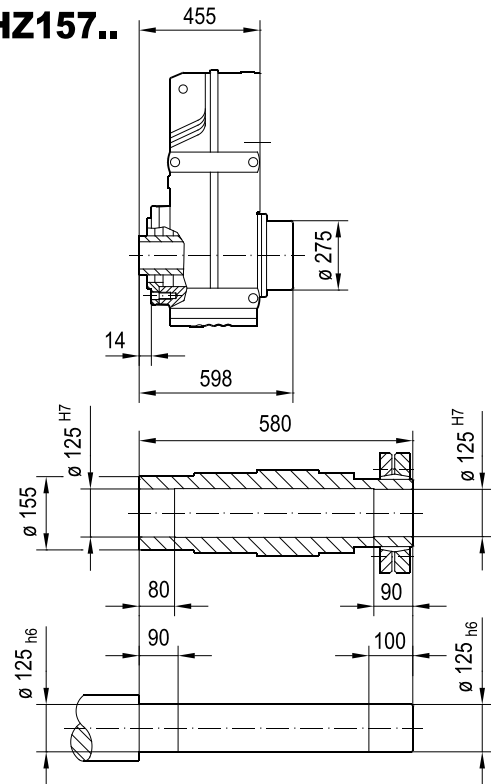

(→ 4.1)	DRN									
	132L	160..	180..	200L	225..	250M	280S	280M	315S-M	315ME-H
AC	261	314	357	394	434	495	495	495	624	624
AD	228	253	268	283	305	394	394	394	506	506
ADS	228	253	268	283	305	394	394	394	506	506
L	889	955	978	1088	1062	1199	1199	1294	1396	1526
LS	1026	1144	1167	1293	1267	1439	1439	1534	1647	1777
LB	434	500	523	633	607	744	744	839	941	1071
LBS	571	689	712	838	812	984	984	1079	1192	1322