




 








 

 DIN 84-4.8-A2F		37	47	57	67	77	87	97
	KA/KH/KT	M6x12	M6x12	M6x12	M8x16	M8x16	M6x12	M10x20
	SA/SH/ST	M6x12	M6x12	M6x12	M8x16	M8x16	M6x12	M10x20
FA/FH/FT	M6x12	M6x12	M6x12	M8x16	M8x16	M6x12	M10x20	
KA/KH/KT	 Ø 94	 Ø 102	 Ø 125	 Ø 125			 Ø 220	
SA/SH/ST	 Ø 75	 Ø 94	 Ø 102					
FA/FH/FT	 Ø 94	 Ø 102	 Ø 125	 Ø 125	 Ø 142	 Ø 180		

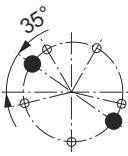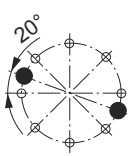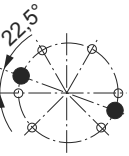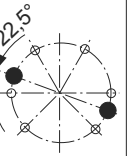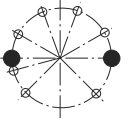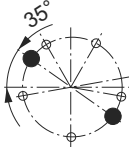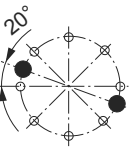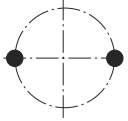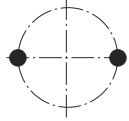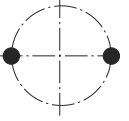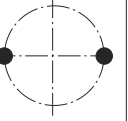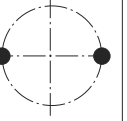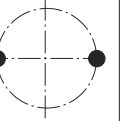

51135AXX



		1		2		3		
		37	47	57	67	77	87	97
	KA/KH/KT					M12-M8	M16-M6	
	SA/SH/ST				M12-M8	M12-M8	M10-M6	M16-M10
	FA/FH/FT							M16-M10
DIN 84-4.8-A2F					M8x16	M8x16	M6x12	M10x20
KA/KH/KT						 Ø 142	 Ø 178	
SA/SH/ST					 Ø 130	 Ø 155	 Ø 180	 Ø 220
FA/FH/FT								 Ø 220

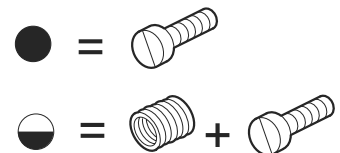

51136AXX