

13 Technical data of the motors

13.1 Key to the data tables

The following table lists the short symbols used in the "Technical data" tables.

P_N	Rated power
M_N	Rated torque
n_N	Rated speed
I_N	Rated current
$\cos\varphi$	Power factor
$\eta_{50\%}$	Efficiency at 50% of the rated power
$\eta_{75\%}$	Efficiency at 75% of the rated power
$\eta_{100\%}$	Efficiency at 100% of the rated power
I_A/I_N	Starting current ratio
M_A/M_N	Starting torque ratio
M_H/M_N	Ramp-up torque ratio
M_K/M_N	Breakdown torque ratio
m_{Mot}	Mass of the motor
J_{Mot}	Mass moment of inertia of the motor
BE..	Brake used
Z_0 BG	Switching frequency for operation with BG brake controller
Z_0 BGE	Switching frequency for operation with BGE brake controller
M_B	Braking torque
m_{BMot}	Mass of the brakemotor
J_{BMot}	Mass moment of inertia of the brakemotor

13.2 IE1 DR2S.. motors. 400 V, 50 Hz, 2-pole

13.2.1 Information on motors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	I _N A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DR2S63MSR2	0.18	0.63	2725	0.465	0.78	57.8	61.0	60.7	4.2	2.6 2.6	2.6
DR2S63MS2	0.25	0.91	2610	0.67	0.80	62.1	64.7	62.3	3.3	2.1 2.1	2.1
DR2S71MS2	0.37	1.26	2810	0.87	0.78	66.6	69.5	69.5	5.4	3.1 2.7	3.1
DR2S71MR2	0.55	1.86	2825	1.24	0.81	72.4	74.6	74.4	5.9	3.2 3.0	3.2
DR2S71M2	0.75	2.6	2760	1.78	0.80	71.3	73.7	72.9	4.7	2.8 2.7	2.8
DR2S80MS2	1.1	3.75	2800	2.45	0.84	74.2	76.4	75.0	4.6	2.3 2.0	2.4
DR2S80M2	1.5	5.1	2820	3.3	0.84	77.2	78.5	77.2	5.1	2.6 2.3	2.6

13

13.2.2 Further information on motors and brakemotors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _B Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DR2S63MSR2	0.18	0.63	2725	4.9	2.95	BE03	5000 6000	1.3	6.8	3.63
DR2S63MS2	0.25	0.91	2610	4.9	2.95	BE03	5000 6000	2.1	6.8	3.63
DR2S71MS2	0.37	1.26	2810	6.8	2.93	BE03	6000 3600	2.7	8.6	3.61
DR2S71MR2	0.55	1.86	2825	8	3.71	BE05	2600 5500	5	10	5.01
DR2S71M2	0.75	2.6	2760	8	3.83	BE05	2600 5500	5	10	5.13
DR2S80MS2	1.1	3.75	2800	11	19.1	BE1	1200 3400	10	15	20.6
DR2S80M2	1.5	5.1	2820	14	24.7	BE1	1000 2600	10	18	26.2

13.3 IE1 DR2S.. motors, 400 V, 50 Hz, 4-pole

13.3.1 Information on motors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	I _{N2} 400 V A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DR2S56MR4 ¹⁾	0.09	0.62	1380	0.35	0.61	43.9	51.4	54.8	3.0	2.8 2.8	2.9
DR2S56M4 ¹⁾	0.12	0.89	1290	0.39	0.74	48.8	53.8	53.3	2.7	2.0 2.0	2.0
DR2S63MSR4	0.12	0.83	1380	0.4	0.64	55.6	61.0	61.9	3.6	2.7 2.6	2.7
DR2S63MS4	0.18	1.29	1330	0.59	0.71	52.1	57.1	57.0	2.9	2.0 2.0	2.1
DR2S63M4	0.25	1.79	1330	0.78	0.70	59.0	62.5	61.5	3.4	2.3 2.3	2.3
DR2S71MS4	0.37	2.6	1350	1.05	0.73	66.0	68.0	66.0	3.6	2.0 1.8	2.0
DR2S71M4	0.55	3.85	1360	1.52	0.72	69.6	71.7	70.0	4.1	2.4 2.2	2.4
DR2S80MK4	0.75	5.1	1410	1.81	0.76	73.6	75.9	75.3	5.2	2.4 2.0	2.6
DR2S80M4	1.1	7.4	1415	2.45	0.80	79.5	80.3	78.9	5.5	2.5 2.1	2.7

1) DR2S56.. motors will be available from spring 2019.

13.3.2 Further information for motors and brakemotors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _B Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DR2S56MR4 ¹⁾	0.09	0.62	1380	²⁾	1.1	BE02	10000 -	0.8	²⁾	1.2
DR2S56M4 ¹⁾	0.12	0.89	1290	²⁾	1.1	BE02	10000 -	1.2	²⁾	1.2
DR2S63MSR4	0.12	0.83	1380	4.9	2.95	BE03	10000 10000	1.7	6.8	3.63
DR2S63MS4	0.18	1.29	1330	4.9	2.95	BE03	10000 10000	2.7	6.8	3.63
DR2S63M4	0.25	1.79	1330	5.8	3.76	BE03	10000 10000	3.4	7.6	4.44
DR2S71MS4	0.37	2.6	1350	6.8	5.42	BE05	6200 9700	5	9.2	6.72
DR2S71M4	0.55	3.85	1360	8	7.14	BE1	5000 9000	10	11	8.44
DR2S80MK4	0.75	5.1	1410	11	17.1	BE1	3500 8500	10	14	18.6
DR2S80M4	1.1	7.4	1415	14	24.7	BE2	3200 8200	20	18	29.2

1) DR2S56.. motors will be available from spring 2019.

2) Only available as gearmotor

13.4 IE1 DR2S.. motors. 400 V, 50 Hz, 6-pole

13.4.1 Information on motors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	I _N A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DR2S63MQ6	0.09	0.93	920	0.36	0.58	37.5	43.7	46.5	2.9	2.7 2.6	2.8
DR2S63MR6	0.12	1.32	870	0.4	0.71	48.7	53.9	54.1	2.6	1.9 1.8	1.9
DR2S63M6	0.18	2	855	0.66	0.71	41.5	48.0	49.1	2.5	1.9 1.9	1.9
DR2S71MS6	0.25	2.65	895	0.78	0.71	60.2	65.1	64.9	3.0	1.7 1.7	2.0
DR2S71M6	0.37	4	885	1.18	0.69	55.1	60.1	60.0	2.9	1.9 1.9	2.0
DR2S80MK6	0.55	5.8	910	1.58	0.72	64.5	67.2	65.9	3.5	1.8 1.8	2.1

13.4.2 Further information on motors and brakemotors

DR2S.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _B Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DR2S63MQ6	0.09	0.93	920	5.8	6.47	BE03	12000 12000	2.1	7.6	7.16
DR2S63MR6	0.12	1.32	870	5.8	6.47	BE03	12000 12000	2.7	7.6	7.16
DR2S63M6	0.18	2	855	5.8	6.57	BE03	12000 12000	3.4	7.6	7.26
DR2S71MS6	0.25	2.65	895	6.8	8.29	BE1	7000 12000	7	9.4	9.59
DR2S71M6	0.37	4	885	8	10.4	BE1	5200 12000	10	11	11.7
DR2S80MK6	0.55	5.8	910	11	17.1	BE2	3000 9000	14	15	21.6

13.5 IE1 DRS.. motors. 400 V, 50 Hz, 2-pole

13.5.1 Information on motors

Motor type DRS..	P _N kW	M _N Nm	n _N min ⁻¹	I _{N2} 400 V A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DRS90M2	1.5	5.1	2830	3.1	0.89	83.3	80.0	78.3	5.9	2.7 2.6	2.7
DRS90L2	2.2	7.4	2820	4.45	0.89	84.9	82.8	80.5	5.8	2.9 2.5	2.6
DRS100M2	3	10.1	2840	5.8	0.91	86.9	84.6	82.5	6.4	3.1 2.8	2.8
DRS100LC2	4	13.2	2900	7.8	0.88	86.9	85.6	84.2	7.7	2.7 2.1	3.0
DRS112M2	4	13.2	2900	7.6	0.89	87.7	85.4	84.3	6.3	2.3 2.1	2.8
DRS132S2	5.5	18.2	2890	10.2	0.91	89.2	87.0	85.5	6.5	2.3 2.1	2.8
DRS132M2	7.5	24.5	2910	13.7	0.91	90.0	87.8	86.5	7.3	2.5 2.3	3.1
DRS132M2	9.2	30.5	2900	16.9	0.89	90.2	88.8	87.2	6.9	2.5 2.3	3.0

13.5.2 Further information for motors and brakemotors

Motor type DRS..	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _B Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DRS90M2	1.5	5.1	2830	18	35.7	BE1	1100 2700	10	21	37.3
DRS90L2	2.2	7.4	2820	21	43.9	BE2	900 2200	14	26	48.6
DRS100M2	3	10.1	2840	26	56.2	BE2	700 1800	20	31	61
DRS100LC2	4	13.2	2900	31	90	BE5	- 700	28	37	96
DRS112M2	4	13.2	2900	42	114	BE5	- 600	28	49	119
DRS132S2	5.5	18.2	2890	47	147	BE5	- 500	40	55	151
DRS132M2	7.5	24.5	2910	61	193	BE5	- 500	55	68	198
DRS132M2	9.2	30.5	2900	61	193	BE5	- 500	55	68	198

13.6 IE1 DRS.. motors, 400 V, 50 Hz, 4-pole

13.6.1 Information on motors

Motor type DRS..	P _N kW	M _N Nm	n _N min ⁻¹	I _{N2} 400 V A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DRS90M4	1.5	10.3	1395	3.3	0.82	82.0	82.0	79.6	5.0	2.3 2.0	2.5
DRS90L4	2.2	15	1400	4.85	0.81	82.9	83.1	81.1	5.1	2.5 2.2	2.5
DRS100M4	3	20.5	1400	6.4	0.82	85.2	84.7	82.4	5.3	2.8 2.4	2.8
DRS100LC4	4	26.5	1440	8.9	0.78	83.2	84.3	83.2	6.5	2.5 2.3	3.1
DRS112M4	4	26.5	1435	8.1	0.84	86.1	85.6	83.8	6.0	2.0 1.7	2.5
DRS132S4	5.5	36.5	1445	11.1	0.82	86.4	86.7	85.7	6.7	2.4 2.1	2.8
DRS132M4	7.5	49.5	1445	14.4	0.85	90.0	89.1	87.1	6.6	2.4 1.9	2.7
DRS132MC4	9.2	60	1465	18.6	0.81	87.9	88.5	87.6	7.2	2.1 1.6	2.9
DRS160S4	9.2	60	1460	18.9	0.79	87.9	89.0	88.0	6.4	2.5 2.0	2.6
DRS160M4	11	72	1460	22	0.81	89.2	89.1	88.0	6.8	2.7 2.3	2.8
DRS160MC4	15	97	1470	30	0.80	90.3	90.2	89.1	6.3	2.1 1.7	2.4
DRS180S4	15	98	1460	29	0.83	90.0	90.3	89.5	6.2	2.3 2.0	2.6
DRS180M4	18.5	121	1465	34.5	0.85	90.6	90.8	90.0	6.5	2.2 1.8	2.7
DRS180L4	22	143	1465	41.5	0.84	90.9	91.2	90.5	6.9	2.4 2.0	2.8
DRS180LC4	30	195	1470	57	0.84	92.2	92.0	90.9	5.6	1.8 1.5	2.2
DRS200L4	30	194	1475	57	0.82	91.6	91.9	91.3	6.4	2.1 1.9	2.6
DRS225S4	37	240	1475	70	0.82	92.2	92.0	91.6	7.1	2.4 1.9	3.0
DRS225M4	45	290	1480	84	0.83	92.8	92.7	92.3	7.4	2.5 2.2	2.9
DRS225MC4	55	355	1480	106	0.81	92.4	92.8	92.4	6.8	2.4 1.8	2.4
DRS250M4	55	355	1479	105	0.82	92.1	92.5	92.7	6.9	3.0 2.1	2.6
DRS280S4	75	485	1480	140	0.83	92.3	93.0	93.4	7.8	3.0 2.1	2.6
DRS280M4	90	580	1478	170	0.82	93.2	93.7	93.6	7.0	3.4 2.3	2.8
DRS315K4	110	710	1482	200	0.84	93.7	94.2	94.0	6.1	2.2 1.7	2.5
DRS315S4	132	850	1484	230	0.86	93.4	94.2	94.2	6.5	2.4 1.9	2.7
DRS315M4	160	1030	1483	280	0.87	94.6	94.8	94.6	6.9	2.1 1.7	2.3
DRS315L4	200	1290	1481	350	0.88	94.7	94.9	94.6	6.4	2.1 1.7	2.3

13.6.2 Further information for motors and brakemotors

Motor type DRS..	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _{B_req} Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DRS90M4	1.5	10.3	1395	19	36.6	BE2	2900 7500	20	23	41.3
DRS90L4	2.2	15	1400	21	44.9	BE5	2300 5600	40	27	50.9
DRS100M4	3	20.5	1400	26	57.2	BE5	- 8500	40	32	63.2
DRS100LC4	4	26.5	1440	31	91	BE5	- 3800	55	37	97
DRS112M4	4	26.5	1435	42	152	BE5	- 3100	55	49	157
DRS132S4	5.5	36.5	1445	47	196	BE11	- 2800	80	62	206
DRS132M4	7.5	49.5	1445	61	258	BE11	- 2000	110	76	269
DRS132MC4	9.2	60	1465	64	347	BE11	- 1500	110	79	357
DRS160S4	9.2	60	1460	75	366	BE20	- 1100	150	100	417
DRS160M4	11	72	1460	84	442	BE20	- 1000	150	110	493
DRS160MC4	15	97	1470	89	609	BE20	- 900	200	115	661
DRS180S4	15	98	1460	120	909	BE20	- 900	200	155	969
DRS180M4	18.5	121	1465	140	1130	BE30	- 800	300	180	1260
DRS180L4	22	143	1465	150	1310	BE30	- 590	300	190	1450
DRS180LC4	30	195	1470	160	1700	BE32	- 520	400	205	1930
DRS200L4	30	194	1475	255	2390	BE32	- 550	400	310	2620
DRS225S4	37	240	1475	285	2970	BE32	- 320	500	340	3200
DRS225M4	45	290	1480	305	3470	BE32	- 270	600	360	3700
DRS225MC4	55	355	1480	320	4390	BE32	- 200	600	375	4620
DRS250M4	55	355	1479	435	6360	BE62	- 200	800	520	6950
DRS280S4	75	485	1480	510	8930	BE62	- 150	1000	600	9520
DRS280M4	90	580	1478	510	9030	BE62	- 100	1200	600	9620
DRS315K4	110	710	1482	830	18500	BE122	- 65	1600	960	19500
DRS315S4	132	850	1484	910	22600	BE122	- 50	2000	1040	23600
DRS315M4	160	1030	1483	1060	28000	BE122	- 35	2000	1190	29000
DRS315L4	200	1290	1481	1140	32000	BE122	- 25	2000	1270	33000

13.7 IE1 DRS.. motors, 400 V, 50 Hz, 6-pole

13.7.1 Information on motors

DRS.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	I _{N2} 400 V A	cosφ	η _{50%} %	η _{75%} %	η _{100%} %	I _A /I _N	M _A /M _N M _H /M _N	M _K /M _N
DRS90L6	1.1	11.3	930	3.1	0.68	77.5	76.3	75.0	4.2	2.3 2.3	2.5
DRS100M6	1.5	15.5	925	4.25	0.68	76.0	77.3	75.7	4.2	2.7 2.7	2.7
DRS100LC6	2.2	22	955	5.5	0.71	80.1	80.8	80.0	5.1	2.2 2.2	2.7
DRS112M6	2.2	22	955	5.4	0.74	81.0	80.5	79.3	5.5	2.1 1.8	2.7
DRS112M6	3	30.5	945	7	0.76	84.6	83.0	81.0	5.1	1.9 1.6	2.5
DRS132S6	4	40.5	940	9.8	0.76	85.1	84.2	81.7	4.3	2.1 1.9	2.4
DRS132MC6	5.5	54	970	12.2	0.76	87.2	86.6	85.5	5.8	1.9 1.7	2.7
DRS160S6	5.5	55	960	12.9	0.73	85.5	85.4	84.4	5.2	2.0 1.8	2.6
DRS160M6	7.5	75	955	17.3	0.73	86.8	87.1	85.9	5.1	2.2 1.9	2.5

13

13.7.2 Further information for motors and brakemotors

DRS.. motor type	P _N kW	M _N Nm	n _N min ⁻¹	m _{Mot} kg	J _{Mot} 10 ⁻⁴ kgm ²	BE..	Z ₀ BG BGE h ⁻¹	M _{B_req} Nm	m _{BMot} kg	J _{BMot} 10 ⁻⁴ kgm ²
DRS90L6	1.1	11.3	930	21	44.6	BE5	3500 8000	40	27	50.5
DRS100M6	1.5	15.5	925	26	56.8	BE5	- 7000	40	32	62.8
DRS100LC6	2.2	22	955	31	91	BE5	- 5000	55	37	97
DRS112M6	2.2	22	955	42	148	BE11	- 4000	80	57	158
DRS112M6	3	30.5	945	42	148	BE11	- 3600	80	57	158
DRS132S6	4	40.5	940	47	190	BE11	- 3500	80	62	201
DRS132MC6	5.5	54	970	64	345	BE11	- 2900	110	79	356
DRS160S6	5.5	55	960	75	522	BE11	- 2700	110	94	544
DRS160M6	7.5	75	955	84	634	BE20	- 2700	150	110	685

14 Address directory SEW-EURODRIVE

Algeria			
Sales	Algiers	REDUCOM Sarl 16, rue des Frères Zaghroune Bellevue 16200 El Harrach Alger	Tel. +213 21 8214-91 Fax +213 21 8222-84 http://www.reducom-dz.com info@reducom-dz.com
Argentina			
Assembly Sales	Buenos Aires	SEW EURODRIVE ARGENTINA S.A. Ruta Panamericana Km 37.5, Lote 35 (B1619IEA) Centro Industrial Garín Prov. de Buenos Aires	Tel. +54 3327 4572-84 Fax +54 3327 4572-21 http://www.sew-eurodrive.com.ar sewar@sew-eurodrive.com.ar
	Córdoba	SEW EURODRIVE ARGENTINA S.A. Ruta Nacional 19, Manzana 97, Lote 5 (X5125) Malvinas Argentinas Prov. de Córdoba	Tel. +54 351-490-0010 http://www.sew-eurodrive.com.ar sewcor@sew-eurodrive.com.ar
	Santa Fe	SEW EURODRIVE ARGENTINA S.A. Ruta Prov. 21 Km 7, Lote 41 Parque Industrial Alvear (2126) Gral. Alvear Prov. de Santa Fe	Tel. +54 341-317-7277 http://www.sew-eurodrive.com.ar sewsfe@sew-eurodrive.com.ar
Service	Mendoza	SEW EURODRIVE ARGENTINA S.A. Francisco Gabrielli (ex Urquiza) 2060-Zona Industrial- Guaymallen- CP 5521	Tel. +54 261-4214150 http://www.sew-eurodrive.com.ar sewmen@sew-eurodrive.com.ar
Technical Offices	Tucumán	SEW EURODRIVE ARGENTINA S.A. Balcarce 609 (T4000IAM) S.M. de Tucumán Prov. de Tucumán	Tel. +54 381-400-4569 http://www.sew-eurodrive.com.ar sewtuc@sew-eurodrive.com.ar
	Bahía Blanca	SEW EURODRIVE ARGENTINA S.A. O'Higgins 95, 1er Piso A (B8000IVA) Bahía Blanca Prov. de Buenos Aires	Tel. +54 291-451-7345 http://www.sew-eurodrive.com.ar sewbb@sew-eurodrive.com.ar
	Neuquén	SEW EURODRIVE ARGENTINA S.A.	Tel. +549 299 588 7950 http://www.sew-eurodrive.com.ar sewnqn@sew-eurodrive.com.ar
Australia			
Assembly Sales Service	Melbourne	SEW-EURODRIVE PTY. LTD. 27 Beverage Drive Tullamarine, Victoria 3043	Tel. +61 3 9933-1000 Fax +61 3 9933-1003 http://www.sew-eurodrive.com.au enquires@sew-eurodrive.com.au
	Sydney	SEW-EURODRIVE PTY. LTD. 9, Sleigh Place, Wetherill Park New South Wales, 2164	Tel. +61 2 9725-9900 Fax +61 2 9725-9905 enquires@sew-eurodrive.com.au
Sales Service	Adelaide	SEW-EURODRIVE PTY. LTD. 9C Park Way Mawson Lakes, SA 5095	Tel. +61 8 8161 4000 Fax +61 8 8161 4002 enquires@sew-eurodrive.com.au
	Brisbane	SEW-EURODRIVE PTY. LTD. 1 /34 Collinsvale St Rocklea, Queensland, 4106	Tel. +61 7 3276 5100 Fax +61 7 3276 5102 enquires@sew-eurodrive.com.au
	Perth	SEW-EURODRIVE PTY. LTD. 10 Colin Jamieson Drive Welshpool, WA 6106	Tel. +61 8 9251-4900 Fax +61 8 9251-4903 enquires@sew-eurodrive.com.au
Sales	Townsville	SEW-EURODRIVE PTY. LTD. 12 Leyland Street Garbutt, QLD 4814	Tel. +61 7 4779 4333 Fax +61 7 4779 5333 enquires@sew-eurodrive.com.au
Austria			
Assembly Sales Service	Vienna	SEW-EURODRIVE Ges.m.b.H. Richard-Strauss-Straße 24 1230 Wien	Tel. +43 1 617 55 00-0 Fax +43 1 617 55 00-30 http://www.sew-eurodrive.at sew@sew-eurodrive.at
Technical Offices	Linz	SEW-EURODRIVE Ges.m.b.H. Jaxstraße 2-4 4020 Linz	Tel. +43 732 655 109-0 Fax +43 732 655 109-20 tb-linz@sew-eurodrive.at

Graz	SEW-EURODRIVE Ges.m.b.H. Grabenstraße 231 8045 Graz	Tel. +43 316 685 756-0 Fax +43 316 685 756-20 tb-graz@sew-eurodrive.at
Dornbirn	SEW-EURODRIVE Ges.m.b.H. Lustenauerstraße 27/1 6850 Dornbirn	Tel. +43 5572 3725 99-0 Fax +43 5572 3725 99-20 tb-dornbirn@sew-eurodrive.at

Bangladesh

Sales	Bangladesh	SEW-EURODRIVE INDIA PRIVATE LIMITED 345 DIT Road East Rampura Dhaka-1219, Bangladesh	Tel. +88 01729 097309 salesdhaka@seweurodrivebangladesh.com
-------	------------	---	--

Belarus

Sales	Minsk	Foreign unitary production enterprise SEW-EURODRIVE RybalkoStr. 26 220033 Minsk	Tel. +375 17 298 47 56 / 298 47 58 Fax +375 17 298 47 54 http://www.sew.by sales@sew.by
-------	-------	---	--

Belgium

Assembly Sales Service	Brussels	SEW-EURODRIVE n.v./s.a. Researchpark Haasrode 1060 Evenementenlaan 7 3001 Leuven	Tel. +32 16 386-311 Fax +32 16 386-336 http://www.sew-eurodrive.be info@sew-eurodrive.be
Service Competence Center	Industrial Gears	SEW-EURODRIVE n.v./s.a. Rue du Parc Industriel, 31 6900 Marche-en-Famenne	Tel. +32 84 219-878 Fax +32 84 219-879 http://www.sew-eurodrive.be service-IG@sew-eurodrive.be

Brazil

Production Sales Service	São Paulo	SEW-EURODRIVE Brasil Ltda. Estrada Municipal José Rubim, 205 – Rodovia Santos Dumont Km 49 Indaiatuba – 13347-510 – SP	Tel. +55 19 3835-8000 sew@sew.com.br
Assembly Sales Service	Rio Claro	SEW-EURODRIVE Brasil Ltda. Rodovia Washington Luiz, Km 172 Condomínio Industrial Conpark Caixa Postal: 327 13501-600 – Rio Claro / SP	Tel. +55 19 3522-3100 Fax +55 19 3524-6653 montadora.rc@sew.com.br
	Joinville	SEW-EURODRIVE Brasil Ltda. Jvl / Ind Rua Dona Francisca, 12.346 – Pirabeiraba 89239-270 – Joinville / SC	Tel. +55 47 3027-6886 Fax +55 47 3027-6888 filial.sc@sew.com.br

Bulgaria

Sales	Sofia	BEVER-DRIVE GmbH Bogdanovetz Str.1 1606 Sofia	Tel. +359 2 9151160 Fax +359 2 9151166 bever@bever.bg
-------	-------	---	---

Cameroon

Sales	Douala	SEW-EURODRIVE S.A.R.L. Ancienne Route Bonabéri P.O. Box B.P 8674 Douala-Cameroun	Tel. +237 233 39 02 10 Fax +237 233 39 02 10 sew@sew-eurodrive-cm
-------	--------	--	---

Canada

Assembly Sales Service	Toronto	SEW-EURODRIVE CO. OF CANADA LTD. 210 Walker Drive Bramalea, ON L6T 3W1	Tel. +1 905 791-1553 Fax +1 905 791-2999 http://www.sew-eurodrive.ca l.watson@sew-eurodrive.ca
	Vancouver	SEW-EURODRIVE CO. OF CANADA LTD. Tilbury Industrial Park 7188 Honeyman Street Delta, BC V4G 1G1	Tel. +1 604 946-5535 Fax +1 604 946-2513 b.wake@sew-eurodrive.ca
	Montreal	SEW-EURODRIVE CO. OF CANADA LTD. 2001 Ch. de l'Aviation Dorval Quebec H9P 2X6	Tel. +1 514 367-1124 Fax +1 514 367-3677 n.paradis@sew-eurodrive.ca

Chile			
Assembly Sales Service	Santiago de Chile	SEW-EURODRIVE CHILE LTDA Las Encinas 1295 Parque Industrial Valle Grande LAMP Santiago de Chile P.O. Box Casilla 23 Correo Quilicura - Santiago - Chile	Tel. +56 2 2757 7000 Fax +56 2 2757 7001 http://www.sew-eurodrive.cl ventas@sew-eurodrive.cl
China			
Production Assembly Sales Service	Tianjin	SEW-EURODRIVE (Tianjin) Co., Ltd. No. 78, 13th Avenue, TEDA Tianjin 300457	Tel. +86 22 25322612 Fax +86 22 25323273 http://www.sew-eurodrive.cn info@sew-eurodrive.cn
Assembly Sales Service	Suzhou	SEW-EURODRIVE (Suzhou) Co., Ltd. 333, Suhong Middle Road Suzhou Industrial Park Jiangsu Province, 215021	Tel. +86 512 62581781 Fax +86 512 62581783 suzhou@sew-eurodrive.cn
	Guangzhou	SEW-EURODRIVE (Guangzhou) Co., Ltd. No. 9, JunDa Road East Section of GETDD Guangzhou 510530	Tel. +86 20 82267890 Fax +86 20 82267922 guangzhou@sew-eurodrive.cn
	Shenyang	SEW-EURODRIVE (Shenyang) Co., Ltd. 10A-2, 6th Road Shenyang Economic Technological Development Area Shenyang, 110141	Tel. +86 24 25382538 Fax +86 24 25382580 shenyang@sew-eurodrive.cn
	Taiyuan	SEW-EURODRIVE (Taiyuan) Co., Ltd. No.3, HuaZhang Street, TaiYuan Economic & Technical Development Zone ShanXi, 030032	Tel. +86-351-7117520 Fax +86-351-7117522 taiyuan@sew-eurodrive.cn
	Wuhan	SEW-EURODRIVE (Wuhan) Co., Ltd. 10A-2, 6th Road No. 59, the 4th Quanli Road, WEDA 430056 Wuhan	Tel. +86 27 84478388 Fax +86 27 84478389 wuhan@sew-eurodrive.cn
	Xi'An	SEW-EURODRIVE (Xi'An) Co., Ltd. No. 12 Jinye 2nd Road Xi'An High-Technology Industrial Development Zone Xi'An 710065	Tel. +86 29 68686262 Fax +86 29 68686311 xian@sew-eurodrive.cn
Sales Service	Hong Kong	SEW-EURODRIVE LTD. Unit No. 801-806, 8th Floor Hong Leong Industrial Complex No. 4, Wang Kwong Road Kowloon, Hong Kong	Tel. +852 36902200 Fax +852 36902211 contact@sew-eurodrive.hk
Colombia			
Assembly Sales Service	Bogota	SEW-EURODRIVE COLOMBIA LTDA. Calle 17 No. 132-18 Interior 2 Bodega 6, Manzana B Santafé de Bogotá	Tel. +57 1 54750-50 Fax +57 1 54750-44 http://www.sew-eurodrive.com.co sew@sew-eurodrive.com.co
Croatia			
Sales Service	Zagreb	KOMPEKS d. o. o. Zeleni dol 10 10 000 Zagreb	Tel. +385 1 4613-158 Fax +385 1 4613-158 kompeks@inet.hr
Czech Republic			
Assembly Sales Service	Hostivice	SEW-EURODRIVE CZ s.r.o. Floriánova 2459 253 01 Hostivice	Tel. +420 255 709 601 Fax +420 235 350 613 http://www.sew-eurodrive.cz sew@sew-eurodrive.cz
	Drive Service Hotline / 24 Hour Service	+420 800 739 739 (800 SEW SEW)	Service Tel. +420 255 709 632 Fax +420 235 358 218 servis@sew-eurodrive.cz

Assembly Service	Plzeň	SEW-EURODRIVE CZ s.r.o. Areal KRPA a.s. Zahradní 173/2 326 00 Plzeň	Tel. +420 378 775 320 Fax +420 377 970 710 sew@sew-eurodrive.cz
Technical Offices	Brno	SEW-EURODRIVE CZ s.r.o. Křenová 52 60200 Brno	Tel. +420 543 254 174 Fax +420 543 256 845 ilona.cermakova@sew-eurodrive.cz
	Hradec Králové	SEW-EURODRIVE CZ s.r.o. Čechova 498 50202 Hradec Králové	Tel. +420 495 510 141 Fax +420 495 521 313 miroslav.moravec@sew-eurodrive.cz
	Ostrava	SEW-EURODRIVE CZ s.r.o. Studentská 6202/17 708 00 Ostrava-Poruba	Tel. +420 597 329 044 david.kenkus@sew-eurodrive.cz
	Klatovy	SEW-EURODRIVE CZ s.r.o. Videňská 841 33901 Klatovy	Tel. +420 376 331 634 Fax +420 376 331 634 viktor.kubernat@sew-eurodrive.cz
Service	Přerov	SEW-EURODRIVE CZ s.r.o. Areál STS Přerov a.s. ul. 9. května 2452 750 02 Přerov I – Město	Tel. +420 581 224 374 Fax +420 581 224 374 servis@sew-eurodrive.cz

Denmark

Assembly Sales Service	Copenhagen	SEW-EURODRIVE A/S Geminivej 28-30 2670 Greve	Tel. +45 43 95 8500 Fax +45 43 9585-09 http://www.sew-eurodrive.dk sew@sew-eurodrive.dk
------------------------	------------	--	--

Egypt

Sales Service	Cairo	Copam Egypt for Engineering & Agencies Building 10, Block 13005, First Industrial Zone, Obour City Cairo	Tel. +202 44812673 / 79 (7 lines) Fax +202 44812685 http://www.copam-egypt.com copam@copam-egypt.com
---------------	-------	---	--

Estonia

Sales	Tallin	ALAS-KUUL AS Reti tee 4 75301 Peetri küla, Rae vald, Harjumaa	Tel. +372 6593230 Fax +372 6593231 http://www.alas-kuul.ee veiko.soots@alas-kuul.ee
-------	--------	---	--

Finland

Assembly Sales Service	Hollola	SEW-EURODRIVE OY Vesimäentie 4 15860 Hollola	Tel. +358 201 589-300 Fax +358 3 780-6211 http://www.sew-eurodrive.fi sew@sew.fi
Service	Hollola	SEW-EURODRIVE OY Keskikankaantie 21 15860 Hollola	Tel. +358 201 589-300 Fax +358 3 780-6211 http://www.sew-eurodrive.fi sew@sew.fi
Production Assembly	Karkkila	SEW Industrial Gears Oy Santasalonkatu 6, PL 8 03620 Karkkila, 03601 Karkkila	Tel. +358 201 589-300 Fax +358 201 589-310 http://www.sew-eurodrive.fi sew@sew.fi
Technical Offices	Helsinki	SEW-EURODRIVE OY Luutnantintie 5 00410 Helsinki	Tel. +358 201 589-300 sew@sew.fi
	Oulu	SEW Industrial Gears Oy Paulaharjuntie 22 90530 Oulu	Tel. +358 201 589 300 sew@sew.fi
	Vaasa	SEW Industrial Gears Oy Asemakatu 7 65100 Vaasa	Tel. +358 201 589-300 sew@sew.fi
	Kuopio	SEW Industrial Gears Oy Leväsentie 23 70780 Kuopio	Tel. +358 201 589-300 sew@sew.fi
	Tampere	SEW Industrial Gears Oy Kampusareena Korkeakoulunkatu 7, 7.krs 33720 Tampere	Tel. +358 201 589-300 sew@sew.fi

Kotka	SEW Industrial Gears Oy Heikinkatu 7 48100 Kotka	Tel. +358 201 589 300 sew@sew.fi
-------	--	-------------------------------------

France

Production Sales Service	Hagenau	SEW-USOCOME 48-54 route de Soufflenheim B. P. 20185 67506 Haguenau Cedex	Tel. +33 3 88 73 67 00 Fax +33 3 88 73 66 00 http://www.usocome.com sew@usocome.com
Production	Forbach	SEW-USOCOME Zone industrielle Technopôle Forbach Sud B. P. 30269 57604 Forbach Cedex	Tel. +33 3 87 29 38 00
	Brumath	SEW-USOCOME 1 Rue de Bruxelles 67670 Mommenheim Cedex	Tel. +33 3 88 37 48 00
Assembly Sales Service	Bordeaux	SEW-USOCOME Parc d'activités de Magellan 62 avenue de Magellan – B. P. 182 33607 Pessac Cedex	Tel. +33 5 57 26 39 00 Fax +33 5 57 26 39 09
	Lyon	SEW-USOCOME 75 rue Antoine Condorcet 38090 Vaulx-Milieu	Tel. +33 4 74 99 60 00 Fax +33 4 74 99 60 15
	Nantes	SEW-USOCOME Parc d'activités de la forêt 4 rue des Fontenelles 44140 Le Bignon	Tel. +33 2 40 78 42 00 Fax +33 2 40 78 42 20
	Paris	SEW-USOCOME Zone industrielle 2 rue Denis Papin 77390 Verneuil l'Étang	Tel. +33 1 64 42 40 80 Fax +33 1 64 42 40 88
Technical Offices	Alsace	SEW-USOCOME	Tel. +33 3 89 74 51 62 Fax +33 3 89 76 58 71
	Aquitaine / Charentes	SEW-USOCOME	Tel. +33 5 57 26 39 08 Fax +33 5 57 26 39 09
	Auvergne / Limousin	SEW-USOCOME	Tel. +33 5 55 20 12 10 Fax +33 5 55 20 12 11
	Lower Nor- mandie	SEW-USOCOME	Tel. +33 2 31 37 92 86 Fax +33 2 31 74 68 15
	Brittany	SEW-USOCOME	Tel. +33 2 40 78 42 04 Fax +33 2 40 78 42 20
	Burgundy	SEW-USOCOME	Tel. +33 3 85 49 92 18 Fax +33 3 85 49 92 19
	Centre / Poitou	SEW-USOCOME	Tel. +33 2 40 78 42 11 Fax +33 2 40 78 42 20
	Champagne- Ardenne	SEW-USOCOME	Tel. +33 3 25 79 63 24 Fax +33 3 25 79 63 25
	Franche- Comté	SEW-USOCOME	Tel. +33 3 84 68 57 71 Fax +33 3 84 68 57 95
	Île-de-France East / Aisne	SEW-USOCOME	Tel. +33 3 23 62 81 24 Fax +33 3 23 62 81 44
	Île-de-France North / Pi- cardie	SEW-USOCOME	Tel. +33 1 41 05 92 74 Fax +33 1 41 05 92 75
	Île-de-France South	SEW-USOCOME	Tel. +33 1 60 81 10 56 Fax +33 1 60 81 10 57
	Lorraine / Alsace North	SEW-USOCOME	Tel. +33 3 83 96 28 04 Fax +33 3 83 96 28 07
	Midi- Pyrénées / Roussillon	SEW-USOCOME	Tel. +33 5 61 08 15 85 Fax +33 5 61 08 16 44
	Nord-Pas-de- Calais	SEW-USOCOME	Tel. +33 3 21 10 86 86 Fax +33 3 21 10 86 87

Paris / Île-de-France West	SEW-USOCOME	Tel. +33 1 30 90 89 86 Fax +33 1 30 90 93 15
Pays de la Loire	SEW-USOCOME	Tel. +33 2 40 78 42 03 Fax +33 2 40 78 42 20
Provence-Alpes-Côte d'Azur	SEW-USOCOME	Tel. +33 4 91 18 00 11 Fax +33 4 91 18 00 12
Rhône-Alpes East	SEW-USOCOME	Tel. +33 4 75 05 65 95 Fax +33 4 75 05 65 96
Rhône-Alpes North	SEW-USOCOME	Tel. +33 4 74 99 60 03 Fax +33 4 74 99 60 15
Rhône-Alpes West	SEW-USOCOME	Tel. +33 4 74 99 60 04 Fax +33 4 74 99 60 15

Gabon

Sales	Libreville	SEW-EURODRIVE SARL 183, Rue 5.033.C, Lalala à droite P.O. Box 15682 Libreville	Tel. +241 03 28 81 55 +241 06 54 81 33 http://www.sew-eurodrive.cm sew@sew-eurodrive.cm
-------	------------	---	--

Germany

Headquarters Production Sales	Bruchsal	SEW-EURODRIVE GmbH & Co KG Ernst-Blickle-Straße 42 76646 Bruchsal	Tel. +49 7251 75-0 Fax +49 7251 75-1970 http://www.sew-eurodrive.de sew@sew-eurodrive.de
Production / Industrial Gears	Bruchsal	SEW-EURODRIVE GmbH & Co KG Christian-Pähr-Str. 10 76646 Bruchsal	Tel. +49 7251 75-0 Fax +49 7251 75-2970
Production	Graben	SEW-EURODRIVE GmbH & Co KG Ernst-Blickle-Straße 1 76676 Graben-Neudorf	Tel. +49 7251 75-0 Fax +49 7251-2970
	Östringen	SEW-EURODRIVE GmbH & Co KG, Werk Östringen Franz-Gurk-Straße 2 76684 Östringen	Tel. +49 7253 9254-0 Fax +49 7253 9254-90 oesstringen@sew-eurodrive.de
Service Competence Center	Mechanics / Mechatronics	SEW-EURODRIVE GmbH & Co KG Ernst-Blickle-Straße 1 76676 Graben-Neudorf	Tel. +49 7251 75-1710 Fax +49 7251 75-1711 scc-mechanik@sew-eurodrive.de
	Electronics	SEW-EURODRIVE GmbH & Co KG Ernst-Blickle-Straße 42 76646 Bruchsal	Tel. +49 7251 75-1780 Fax +49 7251 75-1769 scc-elektronik@sew-eurodrive.de
Drive Technology Center	North	SEW-EURODRIVE GmbH & Co KG Alte Ricklinger Straße 40-42 30823 Garbsen (Hannover)	Tel. +49 5137 8798-30 Fax +49 5137 8798-55 dtc-nord@sew-eurodrive.de
	East	SEW-EURODRIVE GmbH & Co KG Dänkritzer Weg 1 08393 Meerane (Zwickau)	Tel. +49 3764 7606-0 Fax +49 3764 7606-30 dtc-ost@sew-eurodrive.de
	South	SEW-EURODRIVE GmbH & Co KG Domagkstraße 5 85551 Kirchheim (München)	Tel. +49 89 909552-10 Fax +49 89 909552-50 dtc-sued@sew-eurodrive.de
	West	SEW-EURODRIVE GmbH & Co KG Siemensstraße 1 40764 Langenfeld (Düsseldorf)	Tel. +49 2173 8507-30 Fax +49 2173 8507-55 dtc-west@sew-eurodrive.de
Drive Center	Berlin	SEW-EURODRIVE GmbH & Co KG Alexander-Meißner-Straße 44 12526 Berlin	Tel. +49 306331131-30 Fax +49 306331131-36 dc-berlin@sew-eurodrive.de
	Ludwigshafen	SEW-EURODRIVE GmbH & Co KG c/o BASF SE Gebäude W130 Raum 101 67056 Ludwigshafen	Tel. +49 7251 75 3759 Fax +49 7251 75 503759 dc-ludwigshafen@sew-eurodrive.de
	Saarland	SEW-EURODRIVE GmbH & Co KG Gottlieb-Daimler-Straße 4 66773 Schwalbach Saar – Hülzweiler	Tel. +49 6831 48946 10 Fax +49 6831 48946 13 dc-saarland@sew-eurodrive.de
	Ulm	SEW-EURODRIVE GmbH & Co KG Dieselstraße 18 89160 Dornstadt	Tel. +49 7348 9885-0 Fax +49 7348 9885-90 dc-ulm@sew-eurodrive.de

Germany

	Würzburg	SEW-EURODRIVE GmbH & Co KG Nürnbergerstraße 118 97076 Würzburg-Lengfeld	Tel. +49 931 27886-60 Fax +49 931 27886-66 dc-wuerzburg@sew-eurodrive.de
Drive Service Hotline / 24 Hour Service			0 800 SEWHELP 0 800 7394357
Technical Offices	Augsburg	SEW-EURODRIVE GmbH & Co KG August-Wessels-Straße 29 86156 Augsburg	Tel. +49 821 22779-10 Fax +49 821 22779-50 tb-augsburg@sew-eurodrive.de
	Lake Constance	SEW-EURODRIVE GmbH & Co KG Dornierstraße 4 88677 Markdorf	Tel. +49 7544 96590-90 Fax +49 7544 96590-99 tb-bodensee@sew-eurodrive.de
	Bremen	SEW-EURODRIVE GmbH & Co KG Bornstr.19 ... 22 28195 Bremen	Tel. +49 421 33918-10 Fax +49 421 33918-22 tb-bremen@sew-eurodrive.de
	Dortmund	SEW-EURODRIVE GmbH & Co KG Hildastraße 8 44145 Dortmund	Tel. +49 231 229028-10 Fax +49 231 229028-20 tb-dortmund@sew-eurodrive.de
	Dresden	SEW-EURODRIVE GmbH & Co KG Hauptstraße 32 01445 Radebeul	Tel. +49 351 26338-0 Fax +49 351 26338-38 tb-dresden@sew-eurodrive.de
	Erfurt	SEW-EURODRIVE GmbH & Co KG Dubliner Straße 12 99091 Erfurt	Tel. +49 361 21709-70 Fax +49 361 21709-79 tb-erfurt@sew-eurodrive.de
	Güstrow	SEW-EURODRIVE GmbH & Co KG Glasewitzer Chaussee 33 B 18273 Güstrow P.O. Box Postfach 1216 – D-18262 Güstrow	Tel. +49 3843 8557-80 Fax +49 3843 8557-88 tb-guestrow@sew-eurodrive.de
	Hamburg	SEW-EURODRIVE GmbH & Co KG Bramfelder Straße 119 22305 Hamburg	Tel. +49 40 298109-60 Fax +49 40 298109-70 tb-hamburg@sew-eurodrive.de
	Hannover / Garbsen	SEW-EURODRIVE GmbH & Co KG Alte Ricklinger Str.40-42 30823 Garbsen	Tel. +49 5137 8798-10 Fax +49 5137 8798-50 tb-hannover@sew-eurodrive.de
	Heilbronn	SEW-EURODRIVE GmbH & Co KG Zeppelinstraße 7 74357 Bönningheim	Tel. +49 7143 8738-0 Fax +49 7143 8738-25 tb-heilbronn@sew-eurodrive.de
	Herford	SEW-EURODRIVE GmbH & Co KG Goebenstraße 3 – 7 32052 Herford	Tel. +49 5221 9141-0 Fax +49 5221 9141-20 tb-herford@sew-eurodrive.de
	Karlsruhe	SEW-EURODRIVE GmbH & Co KG Ettlinger Weg 2 76467 Bietigheim P.O. Box Postfach 43 – D-76463 Bietigheim	Tel. +49 7245 9190-10 Fax +49 7245 9190-20 tb-karlsruhe@sew-eurodrive.de
	Kassel	SEW-EURODRIVE GmbH & Co KG Sonnenweg 3 34260 Kaufungen	Tel. +49 561 95144-80 Fax +49 561 95144-90 tb-kassel@sew-eurodrive.de
	Koblenz	SEW-EURODRIVE GmbH & Co KG Carl-Benz-Straße 8 56218 Mülheim-Kärlich	Tel. +49 2630 91930-10 Fax +49 2630 91930-90 tb-koblenz@sew-eurodrive.de
	Lahr	SEW-EURODRIVE GmbH & Co KG Europastraße 3/1 77933 Lahr / Schwarzwald	Tel. +49 7821 90999-60 Fax +49 7821 90999-79 tb-lahr@sew-eurodrive.de
	Langenfeld	SEW-EURODRIVE GmbH & Co KG Siemensstraße 1 40764 Langenfeld	Tel. +49 2173 8507-10 Fax +49 2173 8507-50 tb-langenfeld@sew-eurodrive.de
	Magdeburg	SEW-EURODRIVE GmbH & Co KG Breiteweg 53 39179 Barleben	Tel. +49 39203 7577-1 Fax +49 39203 7577-9 tb-magdeburg@sew-eurodrive.de
	Mannheim	SEW-EURODRIVE GmbH & Co KG Besselstraße 26 68219 Mannheim	Tel. +49 621 71683-10 Fax +49 621 71683-22 tb-mannheim@sew-eurodrive.de

München	SEW-EURODRIVE GmbH & Co KG Domagkstraße 5 85551 Kirchheim	Tel. +49 89 90955-110 Fax +49 89 90955-150 tb-muenchen@sew-eurodrive.de
Münster	SEW-EURODRIVE GmbH & Co KG Hafenplatz 4 48155 Münster	Tel. +49 251 41475-11 Fax +49 251 41475-50 tb-muenster@sew-eurodrive.de
Nuremberg	SEW-EURODRIVE GmbH & Co KG Lina-Ammon-Straße 22 90471 Nürnberg	Tel. +49 911 98884-50 Fax +49 911 98884-60 tb-nuernberg@sew-eurodrive.de
Regensburg	SEW-EURODRIVE GmbH & Co KG Im Gewerbepark A15 93059 Regensburg	Tel. +49 941 46668-68 Fax +49 941 46668-66 tb-regensburg@sew-eurodrive.de
Rhine-Main	SEW-EURODRIVE GmbH & Co KG Niederstedter Weg 5 61348 Bad Homburg	Tel. +49 6172 9617-0 Fax +49 6172 9617-50 tb-rheinmain@sew-eurodrive.de
Stuttgart	SEW-EURODRIVE GmbH & Co KG Friedrich-List-Straße 46 70771 Leinfelden-Echterdingen	Tel. +49 711 16072-0 Fax +49 711 16072-72 tb-stuttgart@sew-eurodrive.de
Zwickau / Meerane	SEW-EURODRIVE GmbH & Co KG Dankritzer Weg1 08393 Meerane	Tel. +49 3764 7606-0 Fax +49 3764 7606-20 tb-zwickau@sew-eurodrive.de

Great Britain

Assembly Sales Service	Normanton	SEW-EURODRIVE Ltd. DeVilliers Way Trident Park Normanton West Yorkshire WF6 1GX	Tel. +44 1924 893-855 Fax +44 1924 893-702 http://www.sew-eurodrive.co.uk info@sew-eurodrive.co.uk
		Drive Service Hotline / 24 Hour Service	Tel. 01924 896911

Service Competence Center	Southern Eng- land	SEW-EURODRIVE Ltd. Unit 41 Easter Park Benyon Road Silchester Reading Berkshire RG7 2PQ	Tel. +44 1189 701-699 Fax +44 1189 701-021
------------------------------	-----------------------	--	---

Technical Offices	Midlands	SEW-EURODRIVE Ltd. 5 Sugar Brook court Aston Road Bromsgrove Worcs. B60 3EX	Tel. +44 1527 877-319 Fax +44 1527 575-245
-------------------	----------	--	---

	Scotland	SEW-EURODRIVE Ltd. No 37 Enterprise House Springkerse Business Park Stirling FK7 7UF	Tel. +44 17 8647-8730 Fax +44 17 8645-0223
--	----------	--	---

	Northern Ire- land	Heyn Engineering (NI) Ltd. 1 Corry Place, Belfast, BT3 9AH	Tel. +44 02890350022 Fax +44 02890350012 http://www.heyne.co.uk info@heyne.co.uk
--	-----------------------	---	--

Greece

Sales	Athens	Christ. Boznos & Son S.A. 12, K. Mavromichali Street P.O. Box 80136 18545 Piraeus	Tel. +30 2 1042 251-34 Fax +30 2 1042 251-59 http://www.boznos.gr info@boznos.gr
-------	--------	--	--

Technical Office	Thessaloniki	Christ. Boznos & Son S.A. Asklipiou 26 562 24 Evosmos, Thessaloniki	Tel. +30 2 310 7054-00 Fax +30 2 310 7055-15 info@boznos.gr
------------------	--------------	---	---

Hungary

Sales Service	Budapest	SEW-EURODRIVE Kft. Csillaghegyi út 13. 1037 Budapest	Tel. +36 1 437 06-58 Fax +36 1 437 06-50 http://www.sew-eurodrive.hu office@sew-eurodrive.hu
------------------	----------	--	---

Iceland

Sales	Reykjavik	Varma & Vélaverk ehf. Knarrarvogi 4 104 Reykjavik	Tel. +354 585 1070 Fax +354 585)1071 http://www.varmaverk.is vov@vov.is
-------	-----------	---	--

India

Registered Office Assembly Sales Service	Vadodara	SEW-EURODRIVE India Private Limited Plot No. 4, GIDC POR Ramangamdi • Vadodara - 391 243 Gujarat	Tel. +91 265 3045200 Fax +91 265 3045300 http://www.seweurodriveindia.com salesvadodara@seweurodriveindia.com
Assembly Sales Service	Chennai	SEW-EURODRIVE India Private Limited Plot No. K3/1, Sipcot Industrial Park Phase II Mambakkam Village Sriperumbudur - 602105 Kancheepuram Dist, Tamil Nadu	Tel. +91 44 37188888 Fax +91 44 37188811 saleschennai@seweurodriveindia.com
	Pune	SEW-EURODRIVE India Private Limited Plant: Plot No. D236/1, Chakan Industrial Area Phase- II, Warale, Tal- Khed, Pune-410501, Maharashtra	Tel. +91 21 35 628700 Fax +91 21 35 628715 salespune@seweurodriveindia.com
Technical Offices	Ahmedabad	SEW-EURODRIVE India Private Limited 306, Shaan office complex, Behind Sakar-IV, Ellisebridge, Ashram Road Ahmedabad – 380006, Gujarat	Tel. +91 79 40072067 / 68 Fax +91 79 40072069 salesahmedabad@seweurodriveindia.com
	Aurangabad	SEW-EURODRIVE India Private Limited Flat.No.403 , Prism Appt. The Venus Housing Society. Beed Bypass Road, Behind Nishant Park Hotel, Aurangabad – 431003, Maharashtra.	Tel. +91 86000 12333 salesaurangabad@seweurodriveindia.com
	Bangalore	SEW-EURODRIVE India Private Limited Sy.no:41-P3, Peenya1, Phase 1A, Peenya Vil- lage, Yeswanthapura Hobli, Bangalore North Taluk, Bangalore - 560058, Karnataka	Tel. +91 80 28370664 Fax +91 80 28370665 salesbangalore@seweurodriveindia.com
	Bangalore	SEW-EURODRIVE India Private Limited # C-104, 3rd Block, KSSIDC Complex, Electronic City. Bangalore – 560100, Karnataka	Tel. +91 80 28522662 / 28522663 salesbangalore@seweurodriveindia.com
	Bangladesch	SEW-EURODRIVE India Private Limited Genetic Udayanchal, House-96 (6th Floor), Road-23/A, Block-B, Banani, Dhaka-1213, Bangladesh	Tel. +88 01729 097309 salesdhaka@seweurodrivebangladesh.com
	Bellary	SEW-EURODRIVE India Private Limited Door no-56/279 Ward No-15, Sindhigi compound, Near Raghavendra talkies, Bellary-583101, Karnataka	Tel. +91 77609 88668 salesbellary@seweurodriveindia.com
	Chandigarh	SEW-EURODRIVE India Private Limited #699, Type -3, Power Colony, Chandigarh - Rupnagar Highway Rupnagar - 140001, Punjab	Tel. +91 81462 67606 saleschandigarh@seweurodriveindia.com
	Chennai	SEW-EURODRIVE India Private Limited 2nd Floor, Josmans Complex, No. 5, McNichols Road, Chetpet Chennai - 600031, Tamil Nadu	Tel. +91 44 42849812 / 13 / 14 / 15 Fax +91 44 42849816 saleschennai@seweurodriveindia.com
	Kochi	SEW-EURODRIVE India Private Limited House No: 30/1168 A Kaniyampuzha Road Vytila Post Office Cochin – 682019, Kerala	Tel. +91 98951 30375 salescochin@seweurodriveindia.com
	Coimbatore	SEW-EURODRIVE India Private Limited 687/2, Sri Sakthivel Towers (Near Deepam Hospital) Trichy Road, Ramanathapuram Coimbatore - 641 045, Tamil Nadu	Tel. +91 422 2322420 Fax +91 422 2323988 salescoimbatore@seweurodriveindia.com

Cuttack	SEW-EURODRIVE India Private Limited Plot No.: F/56, Chandaka Industrial Estate, P.O.- K I I T, Bhubaneswar – 751024. Orissa	Tel. +91 9937446333 salescuttack@seweurodriveindia.com
Faridabad	SEW-EURODRIVE India Private Limited H.No.: -1172 ,Sector-9 , Near St Anthony School Faridabad 121006	Tel. +91 99580 09275 salesfaridabad@seweurodriveindia.com
Gandhidham	SEW-EURODRIVE India Private Limited TCX-S-28, FF, Ward 12/A, Gandhidham - 370201, Kutch - Gujarat	Tel. +91 81282 36850 salesgandhidham@seweurodriveindia.com
Gandhinagar	SEW-EURODRIVE India Private Limited Office No. 304, Siddhraj Zavod, Between Kh-0 & G-0 Circle, Sarkhej Gandhinagar Highway, Sargasan, Gandhinagar – 382423	Tel. +91 787 8601656 salesgandhinagar@seweurodriveindia.com
Gurgaon	SEW-EURODRIVE India Private Limited 136, Hope Appartment, Sec. 15, Part – II, Jharsa Road, Near Reliance Fresh, Gurgaon-122001, Haryana	Tel. +91 99588 78855 salesgurgaon@seweurodriveindia.com
Hyderabad	SEW-EURODRIVE India Private Limited 408, 4th Floor, Meridian Place Green Park Road, Amerpet Hyderabad - 500016, Telangana	Tel. +91 40 23414698 Fax +91 40 23413884 saleshyderabad@seweurodriveindia.com
Indore	SEW-EURODRIVE India Private Limited 103, Abhishek Avenue, Slide-4, Sch. No. 78, Indore - 452010, Madhya Pradesh	Tel. +91 97524 12068 salesindore@seweurodriveindia.com
Jamshedpur	SEW-EURODRIVE India Private Limited Flat No :- S1 "Kashi Kunj",h. No. 60, New Rani Kudar Road No - 3, P.o. + P.s. - Kadma Jamshedpur - 831005, Jharkhand	Tel. +91 99341 23671 salesjamshedpur@seweurodriveindia.com
Kolhapur	SEW-EURODRIVE India Private Limited C/O. Mr.S.V.Pawar.461/37, Abhideep Resid- ency, Opp-Shriram Petrol Pump, Kasaba Bawada, Kolhapur - 416 122, Maharashtra	Tel. +91 86000 20846 saleskolhapur@seweurodriveindia.com
Kolkata	SEW-EURODRIVE India Private Limited 2nd floor, Room No. 35 Chowringhee Court 55, Chowringhee Road Kolkata - 700 071, West Bengal	Tel. +91 33 22827457 Fax +91 33 22894204 saleskolkata@seweurodriveindia.com
Lucknow	SEW-EURODRIVE India Private Limited 69, Shiv Vihar Colony Vikas Nagar – Sector 5 Lucknow - 226022, Uttar Pradesh	Tel. +91 97936 27333 saleslucknow@seweurodriveindia.com
Mumbai	SEW-EURODRIVE India Private Limited 312 A, 3rd Floor, Acme Plaza, J.B. Nagar, Andheri Kurla Road, Andheri (E) Mumbai - 400059, Maharashtra	Tel. +91 22 28348440 Fax +91 22 28217858 salesmumbai@seweurodriveindia.com
Nagpur	SEW-EURODRIVE India Private Limited Plot No 49, New Kailash Nager, Samta colony, Nagpur-440027, Maharashtra	Tel. +91 95610 89525 salesnagpur@seweurodriveindia.com
Nashik	SEW-EURODRIVE India Private Limited 107, "YOG" Bungalow, Mahatama Nagar, Trimbak Road, Nashik – 422 007, Maharashtra	Tel. +91 96657 52978 salesnashik@seweurodriveindia.com
New Delhi	SEW-EURODRIVE India Private Limited # B-206 DLF Towers-B District Centre Jasola New Delhi -110044	Tel. +91 11 26944551 Fax +91 11 26944467 salesdelhi@seweurodriveindia.com
Navi Mumbai	SEW-EURODRIVE India Private Limited No.202, Shivam Yeshoram Plot No. 262/257, Sector 19 Kopar Khairane, Navi Mumbai - 400 709, Maharashtra	Tel. +91 99677 21324 salesmumbai@seweurodriveindia.com

Pondicherry	SEW-EURODRIVE India Private Limited Plot No 1, Flat No S2, Shubhamangala Apartment, 14th Cross Extension, Krishna Nagar, Pondicherry 605008	Tel. +91 9840971370 salespondicherry@seweurodriveindia.com
Pune	SEW-EURODRIVE India Private Limited Plot No. 7, "Shri Shantadurga Niwas" Shivaji Co-operative Housing Society Ltd., Behind J.W. Marriot. Off Senapati Bapat Marg. Pune -411 016, Maharashtra	Tel. +91 20 25635466 / 467 salespune@seweurodriveindia.com
Pune	SEW-EURODRIVE India Private Limited Jai Tuljabhavani Complex. Office No:- 15 First Floor, Opp. Century Enka Company, MIDC Bhosari, Pune 411 026	Tel. +91 20-65118890 / 91 Fax +91 20 25380721 salespune@seweurodriveindia.com
Raipur	SEW-EURODRIVE India Private Limited A-42, Ashoka Millenium Complex, Ring Road-1, Raipur 492 001 - Chhattisgarh	Tel. +91 771 4090765 Fax +91 771 4090765 salesraipur@seweurodriveindia.com
Ranchi	SEW-EURODRIVE India Private Limited 1D- Shail Madhuri Apartment, Near Kokar Pool, H.B Road, Kokar Ranchi - 834001, Jharkhand.	Tel. +91 82946 30772 salesranchi@seweurodriveindia.com
Tiruchirappalli	SEW-EURODRIVE India Private Limited Plot No.24, Door No.64A Rajaram Salai, K.K Nagar Trichy-620 021, Tamilnadu	Tel. +91 97899 79855 salestrichy@seweurodriveindia.com
Vadodara	SEW-EURODRIVE India Private Limited Unit No. 301, Savorite Bldg, Plot No. 143, Vinayak Society, off old Padra Road, Vadodara - 390 007, Gujarat	Tel. +91 265 2325258 / 6560482 salesvadodara@seweurodriveindia.com
Vizag	SEW-EURODRIVE India Private Limited D.No.7-13-50/1, Near Padmaja hospital, Ramalayam street, Chittinaidu colony, Old gajuwaka, Visakhapatnam - 530026, Andhra Pradesh	Tel. +91 99895 01748 salesvizag@seweurodriveindia.com

Indonesia

Sales	Medan	PT. Serumpun Indah Lestari Jl.Pulau Solor no. 8, Kawasan Industri Medan II Medan 20252	Tel. +62 61 687 1221 Fax +62 61 6871429 / +62 61 6871458 / +62 61 30008041 sil@serumpunindah.com serumpunindah@yahoo.com http://www.serumpunindah.com
	Jakarta	PT. Cahaya Sukses Abadi Komplek Rukan Puri Mutiara Blok A no 99, Sunter Jakarta 14350	Tel. +62 21 65310599 Fax +62 21 65310600 csajkt@cbn.net.id
	Jakarta	PT. Agrindo Putra Lestari Jl.Pantai Indah Selatan, Komplek Sentra Industri Terpadu, Pantai indah Kapuk Tahap III, Blok E No. 27 Jakarta 14470	Tel. +62 21 2921-8899 Fax +62 21 2921-8988 aplindo@indosat.net.id http://www.aplindo.com
	Surabaya	PT. TRIAGRI JAYA ABADI Jl. Sukosemolo No. 63, Galaxi Bumi Permai G6 No. 11 Surabaya 60111	Tel. +62 31 5990128 Fax +62 31 5962666 sales@triagri.co.id http://www.triagri.co.id
	Surabaya	CV. Multi Mas Jl. Raden Saleh 43A Kav. 18 Surabaya 60174	Tel. +62 31 5458589 Fax +62 31 5317220 sianhwa@sby.centrin.net.id http://www.cvmultimas.com

Ireland

Sales Service	Dublin	Alpert Engineering Ltd. 48 Moyle Road Dublin Industrial Estate Glasnevin, Dublin 11	Tel. +353 1 830-6277 Fax +353 1 830-6458 http://www.alpert.ie info@alpert.ie
---------------	--------	--	---

Israel			
Sales	Tel Aviv	Liraz Handasa Ltd. Ahofer Str 34B / 228 58858 Holon	Tel. +972 3 5599511 Fax +972 3 5599512 http://www.liraz-handasa.co.il office@liraz-handasa.co.il
Italy			
Assembly Sales Service	Milan	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Via Bernini,14 20020 Solaro (Milano)	Tel. +39 02 96 980229 Fax +39 02 96 980 999 http://www.sew-eurodrive.it milano@sew-eurodrive.it
Drive Center	Bologna	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Via della Grafica, 47 40064 Ozzano dell'Emilia (Bo)	Tel. +39 051 65-23-801 Fax +39 02 96 980 499 bologna@sew-eurodrive.it
	Caserta	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Viale Carlo III Km. 23,300 81020 S. Nicola la Strada (Caserta)	Tel. +39 0823 219011 Fax +39 02 96 980 599 caserta@sew-eurodrive.it
	Pescara	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Viale Europa,132 65010 Villa Raspa di Spoltore (PE)	Tel. +39 085 41-59-427 Fax +39 02 96 980 699 pescara@sew-eurodrive.it
	Turin	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Filiale Torino c.so Unione Sovietica 612/15 - int. C 10135 Torino	Tel. +39 011 3473780 Fax +39 02 96 980 799 torino@sew-eurodrive.it
	Verona	SEW-EURODRIVE di R. Blickle & Co.s.a.s. Via Antonio Meucci, 5 37042 - Caldiero (VR)	Tel. +39 045 89-239-11 Fax +39 02 96 980 814 verona@sew-eurodrive.it
Ivory Coast			
Sales	Abidjan	SEW-EURODRIVE SARL Ivory Coast Rue des Pêcheurs, Zone 3 26 BP 916 Abidjan 26	Tel. +225 21 21 81 05 Fax +225 21 25 30 47 info@sew-eurodrive.ci http://www.sew-eurodrive.ci
Japan			
Assembly Sales Service	Iwata	SEW-EURODRIVE JAPAN CO., LTD 250-1, Shimoman-no, Iwata Shizuoka 438-0818	Tel. +81 538 373811 Fax +81 538 373814 http://www.sew-eurodrive.co.jp sewjapan@sew-eurodrive.co.jp hamamatsu@sew-eurodrive.co.jp
Technical Offices	Fukuoka	SEW-EURODRIVE JAPAN CO., LTD C-go, 5th-floor, Yakuin-Hiruzu-Bldg. 1-5-11, Yakuin, Chuo-ku Fukuoka, 810-0022	Tel. +81 92 713-6955 Fax +81 92 713-6860 fukuoka@sew-eurodrive.co.jp
	Kyoto	SEW-EURODRIVE JAPAN CO., LTD Kyoto Operation Center 9-1-11 Seikadai, Seika-cho, Souraku-gun, Kyoto 619-0238	Tel. +81 774 98-2750 Fax +81 774 93-2100 sewjapan@sew-eurodrive.co.jp
	Osaka	SEW-EURODRIVE JAPAN CO., LTD Higobashi Shimizu Bldg. 10th floor 1-3-7 Tosabori, Nishi-ku Osaka, 550-0001	Tel. +81 6 6444-8330 Fax +81 6 6444-8338 osaka@sew-eurodrive.co.jp
	Tokio	SEW-EURODRIVE JAPAN CO., LTD Renai Partire Shiodome 5th floor 2-18-3 Higashi-Shinbashi, Minato-Ku, Tokyo 105-0021	Tel. +81 3 3239-0469 Fax +81 3 3239-0943 tokyo@sew-eurodrive.co.jp
Kazakhstan			
Sales	Almaty	SEW-EURODRIVE LLP 291-291A, Tole bi street 050031, Almaty	Tel. +7 (727) 350 5156 Fax +7 (727) 350 5156 http://www.sew-eurodrive.kz sew@sew-eurodrive.kz
	Tashkent	SEW-EURODRIVE LLP Representative office in Uzbekistan 96A, Sharaf Rashidov street, Tashkent, 100084	Tel. +998 71 2359411 Fax +998 71 2359412 http://www.sew-eurodrive.uz sew@sew-eurodrive.uz

	Ulaanbaatar	IM Trading LLC Olympic street 28B/3 Sukhbaatar district, Ulaanbaatar 14230	Tel. +976-77109997 Fax +976-77109997 imt@imt.mn
Technical Offices	Karagandy	SEW-EURODRIVE LLP 82, Molokov Street 100004, Karagandy	Tel. +7 (7212) 955 956 Fax +7 (7212) 955 956 karagandy@sew-eurodrive.kz
	Oskemen	SEW-EURODRIVE LLP 62 Satpaev ave. office 313 070016, Ust-Kamenogorsk	Tel. +7 (723) 291 37 48 (ext 760) Fax +7 (727) 350 5156 (ext 709) oskemen@sew-eurodrive.kz
	Aktobe	SEW-EURODRIVE LLP 52/1 Marat Ospanov str., office 11 030000, Aktobe	Tel. +7 (771) 993 0915 aktobe@sew-eurodrive.kz
Kenya			
Sales	Nairobi	SEW-EURODRIVE Pty Ltd Transnational Plaza, 5th Floor Mama Ngina Street P.O. Box 8998-00100 Nairobi	Tel. +254 791 398840 http://www.sew-eurodrive.co.tz info@sew.co.tz
Latvia			
Sales	Riga	SIA Alas-Kuul Katlakalna 11C 1073 Riga	Tel. +371 6 7139253 Fax +371 6 7139386 http://www.alas-kuul.lv info@alas-kuul.com
Lebanon			
Sales (Lebanon)	Beirut	Gabriel Acar & Fils sarl B. P. 80484 Bourj Hammoud, Beirut	Tel. +961 1 510 532 Fax +961 1 494 971 ssacar@inco.com.lb
Sales (Jordan, Kuwait , Beirut Saudi Arabia, Syria)		Middle East Drives S.A.L. (offshore) Sin El Fil. B. P. 55-378 Beirut	Tel. +961 1 494 786 Fax +961 1 494 971 http://www.medrives.com info@medrives.com
Lithuania			
Sales	Alytus	UAB Irseva Statybininku 106C 63431 Alytus	Tel. +370 315 79204 Fax +370 315 56175 http://www.irseva.lt irmantas@irseva.lt
Luxembourg			
Representation: Belgium			
Macedonia			
Sales	Skopje	Boznos DOOEL Dime Anicin 2A/7A 1000 Skopje	Tel. +389 23256553 Fax +389 23256554 http://www.boznos.mk
Malaysia			
Assembly Sales Service	Johor	SEW-EURODRIVE SDN BHD No. 95, Jalan Seroja 39, Taman Johor Jaya 81000 Johor Bahru, Johor West Malaysia	Tel. +60 7 3549409 Fax +60 7 3541404 sales@sew-eurodrive.com.my
Technical Offices	Kuala Lumpur	SEW-EURODRIVE SDN BHD No. 2, Jalan Anggerik Mokara 31/46 Kota Kemuning Seksyen 31 40460 Shah Alam Selangor Darul Ehsan West Malaysia	Tel. +60 3 51229633 Fax +60 3 51229622 sewsa@sew-eurodrive.com.my
	Penang	SEW-EURODRIVE SDN BHD No. 38, Jalan Bawal Kimsar Garden 13700 Prai, Penang West Malaysia	Tel. +60 4 3999349 Fax +60 4 3999348 sewpg@sew-eurodrive.com.my

Kuching	SEW-EURODRIVE SDN BHD No. 69, Lot 10899 1st Floor, Jalan Tun Jugah 93350 Kuching Sarawak East Malaysia	Tel. +60 82 572780 Fax +60 82 571780 sewswk@sew-eurodrive.com.my
Kota Kinabalu	SEW-EURODRIVE SDN BHD East Malaysia	Tel. +60 19 7539395 sales@sew-eurodrive.com.my
Ipoh	SEW-EURODRIVE SDN BHD West Malaysia	Tel. +60 19 7177366 sewsa@sew-eurodrive.com.my

Mexico

Assembly Sales Service	Quéretaro	SEW-EURODRIVE MEXICO S.A. de C.V. SEM-981118-M93 Tequisquiapan No. 102 Parque Industrial Quéretaro C.P. 76220 Querétaro, México	Tel. +52 442 1030-300 Fax +52 442 1030-301 http://www.sew-eurodrive.com.mx scmexico@seweurodrive.com.mx
Sales Service	Puebla	SEW-EURODRIVE MEXICO S.A. de C.V. Calzada Zavaleta No. 3922 Piso 2 Local 6 Col. Santa Cruz Buenavista C.P. 72154 Puebla, México	Tel. +52 (222) 221 248 http://www.sew-eurodrive.com.mx scmexico@seweurodrive.com.mx

Mongolia

Technical Office	Ulaanbaatar	IM Trading LLC Olympic street 28B/3 Sukhbaatar district, Ulaanbaatar 14230	Tel. +976-77109997 Tel. +976-99070395 Fax +976-77109997 http://imt.mn/ imt@imt.mn
------------------	-------------	---	--

Morocco

Sales Service	Bouskoura	SEW-EURODRIVE Morocco Parc Industriel CFCIM, Lot 55 and 59 Bouskoura	Tel. +212 522 88 85 00 Fax +212 522 88 84 50 http://www.sew-eurodrive.ma sew@sew-eurodrive.ma
------------------	-----------	--	--

Namibia

Sales	Swakopmund	DB Mining & Industrial Services Einstein Street Strauss Industrial Park Unit1 Swakopmund	Tel. +264 64 462 738 Fax +264 64 462 734 anton@dbminingnam.com
-------	------------	--	--

Netherlands

Assembly Sales Service	Rotterdam	SEW-EURODRIVE B.V. Industrieweg 175 3044 AS Rotterdam Postbus 10085 3004 AB Rotterdam	Tel. +31 10 4463-700 Fax +31 10 4155-552 Service: 0800-SEWHELP http://www.sew-eurodrive.nl info@sew-eurodrive.nl
------------------------------	-----------	---	--

New Zealand

Assembly Sales Service	Auckland	SEW-EURODRIVE NEW ZEALAND LTD. P.O. Box 58-428 82 Greenmount drive East Tamaki Auckland	Tel. +64 9 2745627 Fax +64 9 2740165 http://www.sew-eurodrive.co.nz sales@sew-eurodrive.co.nz
	Christchurch	SEW-EURODRIVE NEW ZEALAND LTD. 30 Lodestar Avenue, Wigram Christchurch	Tel. +64 3 384-6251 Fax +64 3 384-6455 sales@sew-eurodrive.co.nz
Technical Office	Palmerston North	SEW-EURODRIVE NEW ZEALAND LTD. C/-Grant Shearman, RD 5, Aronui Road Palmerston North	Tel. +64 6 355-2165 Fax +64 6 355-2316 sales@sew-eurodrive.co.nz

Nigeria

Sales	Lagos	Greenpeg Nig. Ltd Plot 296A, Adeyemo Akapo Str. Omole GRA Ikeja Lagos-Nigeria	Tel. +234-701-821-9200-1 http://www.greenpeg ltd.com bolaji.adekunle@greenpeg ltd.com
-------	-------	---	---

Norway			
Assembly Sales Service	Moss	SEW-EURODRIVE A/S Solgaard skog 71 1599 Moss	Tel. +47 69 24 10 20 Fax +47 69 24 10 40 http://www.sew-eurodrive.no sew@sew-eurodrive.no
Pakistan			
Sales	Karachi	Industrial Power Drives Al-Fatah Chamber A/3, 1st Floor Central Commercial Area, Sultan Ahmed Shah Road, Block 7/8, Karachi	Tel. +92 21 452 9369 Fax +92-21-454 7365 seweurodrive@cyber.net.pk
Paraguay			
Sales	Fernando de la Mora	SEW-EURODRIVE PARAGUAY S.R.L De la Victoria 112, Esquina nueva Asunción Departamento Central Fernando de la Mora, Barrio Bernardino	Tel. +595 991 519695 Fax +595 21 3285539 sewpy@sew-eurodrive.com.py
Peru			
Assembly Sales Service	Lima	SEW EURODRIVE DEL PERU S.A.C. Los Calderos, 120-124 Urbanizacion Industrial Vulcano, ATE, Lima	Tel. +51 1 3495280 Fax +51 1 3493002 http://www.sew-eurodrive.com.pe sewperu@sew-eurodrive.com.pe
Philippines			
Sales	Makati	P.T. Cerna Corporation 4137 Ponte St., Brgy. Sta. Cruz Makati City 1205	Tel. +63 2 519 6214 Fax +63 2 890 2802 mech_drive_sys@ptcerna.com http://www.ptcerna.com
Poland			
Assembly Sales Service	Łódź	SEW-EURODRIVE Polska Sp.z.o.o. ul. Techniczna 5 92-518 Łódź	Tel. +48 42 293 00 00 Fax +48 42 293 00 49 http://www.sew-eurodrive.pl sew@sew-eurodrive.pl
	Service	Tel. +48 42 293 0030 Fax +48 42 293 0043	24 Hour Service Tel. +48 602 739 739 (+48 602 SEW SEW) serwis@sew-eurodrive.pl
Technical Offices	Tychy	SEW-EURODRIVE Polska Sp.z.o.o. ul. Strzelecka 66 43-109 Tychy	Tel. +48 32 32 32 610 Fax +48 32 32 32 648
	Bydgoszcz	SEW-EURODRIVE Polska Sp.z.o.o. ul. Fordońska 246 85-766 Bydgoszcz	Tel.+48 52 567 30 00 Fax +48 52 567 30 09
	Gdansk	SEW-EURODRIVE Polska Sp.z.o.o. ul. Galaktyczna 30A 80-299 Gdańsk	Tel. +48 58 762 70 00 Fax +48 58 762 70 09
	Posen	SEW-EURODRIVE Polska Sp.z.o.o. ul. Wschodnia 7B 62-080 Swadzim k. Poznania	Tel. +48 61 6465500 Fax +48 61 6465519
	Radom	SEW-EURODRIVE Polska Sp.z.o.o. ul. Słowackiego 84 26-600 Radom	Tel. +48 48 679 47 00 Fax +48 48 679 47 09
	Rzeszów	SEW-EURODRIVE Polska Sp.z.o.o. ul. Armii Krajowej 80 35-307 Rzeszów	Tel. +48 17 784 27 00 Fax +48 17 784 27 09
Portugal			
Assembly Sales Service	Coimbra	SEW-EURODRIVE, LDA. Av. da Fonte Nova, n.º 86 3050-379 Mealhada	Tel. +351 231 20 9670 Fax +351 231 20 3685 http://www.sew-eurodrive.pt infosew@sew-eurodrive.pt
Service Competence Center	Lisbon	SEW-EURODRIVE, LDA. Núcleo Empresarial I de São Julião do Tojal Rua de Entremuros, 54 Fracção I 2660-533 São Julião do Tojal	Tel. +351 21 958-0198 / +351 939 598 717 Fax +351 21 958-0245 esc.lisboa@sew-eurodrive.pt

Technical Office	Porto	SEW-EURODRIVE, LDA. Rua Monte da Bela, N.º 191, Fração X 4445-294 Ermesinde	Tel. +351 229 350 383 / +351 932 559 110 Fax +351 229 350 384 esc.porto@sew-eurodrive.pt
------------------	-------	---	--

Romania

Sales Service	Bucharest	Sialco Trading SRL str. Brazilia nr. 36 011783 Bucuresti	Tel. +40 21 230-1328 Fax +40 21 230-7170 sialco@sialco.ro
------------------	-----------	--	---

Russia

Assembly Sales Service	St. Petersburg	ЗАО «СЕВ-ЕВРОДРАЙФ» а. я. 36 195220 Санкт-Петербург	Tel. +7 812 3332522 / +7 812 5357142 Fax +7 812 3332523 http://www.sew-eurodrive.ru sew@sew-eurodrive.ru
------------------------------	----------------	---	---

Technical Offices	Ekaterinburg	ЗАО «СЕВ-ЕВРОДРАЙФ» Kominterna Str. 16 Office 614 620078 Ekaterinburg	Tel. +7 343 310 3977 Fax +7 343 310 3978 eso@sew-eurodrive.ru
	Irkutsk	ЗАО «СЕВ-ЕВРОДРАЙФ» 5-Armii Str., 31 664011 Irkutsk	Tel. +7 3952 25 5880 Fax +7 3952 25 5881 iso@sew-eurodrive.ru
	Moscow	ЗАО «СЕВ-ЕВРОДРАЙФ» Malaja Semjonovskaja Str. д. 9, корпус 2 107023 Moskau	Tel. +7 495 9337090 Fax +7 495 9337094 mso@sew-eurodrive.ru
	Novosibirsk	ЗАО «СЕВ-ЕВРОДРАЙФ» pr. K Marksa 30 630087 Novosibirsk	Tel. +7 383 3350200 Fax +7 383 3462544 nso@sew-eurodrive.ru
	Perm	ЗАО «СЕВ-ЕВРОДРАЙФ» Stakhanovskaya str., 45 Office 512 614066 Perm	Tel. +7 342 2219494 Fax +7 342 2219444 pso@sew-eurodrive.ru
	Togliatti	ЗАО «СЕВ-ЕВРОДРАЙФ» Sportivnaya Str. 4B, office 2 Samarskaya obl. 445057 Togliatti	Tel. +7 8482 710529 Fax +7 8482 810590 tso@sew-eurodrive.ru

Zambia

Representation: South Africa

Senegal

Sales	Dakar	SENEMECA Mécanique Générale Km 8, Route de Rufisque B.P. 3251, Dakar	Tel. +221 338 494 770 Fax +221 338 494 771 http://www.senemeca.com senemeca@senemeca.sn
-------	-------	---	--

Serbia

Sales	Belgrade	DIPAR d.o.o. Ustanicka 128a PC Košum, IV floor 11000 Beograd	Tel. +381 11 347 3244 / +381 11 288 0393 Fax +381 11 347 1337 office@dipar.rs
-------	----------	---	---

Singapore

Assembly Sales Service	Singapore	SEW-EURODRIVE PTE. LTD. No 9, Tuas Drive 2 Jurong Industrial Estate Singapore 638644	Tel. +65 68621701 Fax +65 68612827 http://www.sew-eurodrive.com.sg sewsingapore@sew-eurodrive.com
------------------------------	-----------	---	--

Slovakia

Sales	Bratislava	SEW-Eurodrive SK s.r.o. Rybničná 40 831 06 Bratislava	Tel. +421 2 33595 202, 217, 201 Fax +421 2 33595 200 http://www.sew-eurodrive.sk sew@sew-eurodrive.sk
	Košice	SEW-Eurodrive SK s.r.o. Slovenská ulica 26 040 01 Košice	Tel. +421 55 671 2245 Fax +421 55 671 2254 Mobile +421 907 671 976 sew@sew-eurodrive.sk

Slovenia			
Sales Service	Celje	Pakman - Pogonska Tehnika d.o.o. Ul. XIV. divizije 14 3000 Celje	Tel. +386 3 490 83-20 Fax +386 3 490 83-21 pakman@siol.net
South Africa			
Assembly Sales Service	Johannesburg	SEW-EURODRIVE (PROPRIETARY) LIMITED Eurodrive House Cnr. Adcock Ingram and Aerodrome Roads Aeroton Ext. 2 Johannesburg 2013 P.O.Box 90004 Bertsham 2013	Tel. +27 11 248-7000 Fax +27 11 248-7289 http://www.sew.co.za info@sew.co.za
	Cape Town	SEW-EURODRIVE (PROPRIETARY) LIMITED Rainbow Park Cnr. Racecourse & Omuramba Road Montague Gardens Cape Town P.O.Box 36556 Chempet 7442	Tel. +27 21 552-9820 Fax +27 21 552-9830 Telex 576 062 bgriffiths@sew.co.za
	Durban	SEW-EURODRIVE (PROPRIETARY) LIMITED 48 Prospecton Road Isipingo Durban P.O. Box 10433, Ashwood 3605	Tel. +27 31 902 3815 Fax +27 31 902 3826 cdejager@sew.co.za
	Nelspruit	SEW-EURODRIVE (PROPRIETARY) LIMITED 7 Christie Crescent Vintonia P.O.Box 1942 Nelspruit 1200	Tel. +27 13 752-8007 Fax +27 13 752-8008 robermeyer@sew.co.za
Technical Office	Port Elizabeth	SEW-EURODRIVE (PROPRIETARY) LIMITED 8 Ruan Access Park Old Cape Road Greenbushes 6000 Port Elizabeth	Tel. +27 41 3722246 Fax +27 41 3722247 http://www.sew.co.za fsieberhagen@sew-co-za
South Korea			
Assembly Sales Service	Ansan	SEW-EURODRIVE KOREA CO., LTD. 7, Dangjaengi-ro, Danwon-gu, Ansan-si, Gyeonggi-do, Zip 425-839	Tel. +82 31 492-8051 Fax +82 31 492-8056 http://www.sew-eurodrive.kr master.korea@sew-eurodrive.com
	Busan	SEW-EURODRIVE KOREA CO., LTD. 28, Noksansandan 262-ro 50beon-gil, Gangseo-gu, Busan, Zip 618-820	Tel. +82 51 832-0204 Fax +82 51 832-0230
Technical Offices	Daegu	SEW-EURODRIVE KOREA CO., LTD. No.303 Sungan officetel, 1834, Dalgubeol-daero, Dalseo-gu, Daegu, Zip 704-712	Tel. +82 53 650-7111 Fax +82 53 650-7112
	Daejeon	SEW-EURODRIVE KOREA CO., LTD. No.302 Hongin officetel, 28, Daehak-ro, Yuseong-gu, Daejeon, Zip 305-710	Tel. +82 42 828-6461 Fax +82 42 828-6463
	Gwangju	SEW-EURODRIVE KOREA CO., LTD. 5fl., Hyundai B/D B, 40, Bungmun-daero, Buk-gu, Gwangju, Zip 500-855	Tel. +82 62 511-9172 Fax +82 62 511-9174
	Seoul	SEW-EURODRIVE KOREA CO., LTD. No.1804 Ace Hiend Tower 8th, 84, Gasam digital 1-ro, Geumcheon-gu, Seoul, Zip 153-797	Tel. +82 2 862-8051 Fax +82 2 862-8199
Spain			
Assembly Sales Service	Bilbao	SEW-EURODRIVE ESPAÑA, S.L. Parque Tecnológico, Edificio, 302 48170 Zamudio (Vizcaya)	Tel. +34 94 43184-70 http://www.sew-eurodrive.es sew.spain@sew-eurodrive.es

Technical Offices	Barcelona	SEW-EURODRIVE ESPAÑA, S.L. Avda. Francesc Macià, 60 – Planta 16, porta 1 Eix Macià – “Torre Milenium” 08208 Sabadell (Barcelona)	Tel. +34 93 7162200 Fax +34 93 7233007
	Madrid	SEW-EURODRIVE ESPAÑA, S.L. Gran Via. 48-2° A-D 28220 Majadahonda (Madrid)	Tel. +34 91 6342250 Fax +34 91 6340899
Sri Lanka			
Sales	Colombo	SM International (Pte) Ltd 254, Galle Raod Colombo 4, Sri Lanka	Tel. +94 1 2584887 Fax +94 1 2582981
Swaziland			
Sales	Manzini	C G Trading Co. (Pty) Ltd PO Box 2960 Manzini M200	Tel. +268 2 518 6343 Fax +268 2 518 5033 engineering@cgtrading.co.sz
Sweden			
Assembly Sales Service	Jönköping	SEW-EURODRIVE AB Gnejsvägen 6-8 553 03 Jönköping Box 3100 S-550 03 Jönköping	Tel. +46 36 34 42 00 Fax +46 36 34 42 80 http://www.sew-eurodrive.se jonkoping@sew.se
Sales	Gothemburg	SEW-EURODRIVE AB Gustaf Werners gata 8 421 32 Västra Frölunda	Tel. +46 31 709 68 80 Fax +46 31 709 68 93 goteborg@sew.se
	Stockholm	SEW-EURODRIVE AB Björkholmsvägen 10 141 46 Huddinge	Tel. +46 8 449 86 80 Fax +46 8 449 86 93 stockholm@sew.se
	Malmö	SEW-EURODRIVE AB Borrgatan 5 211 24 Malmö	Tel. +46 40 680 64 80 Fax +46 40 680 64 93 malmo@sew.se
	Skellefteå	SEW-EURODRIVE AB Trädgårdsgatan 8 931 31 Skellefteå	Tel. +46 910 71 53 80 Fax +46 910 71 53 93 skelleftea@sew.se
Switzerland			
Assembly Sales Service	Basel	Alfred Imhof A.G. Jurastrasse 10 4142 Münchenstein bei Basel	Tel. +41 61 417 1717 Fax +41 61 417 1700 http://www.imhof-sew.ch info@imhof-sew.ch
Technical Offices	Rhaetian Switzerland	Ivan Grumelli Z.I. Moulin du choc C 1122 Romanel-sur-Morges, VD	Tel. +41 79 725 4499 Fax +41 61 417 1700
	Bern / Solo- thurn	Rudolf Bühler Muntersweg 5 2540 Grenchen	Tel. +41 32 652 2339 Fax +41 32 652 2331
	Central Switzerland, Aargau	Armin Pfister Stierenweid 4950 Huttwil, BE	Tel. +41 62 962 54 55 Fax +41 62 962 54 56
	Zürich, Ticino	Gian-Michele Muletta Fischerstrasse 61 8132 Egg bei Zürich	Tel. +41 44 994 81 15 Fax +41 44 994 81 16
	Lake Con- stance and East Switzer- land	Markus Künzle Eichweg 4 9403 Goldach	Tel. +41 71 845 2808 Fax +41 71 845 2809
Taiwan			
Sales	Taipei	Ting Shou Trading Co., Ltd. 6F-3, No. 267, Sec. 2 Tung Huw S. Road Taipei	Tel. +886 2 27383535 Fax +886 2 27368268 Telex 27 245 sewtwn@ms63.hinet.net http://www.tingshou.com.tw

Taiwan			
	Nan Tou	Ting Shou Trading Co., Ltd. No. 55 Kung Yeh N. Road Industrial District Nan Tou 540	Tel. +886 49 255353 Fax +886 49 257878 sewtwn@ms63.hinet.net http://www.tingshou.com.tw
Tanzania			
Sales	Daressalam	SEW-EURODRIVE PTY LIMITED TANZANIA Plot 52, Regent Estate PO Box 106274 Dar Es Salaam	Tel. +255 0 22 277 5780 Fax +255 0 22 277 5788 http://www.sew-eurodrive.co.tz info@sew.co.tz
Thailand			
Assembly Sales Service	Chonburi	SEW-EURODRIVE (Thailand) Ltd. 700/456, Moo.7, Donhuaroh Muang Chonburi 20000	Tel. +66 38 454281 Fax +66 38 454288 sewthailand@sew-eurodrive.com
Technical Offices	Bangkok	SEW-EURODRIVE (Thailand) Ltd. 6th floor, TPS Building 1023, Phattanakarn Road Suanluang Bangkok, 10250	Tel. +66 2 7178149 Fax +66 2 7178152 sewthailand@sew-eurodrive.com
	Hat Yai	SEW-EURODRIVE (Thailand) Ltd. Hadyai Country Home Condominium 59/101 Soi.17/1 Rachas-Utid Road. Hadyai, Songkhla 90110	Tel. +66 74 359441 Fax +66 74 359442 sewthailand@sew-eurodrive.com
	Khon Kaen	SEW-EURODRIVE (Thailand) Ltd. 4th Floor, Kaow-U-HA MOTOR Bldg, 359/2, Mitraphab Road. Muang District Khonkaen 40000	Tel. +66 43 225745 Fax +66 43 324871 sewthailand@sew-eurodrive.com
Tunisia			
Sales	Tunis	T. M.S. Technic Marketing Service Zone Industrielle Mghira 2 Lot No. 39 2082 Fouchana	Tel. +216 79 40 88 77 Fax +216 79 40 88 66 http://www.tms.com.tn tms@tms.com.tn
Turkey			
Assembly Sales Service	Kocaeli-Gebze	SEW-EURODRIVE Hareket Sistemleri San. Ve TIC. Ltd. Sti Gebze Organize Sanayi Böl. 400 Sok No. 401 41480 Gebze Kocaeli	Tel. +90 262 9991000 04 Fax +90 262 9991009 http://www.sew-eurodrive.com.tr sew@sew-eurodrive.com.tr
Technical Offices	Adana	SEW-EURODRIVE Hareket	Tel. +90 533 491 81 77 / +90 542 660 34 89 Fax +90 262 999 10 09
	Ankara	SEW-EURODRIVE Hareket Sistemleri San. Ve TIC. Ltd. Sti 1368.Cadde Eminel İşmerkezi No: 18/68 İvogsan / Ankara	Tel. +90 312 385 33 90 Fax +90 312 385 32 58
	Bursa	SEW-EURODRIVE Hareket Sistemleri San. Ve TIC. Ltd. Sti Üçevler Mah. Bayraktepe Sok. Akay İş Merkezi Kat:3 No: 7/6 Nilüfer / Bursa	Tel. +90 224 443 45 60 Fax +90 224 443 45 58
	Istanbul	SEW-EURODRIVE Hareket Sistemleri San. Ve TIC. Ltd. Sti Tekstil Kent Ticaret Merkezi B-13 Blok No:70 Esenler / İstanbul	Tel. +90 262 9991000 04 Fax +90 262 9991009
	Izmir	SEW-EURODRIVE Hareket IAOSB Küçük Parseller Grubu Sosyal Tesis merkezi merkezi 10030 sokak No: 16 / 110 Kara Hasan Atılı İş Merkezi Kat :6 Çigli / İzmir	Tel. +90 232 469 62 64 Fax +90 232 433 61 05

United Arab Emirates

Sales Service	Dubai	SEW-EURODRIVE FZE PO Box 263835 Office No. S3A1SR03 Jebel Ali Free Zone – South, Dubai, United Arab Emirates	Tel. +971 (0)4 8806461 Fax +971 (0)4 8806464 http://www.sew-eurodrive.ae info@sew-eurodrive.ae
------------------	-------	--	--

Ukraine

Assembly Sales Service	Dnipropetrovsk	ООО «СЕВ-Евродрайв» ул. Рабочая, 23-В, офис 409 49008 Днепр	Tel. +380 56 370 3211 Fax +380 56 372 2078 http://www.sew-eurodrive.ua sew@sew-eurodrive.ua
Sales	Kiev	ООО «СЕВ-Евродрайв» ул. С.Олейника, 21 02068 Киев	Tel. +380 44 503 95 77 Fax +380 44 503 95 78 kso@sew-eurodrive.ua
	Ivano-Frankivsk	ООО «СЕВ-Евродрайв» ул. Независимости, 4, оф.303 76000 Ивано-Франковск	Tel. +380 342 725 190 Fax +380 342 725 191 ifso@sew-eurodrive.ua

Uruguay

Assembly Sales	Montevideo	SEW-EURODRIVE Uruguay, S. A. Jose Serrato 3569 Esquina Corumbe CP 12000 Montevideo	Tel. +598 2 21181-89 Fax +598 2 21181-90 sewuy@sew-eurodrive.com.uy
-------------------	------------	--	---

USA

Production Assembly Sales Service	Southeast Region	SEW-EURODRIVE INC. 1295 Old Spartanburg Highway P.O. Box 518 Lyman, S.C. 29365	Tel. +1 864 439-7537 Fax Sales +1 864 439-7830 Fax Production +1 864 439-9948 Fax Assembly +1 864 439-0566 Fax Confidential/HR +1 864 949-5557 http://www.seweurodrive.com cslyman@seweurodrive.com
Assembly Sales Service	Northeast Region	SEW-EURODRIVE INC. Pureland Ind. Complex 2107 High Hill Road, P.O. Box 481 Bridgeport, New Jersey 08014	Tel. +1 856 467-2277 Fax +1 856 845-3179 csbridgeport@seweurodrive.com
	Midwest Region	SEW-EURODRIVE INC. 2001 West Main Street Troy, Ohio 45373	Tel. +1 937 335-0036 Fax +1 937 332-0038 cstroy@seweurodrive.com
	Southwest Region	SEW-EURODRIVE INC. 3950 Platinum Way Dallas, Texas 75237	Tel. +1 214 330-4824 Fax +1 214 330-4724 csdallas@seweurodrive.com
	Western Region	SEW-EURODRIVE INC. 30599 San Antonio St. Hayward, CA 94544	Tel. +1 510 487-3560 Fax +1 510 487-6433 cshayward@seweurodrive.com
	Wellford	SEW-EURODRIVE INC. 148/150 Finch Rd. Wellford, S.C. 29385	Tel. +1 864 439-7537 Fax +1 864 661 1167 IGOrders@seweurodrive.com

Additional addresses for service provided on request!

Vietnam

Sales	Ho Chi Minh City	SEW-EURODRIVE PTE. LTD. RO at Hochim- inh City Floor 8, KV I, Loyal building, 151-151 Bis Vo Thi Sau street, ward 6, District 3, Ho Chi Minh City, Vietnam	Tel. +84 937 299 700 Fax huytam.phan@sew-eurodrive.com
	Hanoi	MICO LTD Quảng Trị - North Vietnam / All sectors except Construction Materials 8th Floor, Ocean Park Building, 01 Dao Duy Anh St, Ha Noi, Viet Nam	Tel. +84 4 39386666 Fax +84 4 3938 6888 nam_ph@micogroup.com.vn http://www.micogroup.com.vn

Index

A

Abbreviation Key	42
Adapter	14
Adapter for mounting of	
IEC motors	143
NEMA motors	146
Servomotors	148
Additional documentation	8
Additional documentation for	
Project Planning for Drives	42
Agitator drive	
Strength class of the screws	151
Agitator gear unit	21

B

Backstop	14
Bearing greases	107
Brakemotors	13
Breather valve	124, 175
Compound gear unit	60
Breather valve in motor flange	62

C

Centering shoulder	14
Certification	13
Changing the mounting position	62
Churning losses	47
Combination options	171
Combinations, possible	
Structure of the tables	171
Compound gear unit	
Breather valve	60
Oil drain plug	60
Oil level plug	60
Screw plug bore	60
Condition monitoring	24
DUO 10A	19
Oil aging sensor	19
Vibration SmartCheck	19
Copyright notice	9

D

Designs	
Helical gearmotors	32, 178

Helical-bevel gearmotors	35, 36, 37
Helical-worm gearmotors	39, 704
Parallel-shaft helical gearmotors	33, 359
SPIROPLAN® gearmotors	40, 811
Designs, possible	
SPIROPLAN® gear units	12
Diagnostic unit	
Oil aging sensor DUO10A	19
Vibration SmartCheck	19
Dismounting using the SEW-EURODRIVE as-	
sembly/disassembly kit	130
Drive and gear unit selection data	42
Drive solution	6
DUO 10A	
Technical data	165

E

Efficiency	47
Efficiency of R, F, K, S, W gear units	46
Encoder	26
Extended storage	18

F

Fixed safety cover	161
Part numbers and dimensions	162, 163, 164
Flange contours	
FAF.., KAF.., SAF.. and WAF	158
FF.., KF.., SF.. and WF..	156
RF.. and R..F	154
Force application - definition	55

G

Gear ratios, max. torques	
Structure of the tables	171
Gear unit mounting	151
Strength class	151
Gear units	
Extended storage	18
Gear units with hollow shaft	132
Special motor/gear unit combinations	133
Gear units with hollow shafts and key	
Installation/removal kit	126
Gearmotor	
Accessibility	11
Heat dissipation	11

Installation altitude.....	11
Noise	11
Painting	11
Grease filling	107

H

Heavy load range	8
Helical gear units	
Type designation	22
Helical gearmotors	
Designs	178
Mounting positions	72
Helical-Bevel Gear Units	
Type designation	23
Helical-bevel gearmotors	
Designs	35, 36, 37
Mounting positions	80
Variants	516
Helical-worm gear units	
Type designation	23
Helical-worm gearmotors	
Designs	39, 704
Mounting positions	93
Higher permitted overhung loads	
Gear units	55
Hollow shaft and key, mounting/dismounting	126

I

Installation altitude.....	11
Installation kit for gear units with hollow shaft and key.....	126
International markets	13

L

Light load range.....	8
Lubricant	
Compatibility with oil seal	109
Lubricant table	108
Lubricant fill quantities	119
Lubricant table	
Notes	108

M

Modular automation system	6
Motor	
Operating temperature	10

Motor flange	
Breather valve, oil drain plug.....	62
Motor mounting positions	105
Motor platform	14
Mounting gear units with hollow shaft and key	
Supplied fastening parts.....	126
Using the assembly/disassembly kit by SEW-EURODRIVE.....	128
Mounting of gear units.....	151
Mounting position	
Mounting position M0	62
Mounting position MX.....	62
Mounting position sheets, key	71
Mounting positions	
Helical gearmotors	72
Helical-bevel gearmotors.....	80
Helical-worm gearmotors	93
Overview	61
Parallel-shaft helical gearmotors	77
SPIROPLAN® gearmotors	99
Multi-stage gearmotors.....	59

N

NOCO® fluid.....	17
Notes on the gearmotor dimension sheets.....	174

O

Oil aging sensor	19
Oil aging sensor DUO10A	
Technical data	165
Oil drain plug	
Compound gear unit.....	60
Oil drain plug in motor flange	62
Oil expansion tank	20
Oil level plug	
Compound gear unit.....	60
Oil quantity	119
Oil seal	
Lubricant compatibility	109
Operating temperature	
Gear units	10
Motor	10
Options	
TorcLOC®	135
Type designation	24
Order information	66

Output designs	25	Shouldered hollow shaft with shrink disk.....	136
Overhung load		Helical-bevel gear unit.....	139
Permitted overhung load	53	Helical-worm gear unit.....	141
Reduced overhung load	53	Parallel-shaft helical gear units	137
Overhung load conversion, gear unit constants ..	56	Shrink disk connection	176
P		SPIROPLAN® gear units	
Parallel-shaft helical gear unit		Mounting position M0	62
Type designation	22	Type designation	24
Parallel-shaft helical gearmotors		SPIROPLAN® gearmotors	
Designs	33, 359	Designs	40, 811
Mounting positions	77	Mounting positions	99
Permitted axial load	55	Splined hollow shaft	176
Product names	9	Storage conditions.....	18
Project Planning for Drives		Strength class	
Additional documentation	42	Gear unit mounting.....	151
Multi-stage gearmotors.....	59	Structure of the selection tables	172
Project planning procedure	43	Surface protection	18
Project Planning for Gear Units		Swing base	14
Service factor	49	T	
R		Technical data	
R, F, K, S, W gear units		DUO 10A	165
Operating temperature	10	Oil aging sensor DUO10A	165
Reduced backlash gear units	12, 125	Vibration SmartCheck	167
Removal kit for gear units with hollow shaft and key		Thermal rating	47
.....	126	Tolerances.....	174
Rubber buffer for FA/FH/FV/FT	176	Shaft heights	174
S		Flanges.....	175
Safety cover	160	Hollow shafts	174
Fixed.....	160	Multiple-spline shafts.....	175
Flat	160	Shaft ends	174
Rotating	160	TorqLOC®	
Screw plug bore		Options	135
Compound gear unit.....	60	TorqLOC® hollow shaft mounting system.....	134
Selection tables		Torque arm	176
Gearmotors, structure of the selection tables		Torque arm position	176
.....	172	Trademarks	9
Self-locking helical-worm or SPIROPLAN® gear		Type designation	30
units.....	46	Helical gear units	22
Service factor		Helical-Bevel Gear Units	23
Determining the service factor.....	49	Helical-worm gear units.....	23
SEW fB	49	Options	24
SEW service factor	49	Parallel-shaft helical gear unit	22
SEW-EURODRIVE		SPIROPLAN® gear units	24
Group of companies	6	Temperature detection	27
		Type designation AC motors and options	24

Type designation DR..	
Condition monitoring	29
Encoder	26
Storage	28
Temperature sensor and temperature detection	27
Ventilation.....	28
Type designation DR2S..	
Motor series.....	25

U

Universal mounting position M0	62
--------------------------------------	----

V

Variants	
Helical-bevel gearmotors.....	516
Variants, possible	
Brakemotors	13
Reduced backlash.....	125
RM Gearmotors.....	12
Vibration SmartCheck	19
Technical data	167

Inquiry/order



Customer data:

Company: _____ Customer no.: _____
Department: _____
Name: _____ Phone: _____
Street/P.O. box: _____ Fax: _____
Email: _____
Zip code/city: _____

Contact at SEW:

Name: _____ Phone: _____
Technical office: _____ Fax: _____

Technical data:

Quantity: _____ Desired delivery date: _____
Catalog designation: _____

Gear unit type:

☐ Helical gear units ☐ Parallel-shaft helical gear units ☐ Helical-bevel gear unit ☐ Helical-worm gear unit ☐ Spiroplan® gear units
☐ Double gear units ☐ Servo gear units ☐ Variable-speed gear unit ☐ Electrified monorail system ☐ Miscellaneous: _____

Power: _____ kW Output speed: _____ rpm Output torque: _____ Nm

Cycles/hour: _____ c/h Cyclic duration factor: S _____ / _____ % cdf
☐ 1-shift operation ☐ 2-shift operation ☐ 3-shift operation
☐ Regular ☐ Irregular ☐ Very irregular

Mounting position: ¹⁾

M1 M2 M3 M4 M5 M6 Pivoted
☐ ☐ ☐ ☐ ☐ ☐ ☐

Housing form:

☐ Foot-mounted ☐ Flange (bore) ☐ Flange (thread)
☐ Torque arm ☐ Miscellaneous: _____

Shaft design:

☐ Solid shaft with key ☐ Shrink disk Shaft/hollow shaft Ø: _____ mm
☐ Hollow shaft with key ☐ TorqLOC® Flange Ø: _____ mm

Shaft position (for right-angle gear units):

☐ A ☐ B ☐ AB

Terminal box position:

☐ 0°(R) ☐ 90°(B) ☐ 180°(L) ☐ 270°(T) ☐ X ☐ 1 ☐ 2 ☐ 3

Cable entry:

Degree of protection:

IP54 IP55 IP56 IP65 IP66 IP69K
☐ ☐ ☐ ☐ ☐ ☐

Thermal class:

130(B) 155(F) 180(H)
☐ ☐ ☐

Surface/corrosion protection:

KS OS1 OS2 OS3 OS4
☐ ☐ ☐ ☐ ☐

Line voltage: _____ V

Line frequency: ☐ 50Hz ☐ 60Hz

Connection type:

☐ Δ ☐ Y ☐ YY ☐ Y/Y

Energy efficiency class:

☐ IE1 ☐ IE2 ☐ IE3 ☐ IE4

☐ For inverter operation: Max. frequency: _____ Hz

Control range: _____

Required options:

☐ Brake: Voltage _____ V Braking torque: _____ Nm
☐ Manual brake release: ☐ HR or ☐ HF
☐ Forced cooling fan: Forced cooling fan voltage: _____ V
☐ Motor protection: ☐ TF or ☐ TH
☐ Encoder: _____
☐ Plug connector connection: _____
☐ Inverter: _____
☐ RAL 7031 or ☐ RAL _____

Further options:

Special ambient conditions:


Temperature: from _____ °C to _____ °C ☐ Operation outdoors ☐ Installation altitude >1000m above NN
Further environmental conditions: _____

 
Miscellaneous: _____


 
¹⁾ see back


Place, date _____

Signature: _____

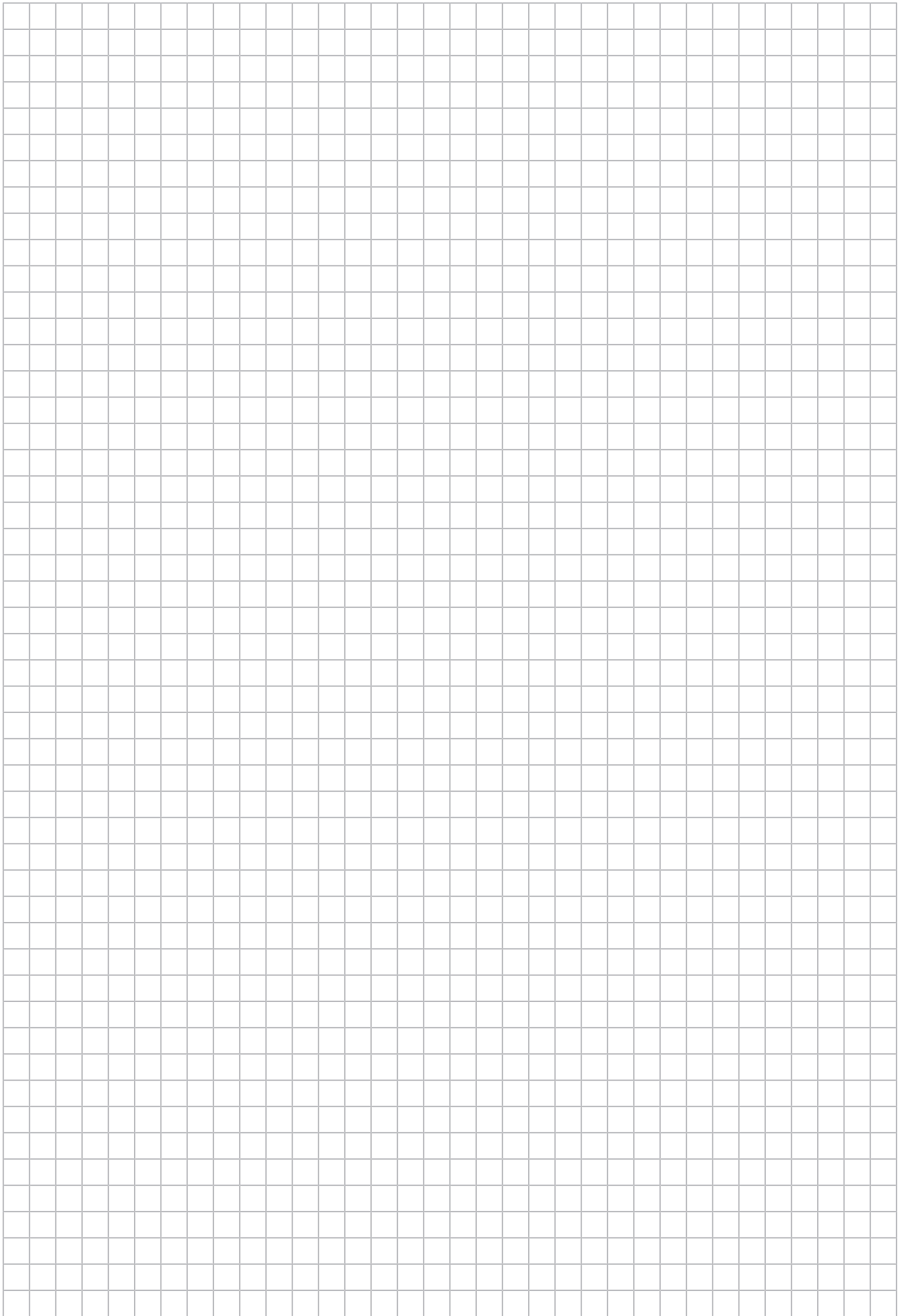



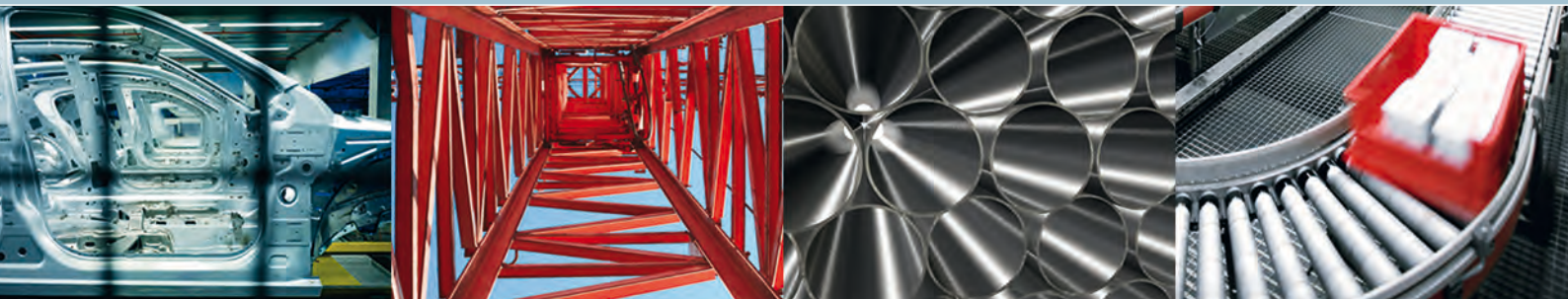

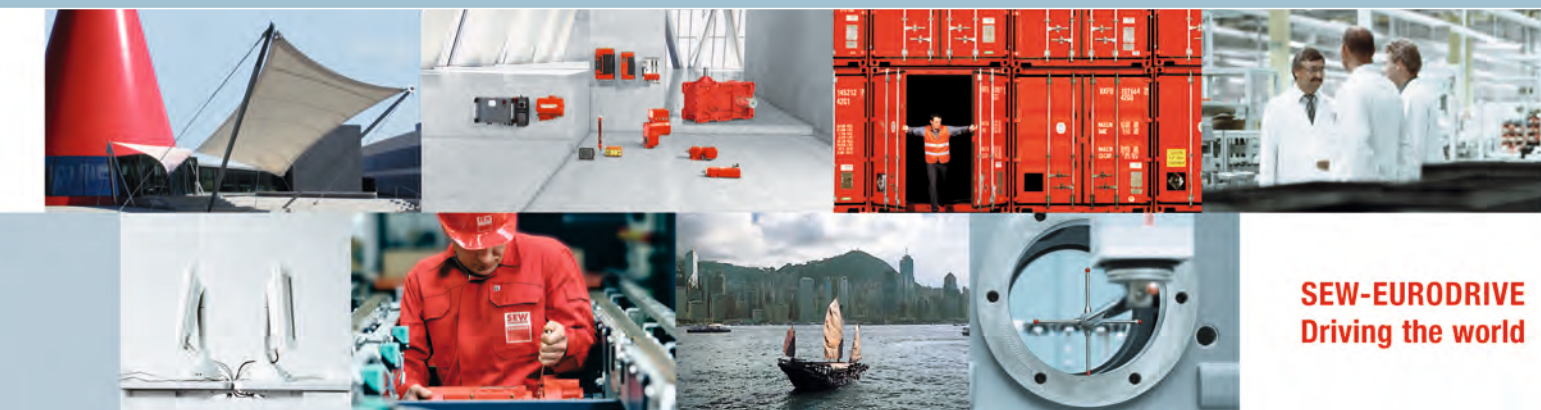

SEW-EURODRIVE
Driving the world

SEW
EURODRIVE

SEW-EURODRIVE GmbH & Co KG
Ernst-Blickle-Str. 42
76646 BRUCHSAL
GERMANY
Tel. +49 7251 75-0
Fax +49 7251 75-1970
sew@sew-eurodrive.com
→ www.sew-eurodrive.com